



SERIES MDP-16 SWITCHES

PUSHBUTTON SWITCHES - MODULAR



SPECIFICATIONS

Contact Rating: 5A, 250VAC; 8A, 125VAC UL and VDE

Life Expectancy (Mechanical): 50,000 cycles

Life Expectancy (Electrical): 6,000 cycles

Contact Resistance: 100mΩ (initial max)

Insulation Resistance: 50MΩ @ 100V min.

Dielectric Strength: 2000VDC

Actuation Force: 500 grams SPDT
800 grams DPDT

Operating Temperature: -25°C to 55°C

Storage Temperature: -40°C to 70°C

FEATURES & BENEFITS

- ▶ Modular interface design
- ▶ Attractive front panel design
- ▶ Illuminated options available
- ▶ Robust product for industrial applications

APPLICATIONS/MARKETS

- ▶ Industrial controls
- ▶ Instrumentation
- ▶ Transportation
- ▶ Telecommunications

HOW TO ORDER

SERIES MDP-16	FUNCTION STYLE	ACTUATOR CONFIGURATION	ACTUATOR STYLE	CIRCUIT CONFIGURATION	LAMP	ACTUATOR COLOR
	EE = Latching OA = Momentary	R = Round S = Square T = Rectangular	1 = Low Bezel 2 = High Bezel 3 = Flush Mount 5 = Full Guard*	1 = SPDT 2 = DPDT	00 = None 01 = 6VAC Incandescent 02 = 14VAC Incandescent 03 = 28VAC Incandescent 04 = 48VAC Incandescent 05 = 60VAC Incandescent 06 = 48VDC Incandescent 07 = Neon 110VAC 08 = Neon 220VAC 09 = LED 6VDC 10 = LED 12VDC 11 = LED 24VDC	R = Red B = Blue G = Green O = Orange Y = Yellow W = White

* Note: Only offered in square

▶ ▶ ▶ **Example Ordering Number**
MDP-16-OA-S-5-2-09-R

Specifications subject to change without notice.

TACT
SWITCHESNAVIGATION
SWITCHESPUSHBUTTON
SWITCHESTOGGLE
SWITCHESROCKER
SWITCHESSLIDE
SWITCHESSNAP-ACTION
SWITCHESDIP
SWITCHESKEYLOCK
SWITCHESROTARY
SWITCHESDETECTOR
SWITCHESCAP
OPTIONS




TACT
SWITCHESNAVIGATION
SWITCHESPUSHBUTTON
SWITCHESTOGGLE
SWITCHESROCKER
SWITCHESSLIDE
SWITCHESSNAP-ACTION
SWITCHESDIP
SWITCHESKEYLOCK
SWITCHESROTARY
SWITCHESDETECTOR
SWITCHESCAP
OPTIONS

SERIES MDP-16 SWITCHES




PUSHBUTTON SWITCHES - MODULAR

LOW BEZEL ACTUATOR STYLE




RECTANGULAR

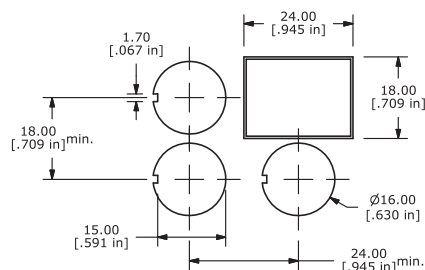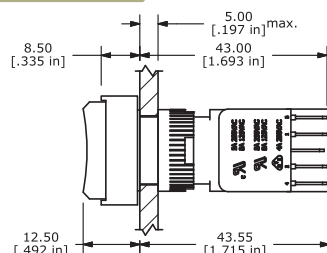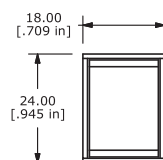

SQUARE

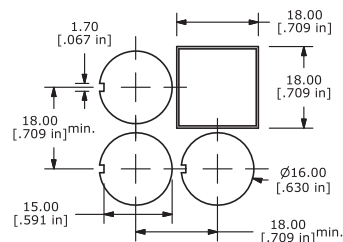
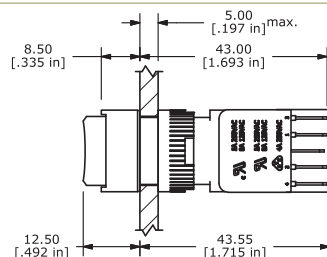
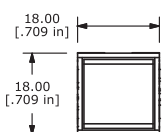


ROUND

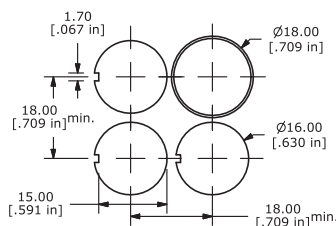
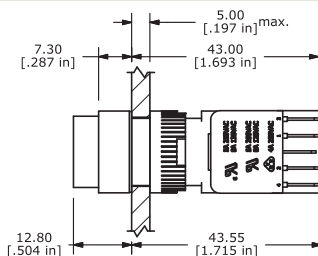
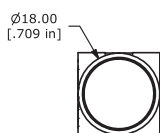


HIGH BEZEL ACTUATOR STYLE




RECTANGULAR

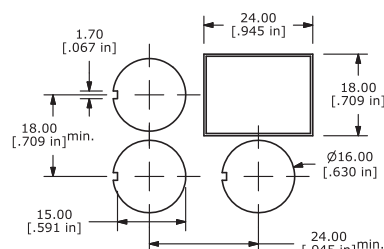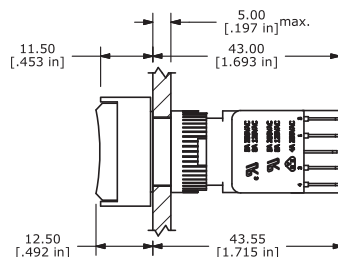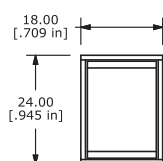

SQUARE

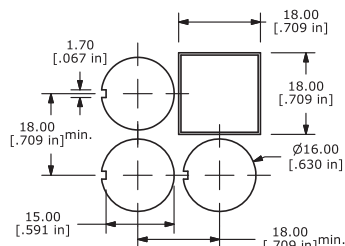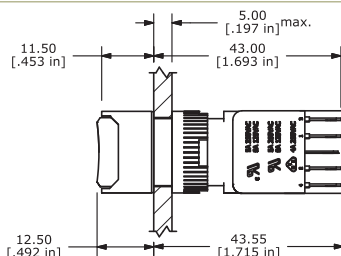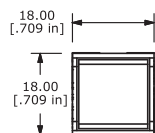


ROUND

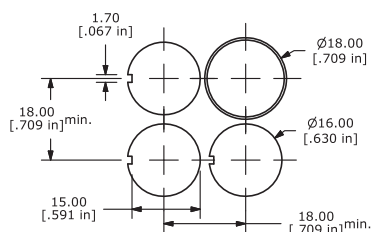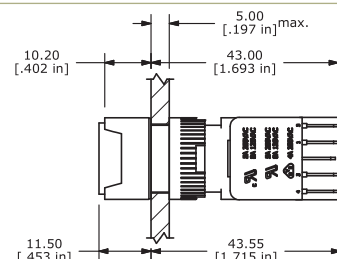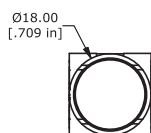




FLUSH MOUNT ACTUATOR STYLE


RECTANGULAR

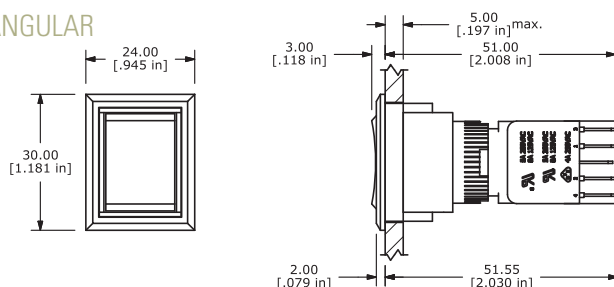

SQUARE


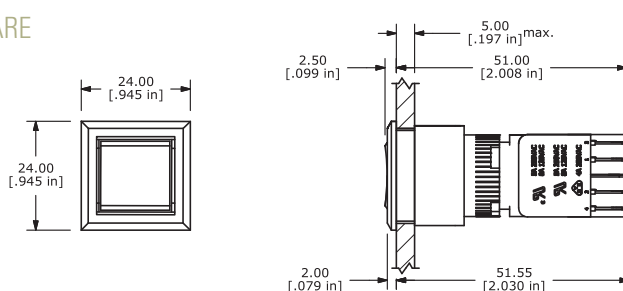


ROUND

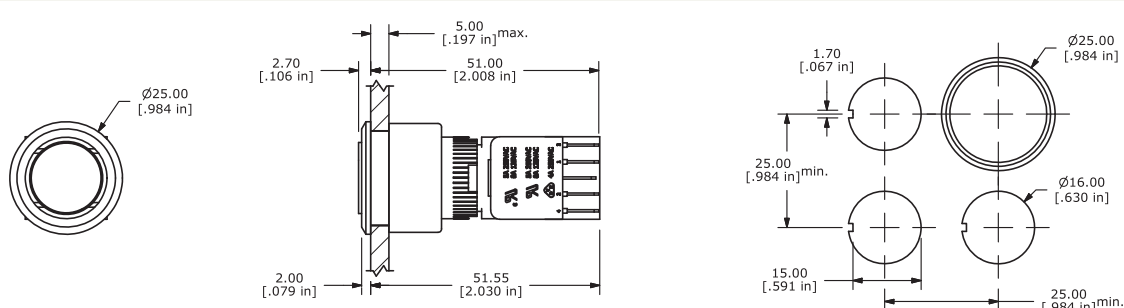


FULL GUARD ACTUATOR STYLE

SQUARE

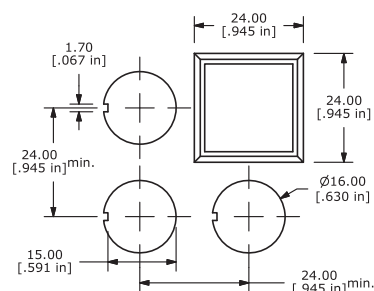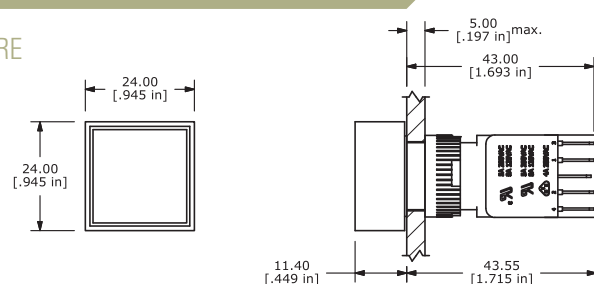


SCHEMATIC

SPDT

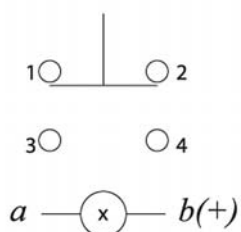

DPDT

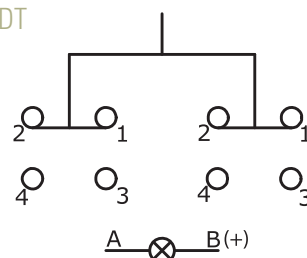TACT
SWITCHESNAVIGATION
SWITCHESPUSHBUTTON
SWITCHESTOGGLE
SWITCHESROCKER
SWITCHESSLIDE
SWITCHESSNAP-ACTION
SWITCHESDIP
SWITCHESKEYLOCK
SWITCHESROTARY
SWITCHESDETECTOR
SWITCHESCAP
OPTIONS

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[MDP160AR31R](#) [MDP160AR39G](#) [MDP160AT11R](#) [MDP160AS51R](#) [MDP160AR11R](#) [MDP160AT19G](#)
[MDP160AS11R](#) [MDP16R111R](#) [MDP160AR19G](#) [MDP160AS19G](#) [MDP160AT1100R](#) [MDP16EET2110R](#)
[MDP16EET3100Y](#) [MDP16OAT1100R](#) [MDP16EER3211B](#) [MDP16EES3211R](#) [MDP16EER3110B](#) [MDP16EES1200Y](#)
[MDP16OAR3103R](#) [MDP16OAT2210G](#) [MDP16EET1101B](#) [MDP16EET2103W](#) [MDP16OAT2100Y](#) [MDP16OAT2103R](#)
[MDP16OAT2200G](#)