
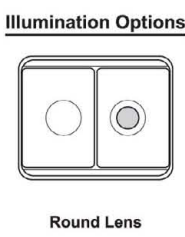
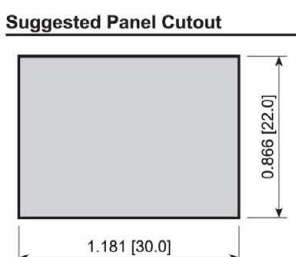


PB2 Series

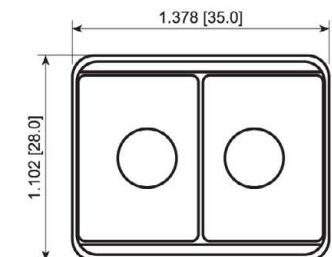

- FEATURES:**
- Popular 22mm x 30mm Cutout
 - High Power Ratings
 - Internal O-rings for Water Resistance
 - Illumination Options

SPECIFICATIONS:

RATING: 20A 125VAC [cURus UL508]
12A 250VAC [cURus UL508]
European Approvals Pending

TEMPERATURE: -20°C to 85°C

ELECTRICAL LIFE: 10,000 Cycles

CONTACT RESISTANCE: 50mΩ Max.

INSULATION RESISTANCE: 5MΩ Min. at 500VDC

DIELECTRIC STRENGTH: 1,500VAC for 1 Minute

INGRESS PROTECTION: IP54

MATERIALS:

Body: Polyamide 6/6

BEZEL: Polyamide 6/6

ACTUATOR: Polyamide 6/6





Lens: Polycarbonate

GASKET: Polyvinyl Chloride

CONTACTS: Silver Plated Copper

TERMINALS: Silver Plated Brass

O-Ring: Silicone

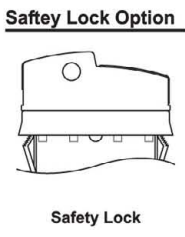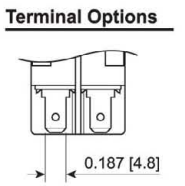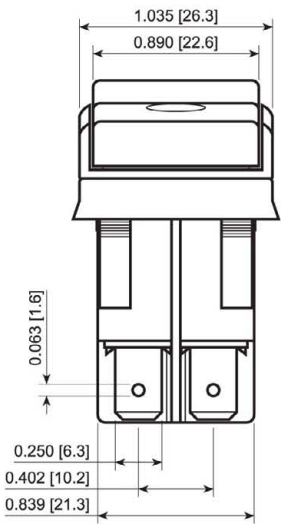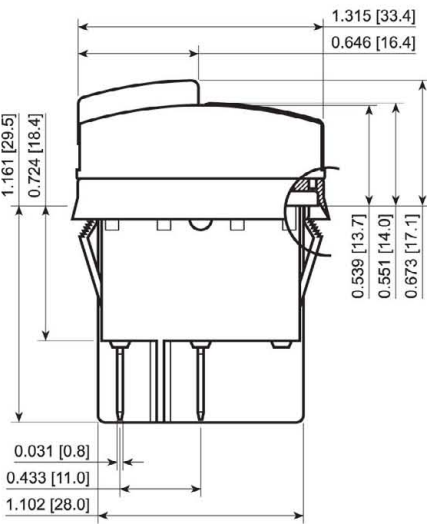

PB242D1100

| Series | Terminal | Function | Rating | Body Color | Actuator Color | Marking Color | Marking Type | Lens Style | Lens Color | Lamp Voltage |
|---|-----------------------------------|--|-----------------------------------|-----------------------------------|---|------------------------------------|---|-----------------------------------|--|--|
| <div><div></div><div></div><div></div><div></div></div> | <div><div></div><div></div></div> | <div><div></div><div></div></div> | <div><div></div><div></div></div> | <div><div></div><div></div></div> | <div><div></div><div></div></div> | <div><div></div><div></div></div> | <div><div></div><div></div></div> | <div><div></div><div></div></div> | <div><div></div><div></div></div> | <div><div></div><div></div></div> |
| PB2 - Std. Version PB2L - Safety Lock | 1 - 4.8mm Tab 4 - 6.3mm Tab | 1 Pole: 1 - Off-On 3 - On-On 2 Pole: 2 - Off-On G - On-On | D - 20A 125VAC 12A 250VAC | 1 - Black 2 - White | 1 - Black 2 - White A - Red/Green | 0 - None 1 - Black 2 - White | 0 - None 1 - I/O Vert. 3 - ON/OFF Vert. R - I/O Horiz. | 2 - Round | 0 - Clear 1 - Red 2 - Amber 3 - Green 4 - Blue | 3 - 6V 4 - 12V 5 - 24V 6 - 125V 7 - 250V |

Custom Colors and Markings Available Upon Request For Illuminated Switches Only

EXAMPLE PART NUMBERS:

PB242D1100 2P Off-On
Black Body/Actuator, No Marking



E-SWITCH®

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE

PUSHBUTTON

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[PB242D212R-207T](#) [PB242D1A2R-236](#) [PB242D1100](#) [PB242D1A11](#) [PB2L42D1100](#) [PB241D1A21](#) [PB242D1121](#)
[PB242D212R-227T](#) [PB2LS42D1100](#) [PB2L42D1A23](#)