


PV5 SERIES ANTI-VANDAL SWITCH

ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS




APPLICATIONS / MARKETS

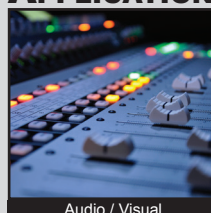


Audio / Visual



Security Devices

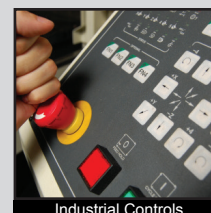


Industrial Controls

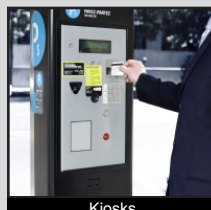

Kiosks



Electrical Housewares

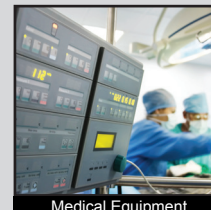

Medical Equipment

RoHS

SPECIFICATIONS

Electrical Rating: 2A, 36VDC
Mechanical Life: 1,000,000 Cycles
Electrical Life: 200,000 Cycles
Contact Resistance: 50mΩ Max.
Insulation Resistance: 1000 MΩ Min.
Dielectric Strength: 2,000VAC
Operating/Storage Temperature: -25°C to 55°C
Travel: 2.50mm
Moisture Protection: IP65
Contact Arrangement: SPST Off-(On)
Actuation Force: 5 N
Panel Thickness: 1-5mm
Mounting Nut Torque: 0.3Nm

FEATURES & BENEFITS

- Multiple actuator finish options
- Solder or screw termination options
- Raised or domed actuator options
- IP65 rated

PART NUMBER CONFIGURATOR

Series	Actuator Options	Terminal Options	Function Options	Rating Options	Body Finish Options	Actuator Finish Options	Contact Material Options
PV5	H	2	4	0	N	1	NONE
PV5	H - Raised S - Domed	2 - Solder 6 - Screw	4 - 1 Pole Off - (On)*	0 - 2A, 36VDC	N - Nickel S - Polished Stainless 1 - Black Anodized	1 - Black 2 - White 6 - Yellow 7 - Blue 8 - Green 9 - Red N - Nickel S - Polished Stainless	NONE - Silver G - Gold

NOTES:

*(ON) Denotes function is momentary

Specifications subject to change without notice



E-SWITCH®

www.e-switch.com




800.867.2717

1




PV5 SERIES ANTI-VANDAL SWITCH

BODY DIMENSIONS - FLATS

SOLDER TERMINATION

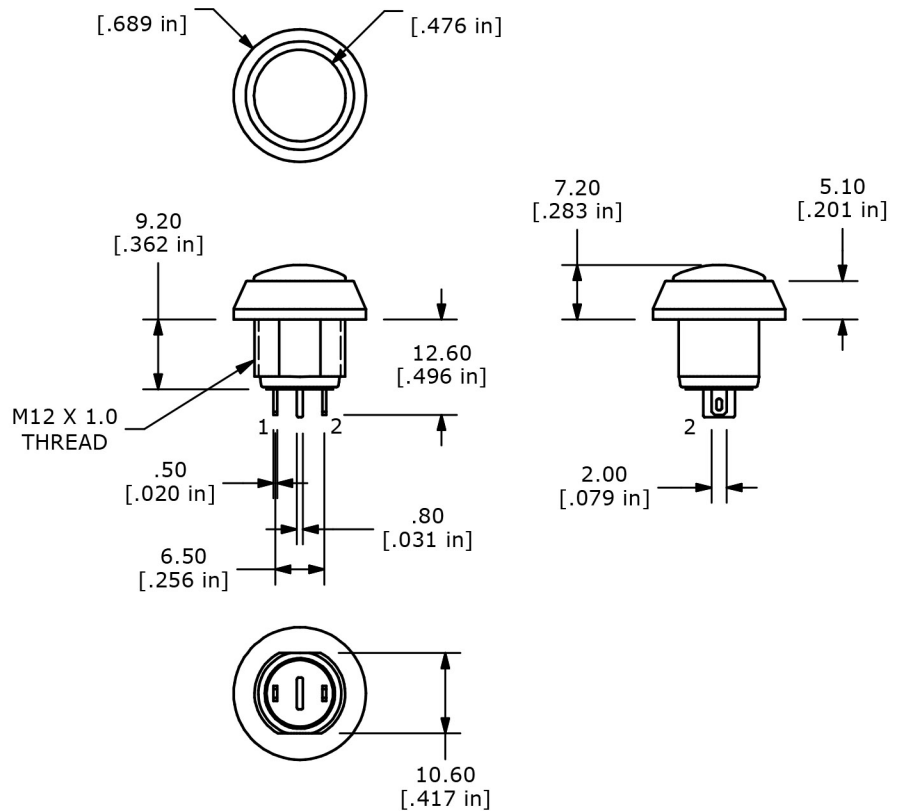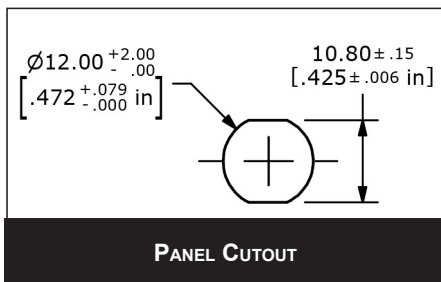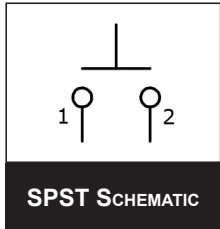

SCREW TERMINATION

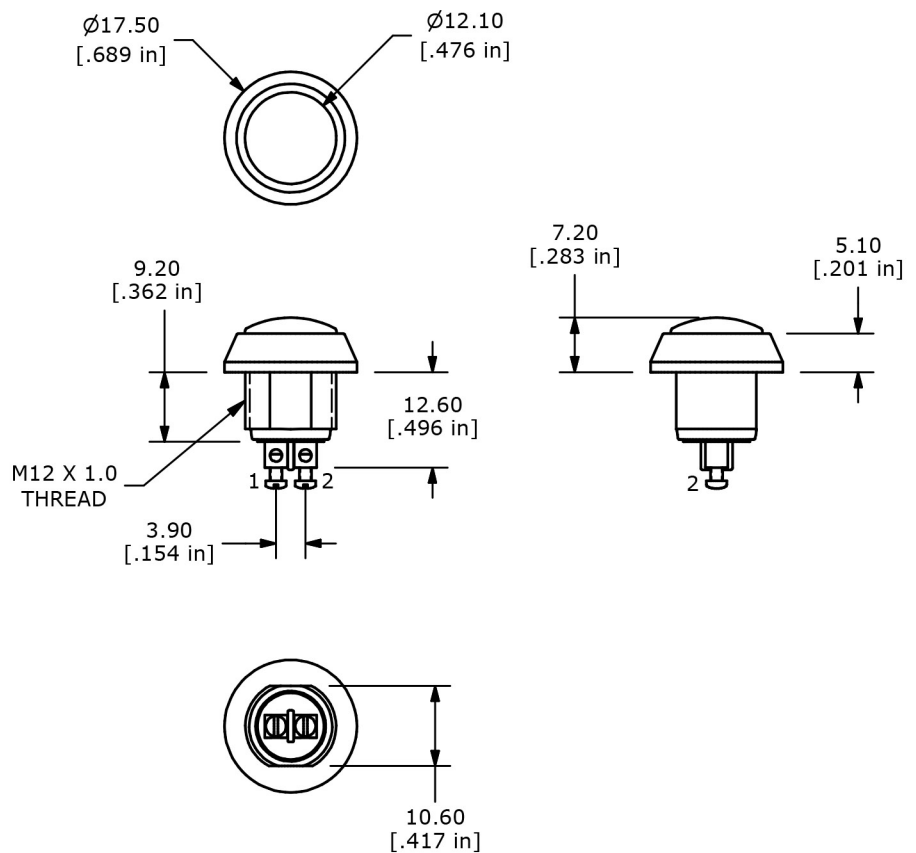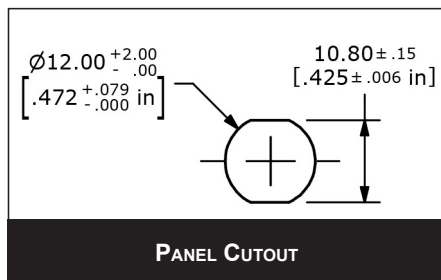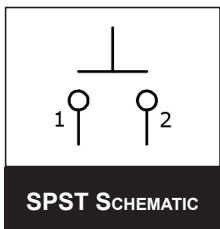

E-SWITCH®

www.e-switch.com

800.867.2717





2

ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS





PV5 SERIES ANTI-VANDAL SWITCH

BODY DIMENSIONS - NICKEL, BLACK ANODIZED OR STAINLESS

SOLDER TERMINATION

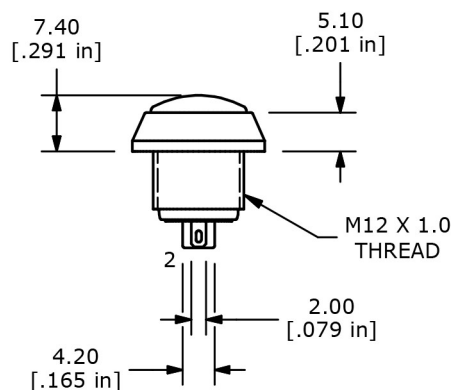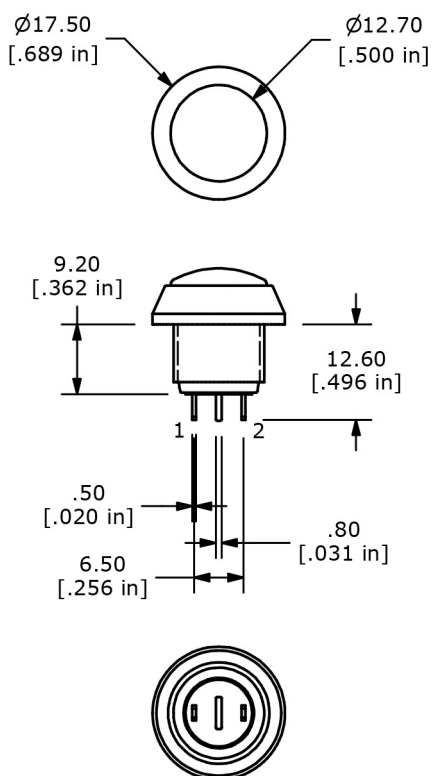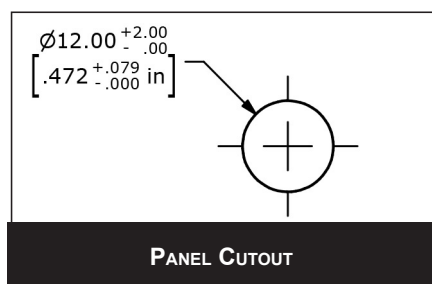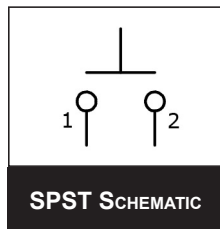

SCREW TERMINATION

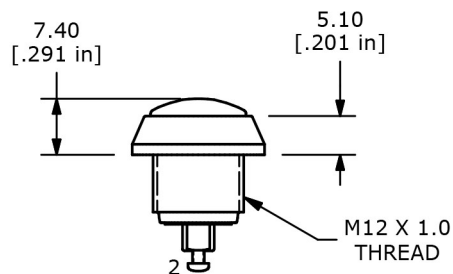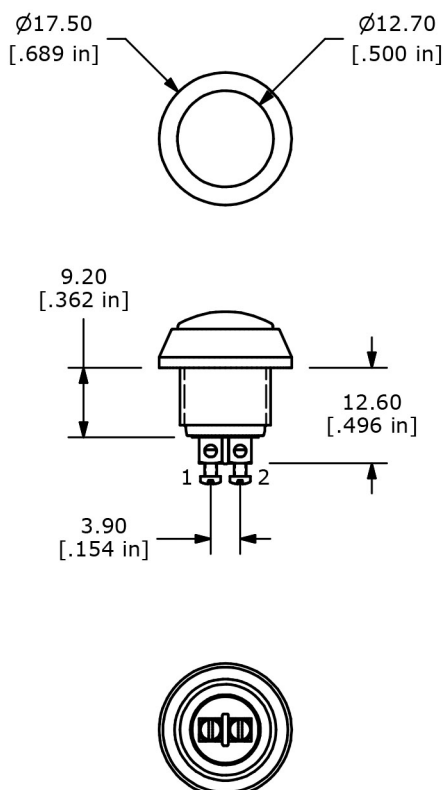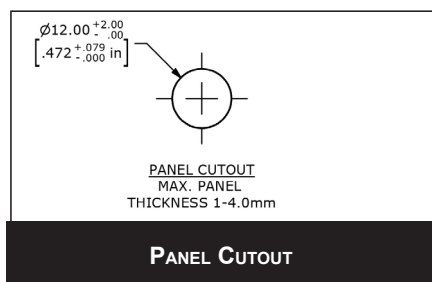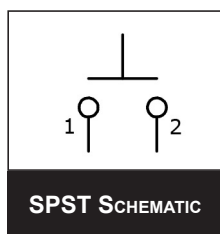

E-SWITCH®



www.e-switch.com

800.867.2717



3

ACTUATOR OPTIONS

NICKEL OR STAINLESS

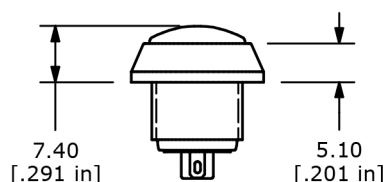
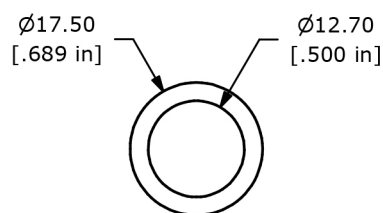


DOMED ACTUATOR

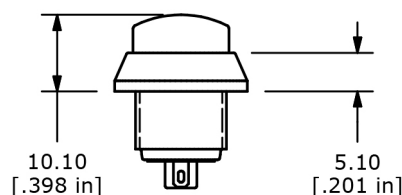
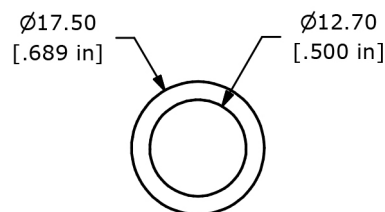


RAISED ACTUATOR

BLACK, WHITE, YELLOW, BLUE, GREEN OR RED

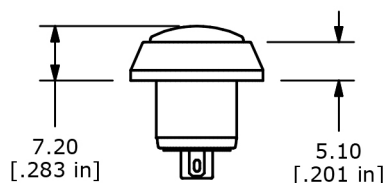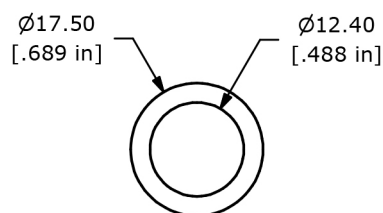

DOMED ACTUATOR

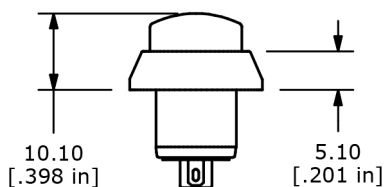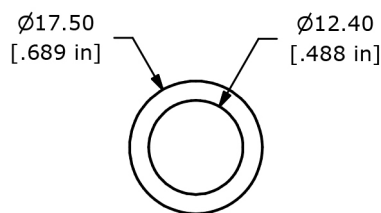

RAISED ACTUATOR



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[PV5S64011](#) [PV5S64017](#) [PV5S64012](#) [PV5S64016](#) [PV5S640SS](#) [PV5S64012G](#) [PV5S64018](#) [PV5S64019](#)
[PV5S64019G](#) [PV5S640NN](#) [PV5S24017](#) [PV5S24018](#) [PV5S24019](#) [PV5S24016](#) [PV5S24011G](#) [PV5S24011](#)
[PV5H24019](#) [PV5H24018](#) [PV5S24016G](#) [PV5S24019G](#) [PV5H24011](#) [PV5S24017G](#) [PV5S24018G](#) [PV5S24012G](#)
[PV5S24011-UP \(ON\)](#) [PV5S24011-OKAY](#) [PV5S24011-MENU](#) [PV5S24011-DOWN \(OFF\)](#) [PV5H240SS](#) [PV5S240S6](#)
[PV5S240S8](#) [PV5S240S9](#) [PV5S240SS](#) [PV5S240S1](#) [PV5S240NN](#) [PV5H640S8](#) [PV5Oring](#) [52-PV5DS240SSG](#)
[PV5HEXNUT12](#)