


PVB3 SERIES ANTI-VANDAL SWITCH




APPLICATIONS / MARKETS

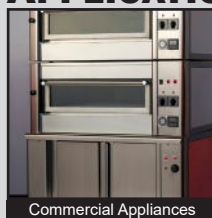


Commercial Appliances



Security Devices

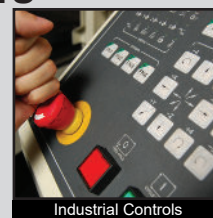


Industrial Controls

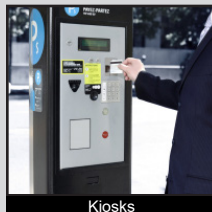

Kiosks



Electrical Housewares

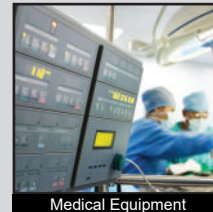

Medical Equipment

RoHS

SPECIFICATIONS

Electrical Rating: 2A, 24VDC. 0.5A, 220VAC
Mechanical Life: 1,000,000 Cycles (Momentary)
500,000 Cycles (Latching)
Electrical Life: 50,000 Cycles
Contact Resistance: 50mΩ Max.
Insulation Resistance: 1000 MΩ Min. @ 500VDC
Dielectric Strength: 1,500VAC
Operating/Storage Temperature: -25°C to 55°C
Travel: 3.0mm
Moisture Protection: IP65
Contact Arrangement: SPDT
Actuation Force: 2.5N
Panel Thickness: 1-7mm

FEATURES & BENEFITS

- 16mm panel cutout
- Ring illumination option
- Multiple LED color options
- IP65 rated
- Momentary or Latching functions

PART NUMBER CONFIGURATOR

Series	Actuator Options	Terminal Options	Function Options	Rating Options	Body Finish Options	Actuator Finish Options	Contact Material Options	Lens Style Option	LED-Color Options	Illumination Voltage Options
PVB3	F - Flat H - High	2 - Solder	B - 1P On - (On)* 3 - 1P On - On	0 - 2A, 24VDC. 0.5A, 220VAC	S - Stainless Steel 1 - Black Anodized	S - Stainless Steel 1 - Black Anodized	NONE - Silver	NONE - Non-Illuminated 3 - Ring Illumination 6 - Ring / Power symbol	NONE - Non-Illuminated 0 - White 1 - Red 2 - Orange 3 - Green 4 - Blue 5 - Yellow R - RGB Common Cathode RA - RGB Common Anode	NONE - Non-Illuminated 1 - Base Voltage† 3 - 6V 4 - 12V 5 - 24V 6 - 125V 7 - 250V

NOTES:

* (ON) Denotes function is momentary

† Base voltage on LEDs:

1.8V @ 20mA for Red, Yellow and Orange LED colors

2.8V @ 20mA for Blue, Green and White LED colors

Specifications subject to change without notice 11.1.2023



E-SWITCH®





www.e-switch.com

800.867.2717

1

PVB3 SERIES ANTI-VANDAL SWITCH

FLAT ACTUATOR LED ILLUMINATED RING BODY DIMENSIONS

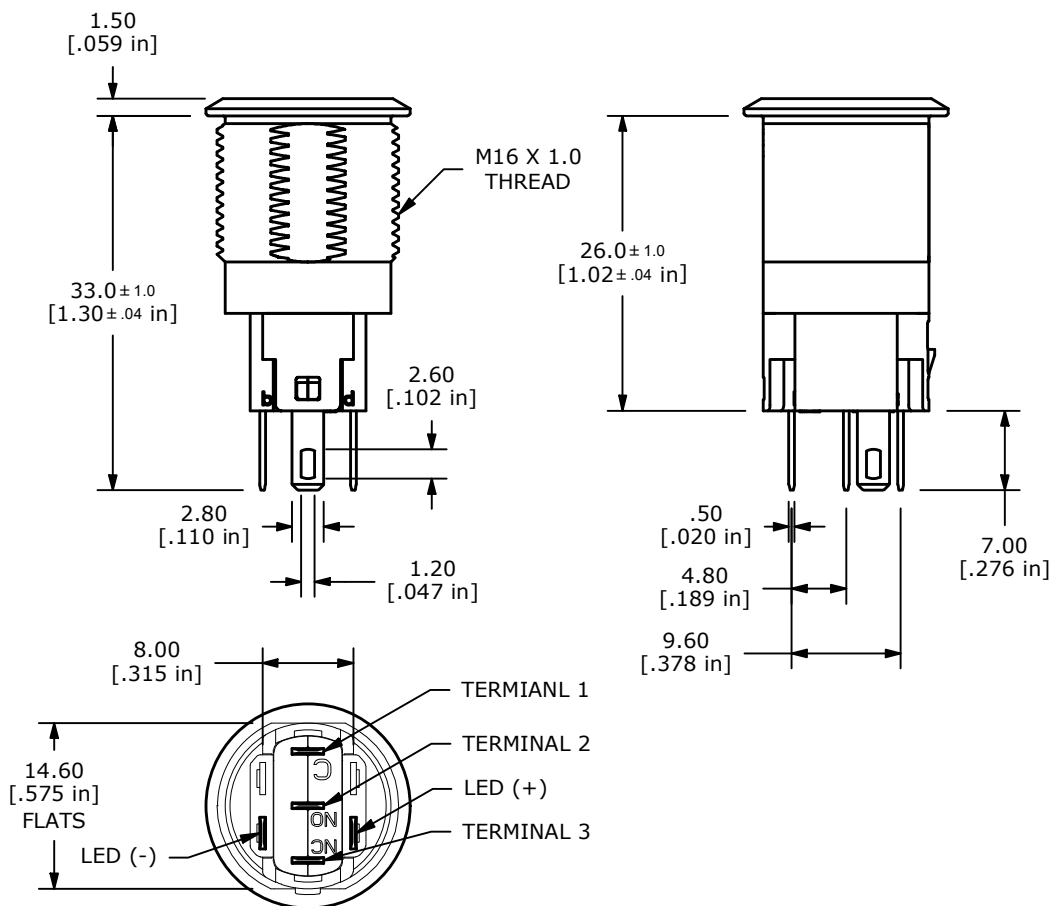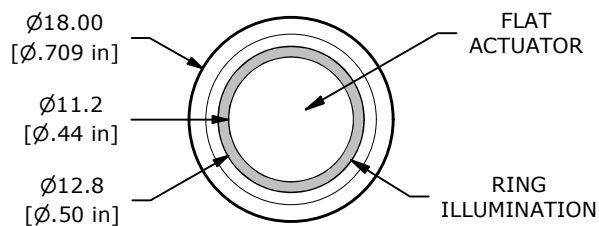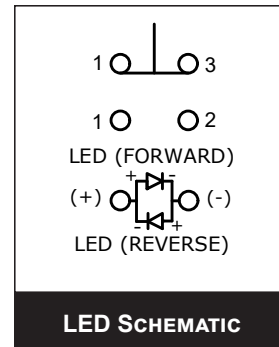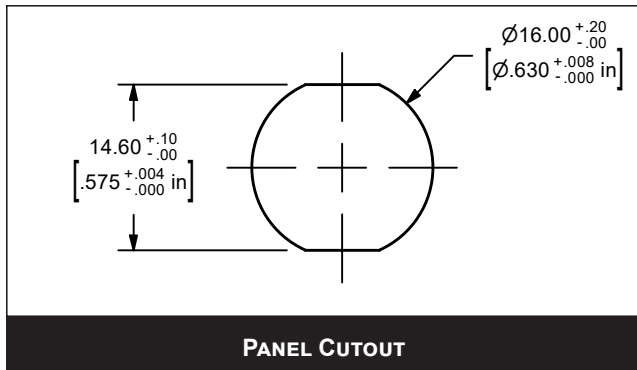

E-SWITCH®

www.e-switch.com

800.867.2717

2

ANTI-VANDAL
SWITCHES

DETECTOR
SWITCHES

DIP
SWITCHES

KEYLOCK
SWITCHES

NAVIGATION
SWITCHES

PUSHBUTTON
SWITCHES

ROCKER
SWITCHES

ROTARY
SWITCHES

SLIDE
SWITCHES

SNAP ACTION
SWITCHES





TACTILE
SWITCHES

TOGGLE
SWITCHES

CAP
OPTIONS

PVB3 SERIES ANTI-VANDAL SWITCH

FLAT ACTUATOR RGB ILLUMINATED RING BODY DIMENSIONS

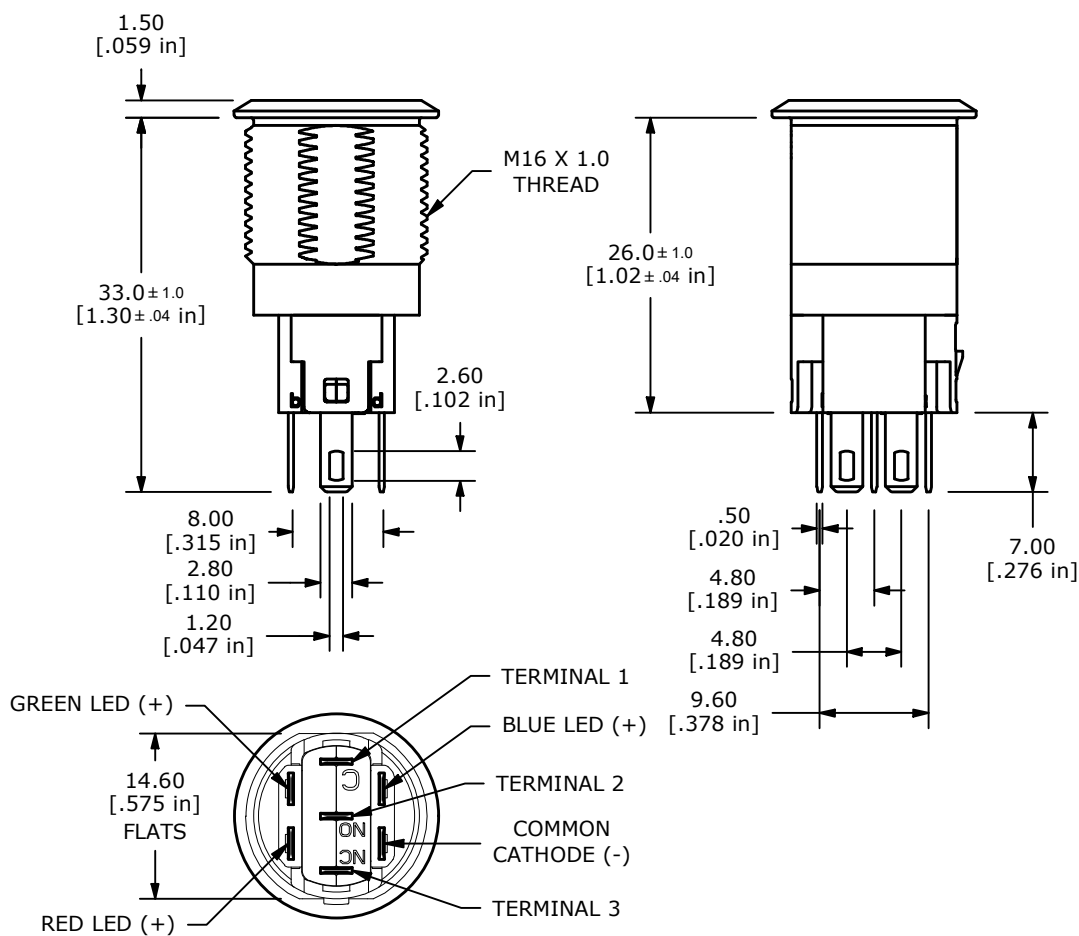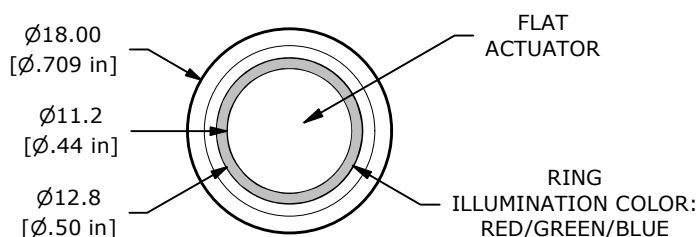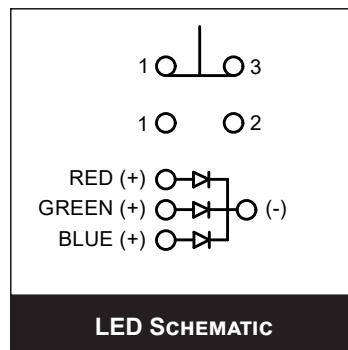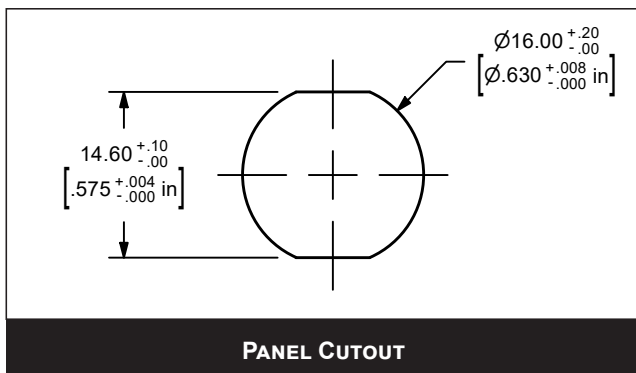

E-SWITCH®





www.e-switch.com

800.867.2717

3

PVB3 SERIES ANTI-VANDAL SWITCH

HIGH ACTUATOR LED ILLUMINATED RING BODY DIMENSIONS

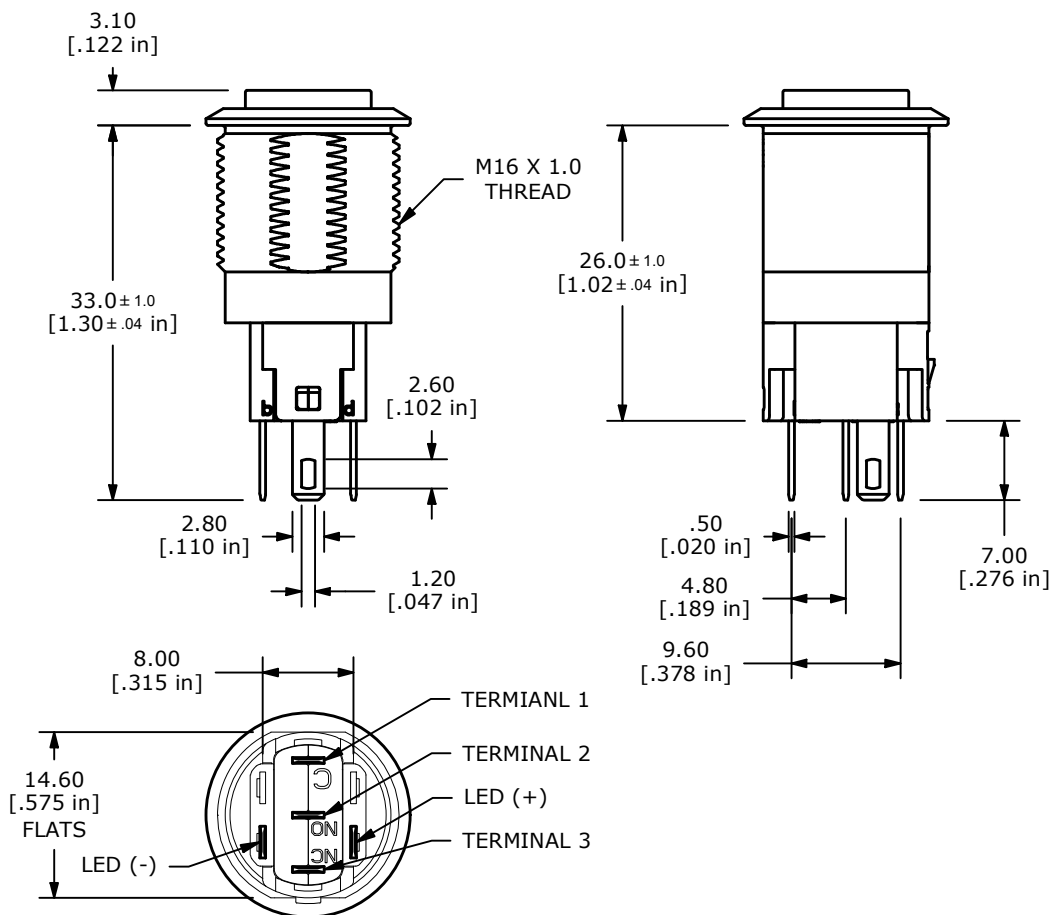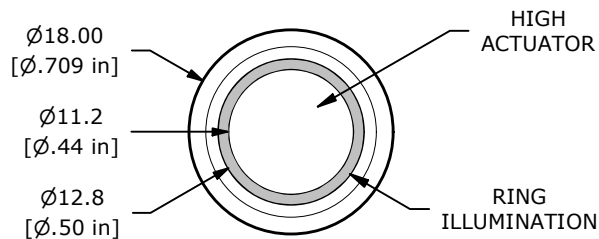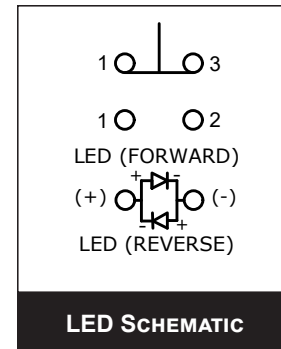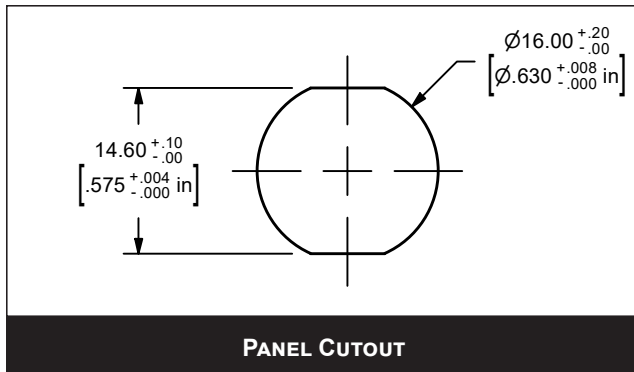

E-SWITCH®

www.e-switch.com





800.867.2717

4

ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS

PVB3 SERIES ANTI-VANDAL SWITCH

FLAT ACTUATOR LED ILLUM RING/POWER BODY DIMENSIONS

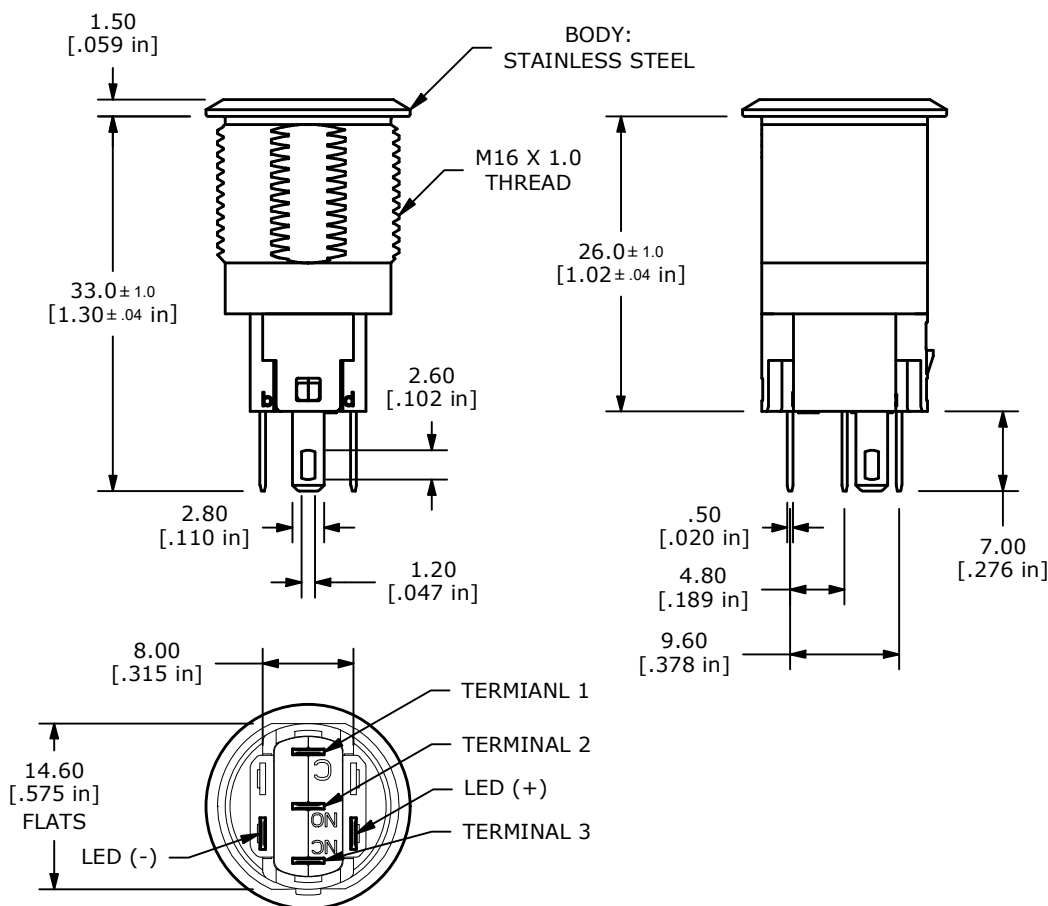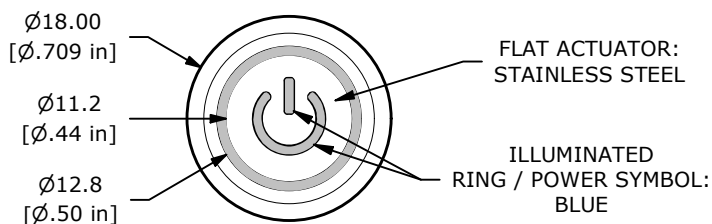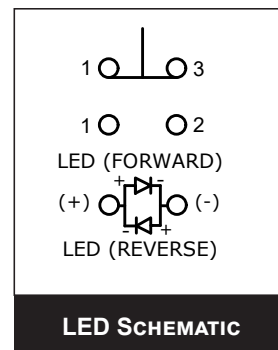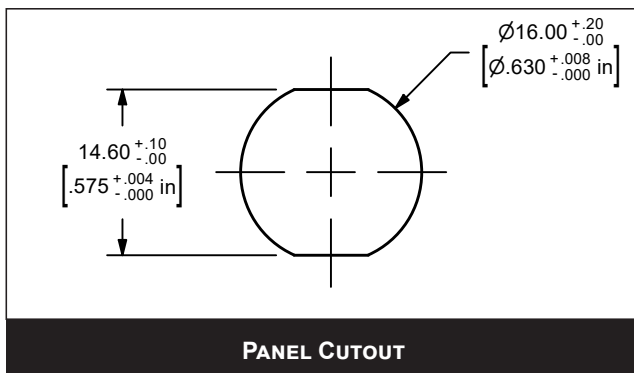

E-SWITCH®

www.e-switch.com

800.867.2717

5

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[E-Switch:](#)

[PVB3F230113R1](#) [PVB3F230SS334](#) [PVB3H2B0SS3R1](#) [PVB3F2B0SS3R1](#) [PVB3H2B0113R1](#) [PVB3F230SS323](#)
[PVB3H230SS341](#) [PVB3F2B0113R1](#) [PVB3F2B0SS3R5](#) [PVB3H230SS331](#) [PVB3H230SS3R1](#) [PVB3H23011301](#)
[PVB3F2B0SS644](#) [PVB3H230113R1](#) [PVB3F230SS3R1](#) [PVB3F2B0SS301](#) [PVB3H230SS311](#) [PVB3F23011331](#)
[PVB3F230SS311](#)