

PZ SERIES ANTI-VANDAL SWITCH

ANTI-VANDAL SWITCHES

DETECTOR SWITCHES

DIP SWITCHES

KEYLOCK SWITCHES

NAVIGATION SWITCHES

PUSHBUTTON SWITCHES

ROCKER SWITCHES

ROTARY SWITCHES

SLIDE SWITCHES

SNAP ACTION SWITCHES


TACTILE SWITCHES

TOGGLE SWITCHES

CAP OPTIONS




APPLICATIONS / MARKETS

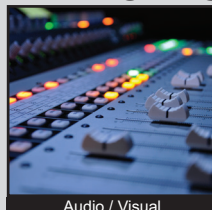


Audio / Visual



Security Devices

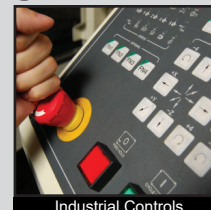

Industrial Controls

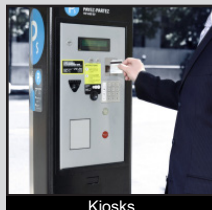

Kiosks



Electrical Housewares



Medical Equipment

SPECIFICATIONS

Contact Rating: 1A @ 5-24VDC
Electrical Life: 50,000,000 Cycles
Contact Resistance: 1Ω Max.
Operating Temperature: -20°C to 65°C
Storage Temperature: -25°C to 65°C
Panel Thickness: 10mm Max.
Moisture Protection: IP68 (in house tested)

FEATURES & BENEFITS

- 19mm and 22mm panel cutouts
- Ring illumination options
- RGB color options
- Bezel options
- IP68 (in house tested)

PART NUMBER CONFIGURATOR

Series	Size Options	Function	Housing	Bezel	Illumination Style	LED-Color Options	Wire Length
PZ	4 - 19mm 7 - 22mm	M - Momentary/Pulse	1 - Black Anodized (Double Flat) 2 - Clear Anodized (Double Flat)	C - Concave F - Flat	N - Non-Illuminated R - Ring Illuminated	N - Non-Illuminated R - RGB	W150 - 150mm (with 1x6 Conn) W300 - 300mm (with 1x6 Conn)

Specifications subject to change without notice 1.19.2022



E-SWITCH®


www.e-switch.com

800.867.2717


1

PZ SERIES ANTI-VANDAL SWITCH

BODY DIMENSIONS 19MM OPTION CONCAVE BEZEL

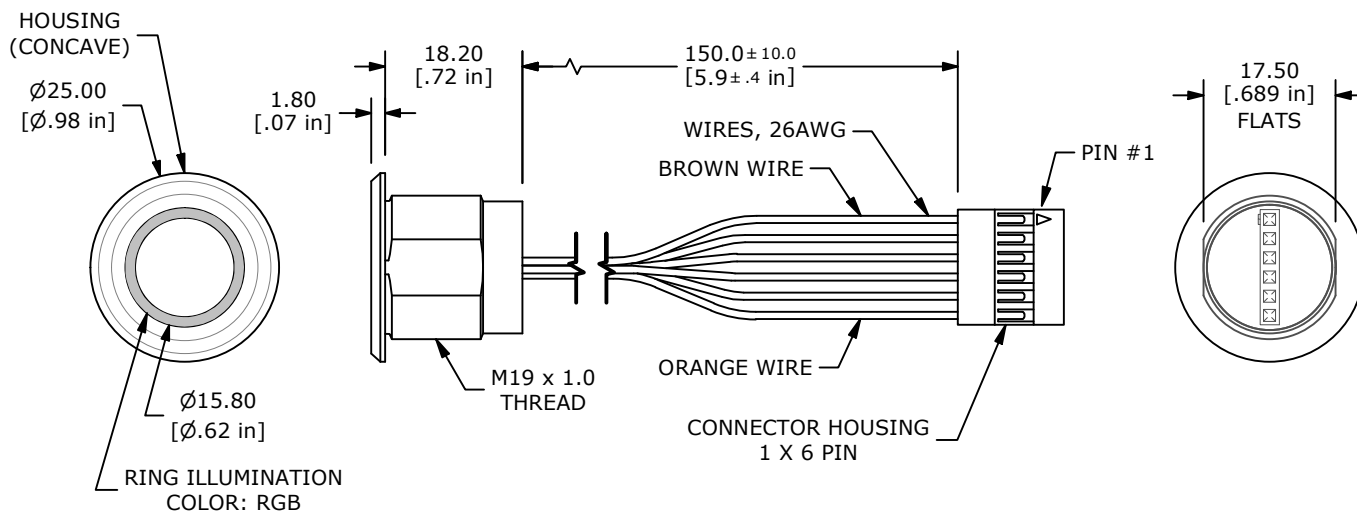

BODY DIMENSIONS 22MM OPTION CONCAVE BEZEL

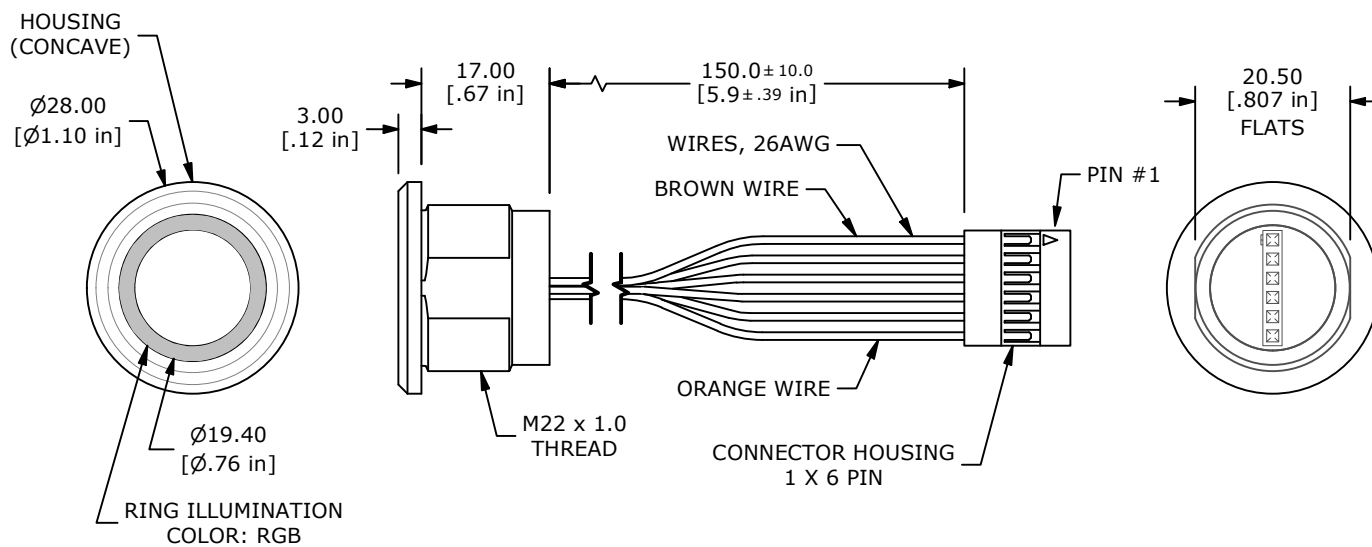

E-SWITCH®

www.e-switch.com

800.867.2717

2

ANTI-VANDAL
SWITCHES

DETECTOR
SWITCHES

DIP
SWITCHES

KEYLOCK
SWITCHES

NAVIGATION
SWITCHES

PUSHBUTTON
SWITCHES

ROCKER
SWITCHES

ROTARY
SWITCHES

SLIDE
SWITCHES

SNAP ACTION
SWITCHES


TACTILE
SWITCHES

TOGGLE
SWITCHES


CAP
OPTIONS

PZ SERIES ANTI-VANDAL SWITCH

BODY DIMENSIONS 19MM OPTION FLAT BEZEL

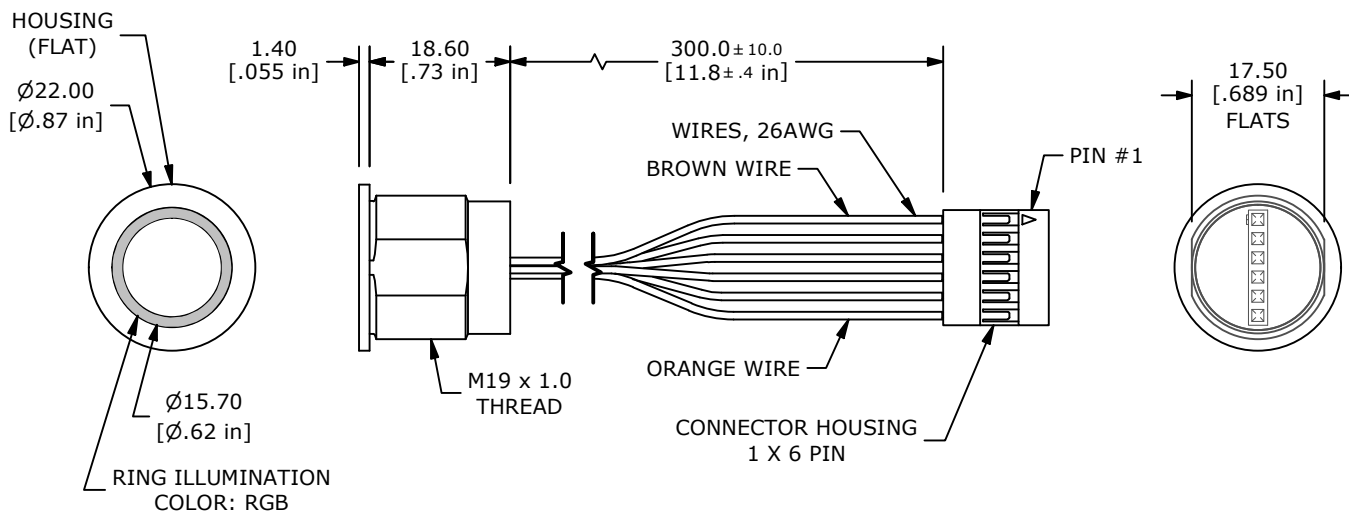

BODY DIMENSIONS 22MM OPTION FLAT BEZEL

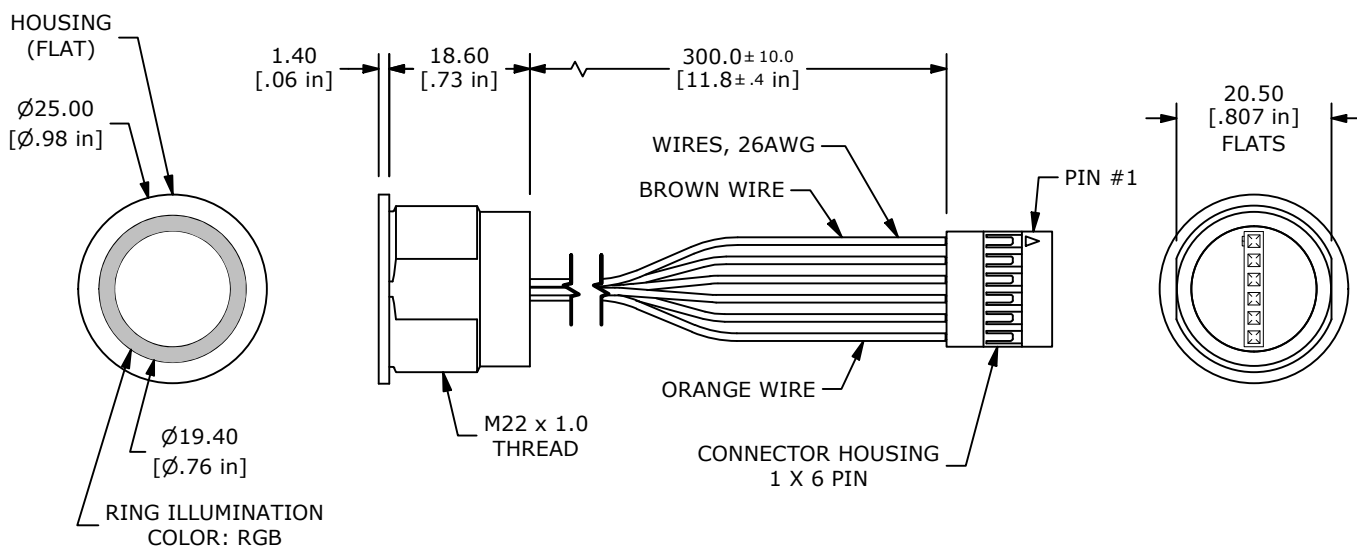

E-SWITCH®


www.e-switch.com

800.867.2717


3

PZ SERIES ANTI-VANDAL SWITCH

PANEL CUTOUT & SCHEMATIC

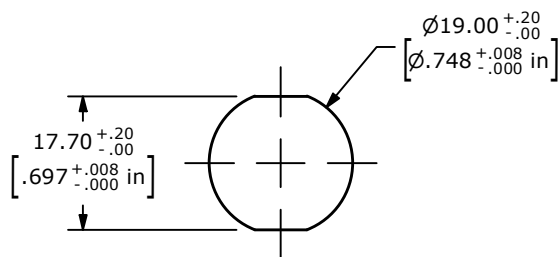


19MM - CUTOUT

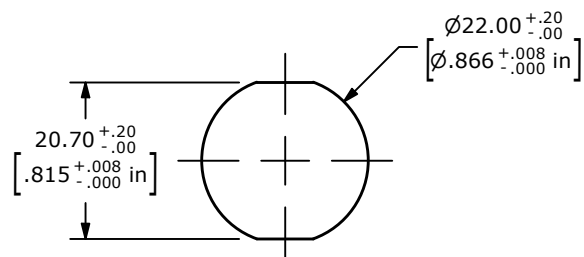


22MM - CUTOUT

RECOMMENDED PANEL CUTOUT

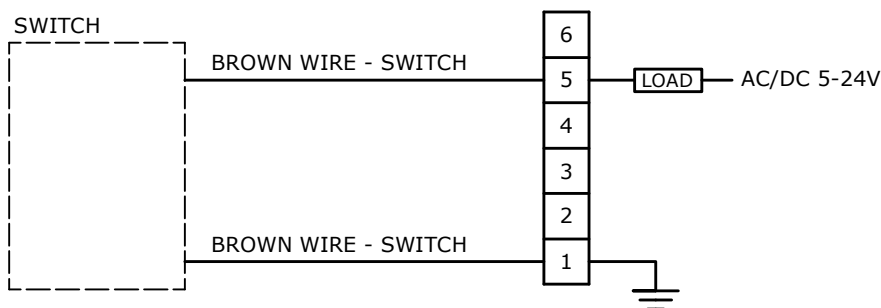

SCHEMATIC
MOMENTARY/PULSE Non-ILLUMINATED

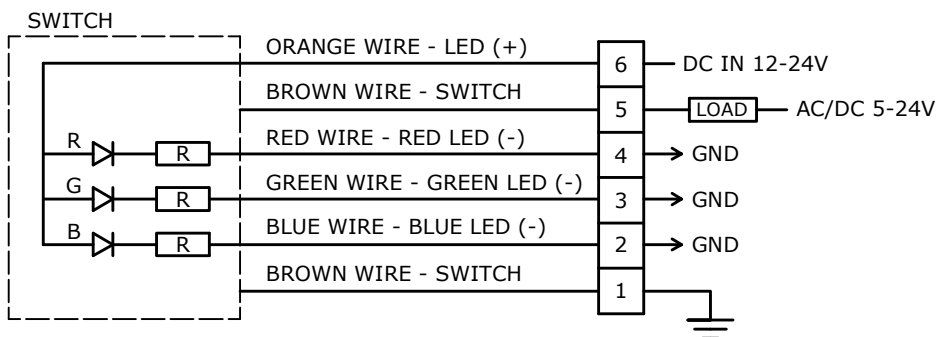

SCHEMATIC
MOMENTARY/PULSE ILLUMINATED - RGB

SCHEMATICS



E-SWITCH®

www.e-switch.com

800.867.2717

4

ANTI-VANDAL
SWITCHES

DETECTOR
SWITCHES

DIP
SWITCHES

KEYLOCK
SWITCHES

NAVIGATION
SWITCHES

PUSHBUTTON
SWITCHES

ROCKER
SWITCHES

ROTARY
SWITCHES

SLIDE
SWITCHES

SNAP ACTION
SWITCHES

TACTILE
SWITCHES

TOGGLE
SWITCHES

CAP
OPTIONS

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[PZ7M2CRRW150](#) [PZ4M2CNNW150](#) [PZ4M2CRRW150](#) [PZ7M2CNNW150](#)