 
 




# RD1 Series

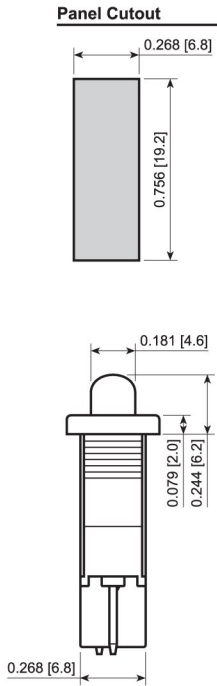

ROCKER

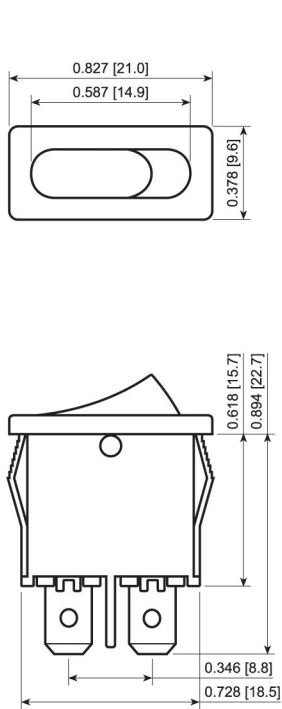

## FEATURES:

- Compact Size With High Ratings
- Ideal for Applications With Limited Space

## SPECIFICATIONS:

**RATING:** RATING OPTION C:

- 16A 125VAC [UL, cUL]
- 10A 250VAC [UL, cUL]
- 1/3HP 125/250VAC [UL, cUL]
- 10(4)A 250V~ 1E4 T125 [VDE]
- 10(2)A 250V~ 5E4 T85 [VDE]

**RATING OPTION 3:**

- 10A 125VAC [UL, cUL]
- 6(2)A 250V~ 1E4 T125 [VDE]

**TEMPERATURE:** -20°C to 105°C [UL, cUL]  
-20°C to 125°C [VDE]

**ELECTRICAL LIFE:** 10,000 Cycles

**CONTACT RESISTANCE:** 35mΩ Max.

**INSULATION RESISTANCE:** 100MΩ Min. at 500VDC

**DIELECTRIC STRENGTH:** 1,500VAC for 1 Minute

## MATERIALS:

**BODY:** Polyamide 6/6, UL94 V-2

**ACTUATOR:** Polyamide 6/6, UL94 V-2

**CONTACTS:** Silver Alloy

**TERMINALS:** Silver Plated Copper



RD1



1 - 4.8mm Tab  
5 - Solder



1 - Off-On  
4 - Off-(On)



3 - 10A 125VAC  
C - 16A 125VAC



1 - Black  
2 - White  
3 - Almond  
4 - Grey  
9 - Red



1 - Black  
2 - White  
3 - Almond  
4 - Grey  
5 - Orange  
7 - Blue  
8 - Green  
9 - Red



0 - None  
1 - Black  
2 - White  
8 - Red



0 - None  
1 - I/O Vert.  
3 - ON/OFF Vert.  
4 - ON/OFF Horiz.

Custom Colors and Markings Available Upon Request

## EXAMPLE PART NUMBERS:

**RD11131100** 1P Off-On  
Black Body/Actuator, No Marking

**RD11131121** 1P Off-On  
Black Body/Actuator, I/O Vert.

**RD111C1100** 1P Off-On  
Black Body/Actuator, No Marking

**RD111C1121** 1P Off-On  
Black Body/Actuator, I/O Vert.



**E-SWITCH®**

www.e-switch.com

800.867.2717

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[E-Switch:](#)

[RD11131121](#) [RD1113112R](#) [RD15131121](#) [RD151C1100](#) [RD111C1121](#) [RD151C2200](#) [RD151C112F](#)