



RD1 Series




ROCKER

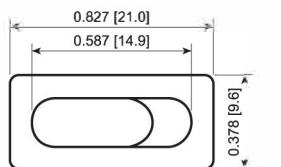


Panel Cutout

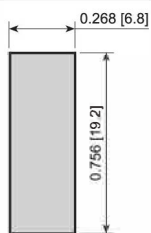



Terminal Options

 

 4.8mm Tab



Solder

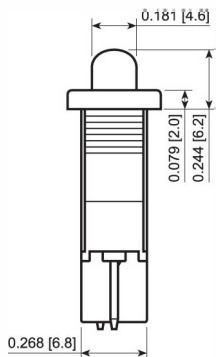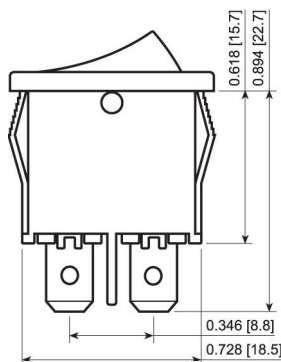

FEATURES:

- Compact Size With High Ratings
- Ideal for Applications With Limited Space

SPECIFICATIONS:

RATING: RATING OPTION C:

- 16A 125VAC [UL, cUL]
- 10A 250VAC [UL, cUL]
- 1/3HP 125/250VAC [UL, cUL]
- 10(4)A 250V~ 1E4 T125 [VDE]
- 10(2)A 250V~ 5E4 T85 [VDE]

RATING OPTION 3:

- 10A 125VAC [UL, cUL]
- 6(2)A 250V~ 1E4 T125 [VDE]

TEMPERATURE: -20°C to 105°C [UL, cUL]

- 20°C to 125°C [VDE]

ELECTRICAL LIFE: 10,000 Cycles

CONTACT RESISTANCE: 35mΩ Max.

INSULATION RESISTANCE: 100MΩ Min. at 500VDC

DIELECTRIC STRENGTH: 1,500VAC for 1 Minute

MATERIALS:

Body: Polyamide 6/6, UL94 V-2

Actuator: Polyamide 6/6, UL94 V-2

Contacts: Silver Alloy

Terminals: Silver Plated Copper



RD11131121



RD11131200



RD111C1900



RD1



1 - 4.8mm Tab



1 - Off-On
4 - Off-(On)



3 - 10A 125VAC
C - 16A 125VAC



1 - Black
2 - White
3 - Almond
4 - Grey
9 - Red



1 - Black
2 - White
3 - Almond
4 - Grey
5 - Orange
7 - Blue
8 - Green
9 - Red



0 - None
1 - Black
2 - White
8 - Red



0 - None
1 - I/O Vert.
3 - ON/OFF Vert.
4 - ON/OFF Horiz.

Custom Colors and Markings Available Upon Request

EXAMPLE PART NUMBERS:

RD11131100 1P Off-On
Black Body/Actuator, No Marking

RD11131121 1P Off-On
Black Body/Actuator, I/O Vert.

RD111C1100 1P Off-On
Black Body/Actuator, No Marking

RD111C1121 1P Off-On
Black Body/Actuator, I/O Vert.



E-SWITCH®

www.e-switch.com

800.867.2717

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE 3/16/2021.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[RD11131121](#) [RD1113112R](#) [RD111C1121](#) [RD11131200](#) [RD11131100](#)