





ROCKER

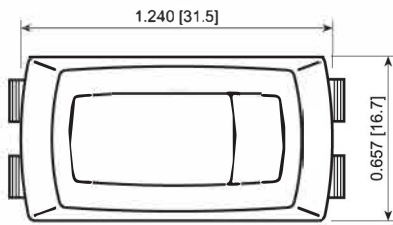

Panel Cutout

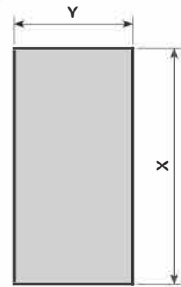


	X	Y
RSC1-Series	1.126 [28.6]	0.547 [13.9]
RSC2-Series	1.071 [27.2]	0.476 [12.1]
RSC3-Series	1.071 [27.2]	0.547 [13.9]
RSC4-Series	1.126 [28.6]	0.476 [12.1]

Actuator Options




 Bi-Color



Flat

 Illumination Options



Full

Terminal Options

6.3mm Tab
(Small Hole)6.3mm Tab
(Large Hole)

4.8mm Tab



Solder

Solder
(Low Clearance)

FEATURES:

- Excellent Quality and Reliability
- 4 Bodies to Cover Many Popular Cutouts
- High Current Capacity
- Illuminated and Bi-Color Actuators

SPECIFICATIONS:

RATING: RATING OPTION D:

20A 125VAC [UL, CSA]
16A 250VAC [UL, CSA]
1/4HP 125VAC [UL]
3/4HP 250VAC [UL]

RATING OPTION C:

15A 125VAC [UL, CSA]



TEMPERATURE: -20°C to 65°C [UL, CSA]
-20°C to 105°C [UL, CSA]

ELECTRICAL LIFE: 10,000 Cycles

CONTACT RESISTANCE: 20mΩ Max. at 1A 5VDC

INSULATION RESISTANCE: 100MΩ Min. at 500VDC

DIELECTRIC STRENGTH: 1,000VAC for 1 Minute

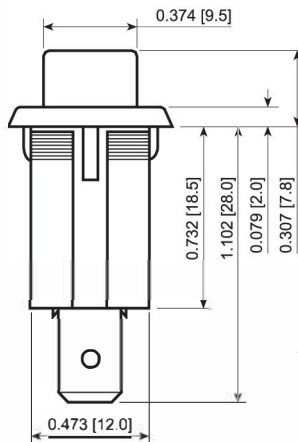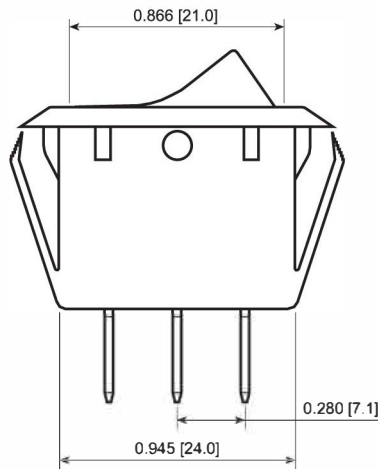

RSC341D1123



RSC241D2200



RSC141D1021-116

RSC141D1A24

RSC241D125Z11

Series	Terminal	Function	Rating	Body Color	Actuator Color	Marking Color	Marking Type	Lens Style	Lens Color	Lamp Voltage

Note:
* = Option Available with Illumination

Custom Colors and Markings Available Upon Request For Illuminated Switches Only

EXAMPLE PART NUMBERS:

RSC141D1000-126 1P Off-On
Black Body, Amber Illum. Actuator, 125V

RSC141D1100 1P Off-On
Black Body/Actuator, No Marking

RSC141D1121 1P Off-On
Black Body/Actuator, I/O Vert.

RSC141D2200 1P Off-On
White Body/Actuator, No Marking



E-SWITCH®

www.e-switch.com

800.867.2717

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[RSC14001000-117](#) [RSC191D1021-137](#) [RSC241D1100](#) [RSC241C1021-147](#) [RSC241D1021-147](#) [RSC241D2011-105](#) [RSC141D1A8R](#) [RSC141C1000-127](#) [RSC141C1123](#) [RSC1C1D1123](#) [RSC191D102Z33-116](#) [RSC441D1000-146](#)