

RVW SERIES ROCKER SWITCH


ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS



APPLICATIONS / MARKETS



Floor Care Appliances

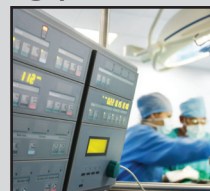

Medical Equipment



Electrical Houseware



Commercial Appliances



Home Appliances



Industrial Controls

RoHS

SPECIFICATIONS

Rating:

Maintained Switches:

20A 125VAC [cURus UL508]

15A 277VAC [cURus UL508]

2HP 110/250VAC [cURus UL508]

Momentary Switches:

20A 125VAC [cURus UL508]

15A 277VAC [cURus UL508]

1.5HP 110/250VAC [cURus UL508]

Operating Temperature: 0°C to 55°C

Electrical Life: 6,000 cycles

Contact Resistance: 50 mΩ Max.

Insulation Resistance: 800 MΩ Min. at 500VDC

Dielectric Strength: 1,500VAC for 1 minute

Ingress Protection: IP54 Standard

FEATURES & BENEFITS

- Up to 20A, 125VAC 2HP rating
- 37.5mm x 21mm panel cutout
- IP54 rated
- Agency Approvals: cURus
- SP or DP Options
- 2 or 3 position Circuit Functions

PART NUMBER CONFIGURATOR

Series	Terminal	Function	Rating	Body Color	Actuator Color	Marking Color	Marking Type
RVW - Matte Finish	1 - 4.8mm Tabs	1 - 1 Pole Off-On	D - 20A 125VAC	1 - Black	1 - Black	0 - None	0 - None
RVWG - Glossy Finish	4 - 6.3mm Tabs	2 - 2 Pole Off-On		2 - White	2 - White	1 - Black	1 - I/O Vertical
	5 - Solder	3 - 1 Pole On-On		3 - Almond	3 - Almond	2 - White	2 - On-Off-On Vertical
	6 - Screw	4 - 1 Pole Off-(On)		4 - Grey	4 - Grey	8 - Red	3 - ON-OFF Vertical
		5 - 1 Pole On-Off-On		5 - Orange	5 - Orange		4 - On-Off Horizontal
		6 - 2 Pole On-Off-On		7 - Blue	7 - Blue		9 - I/O/II Horizontal
		A - 1 Pole On-(Off)		8 - Green	8 - Green		R - I/O Horizontal
		B - 1 Pole On-(On)		9 - Red	9 - Red		S - I/O/II Vertical
		C - 1 Pole On-Off-(On)					
		D - 1 Pole (On)- Off- (On)					
		E - 2 Pole Off-(On)					
		F - 2 Pole On-(Off)					
		G - 2 Pole On-On					
		H - 2 Pole On-(On)					
		J - 2 Pole On-Off-(On)					
		K - 2 Pole (On)-Off-(On)					

NOTE:

Custom Colors and Markings Available Upon Request.

Specifications subject to change without notice 7.3.2018



E-SWITCH®


www.e-switch.com

800.867.2717


1

RVW SERIES ROCKER SWITCH

TERMINAL OPTIONS

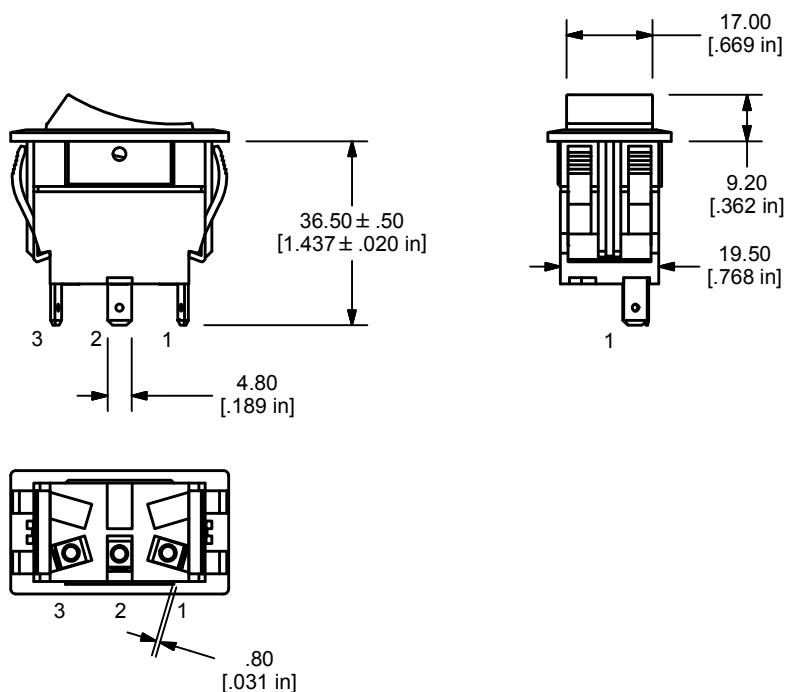

**SINGLE POLE SHOWN WITH
4.8MM TABS**

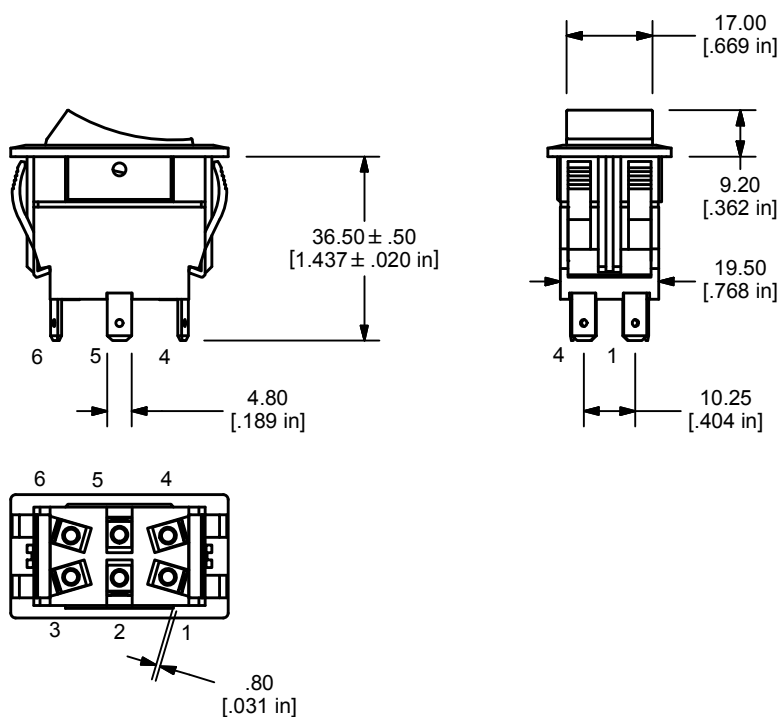

**DOUBLE POLE SHOWN WITH
4.8MM TABS**



E-SWITCH®


www.e-switch.com

800.867.2717


3

RVW SERIES ROCKER SWITCH

TERMINAL OPTIONS

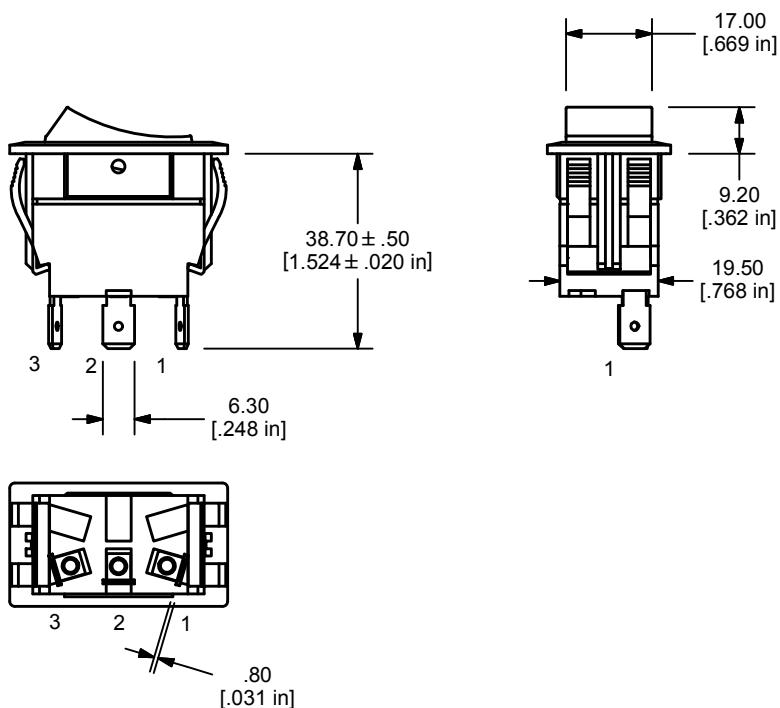

**SINGLE POLE SHOWN WITH
6.3 TAB TABS**

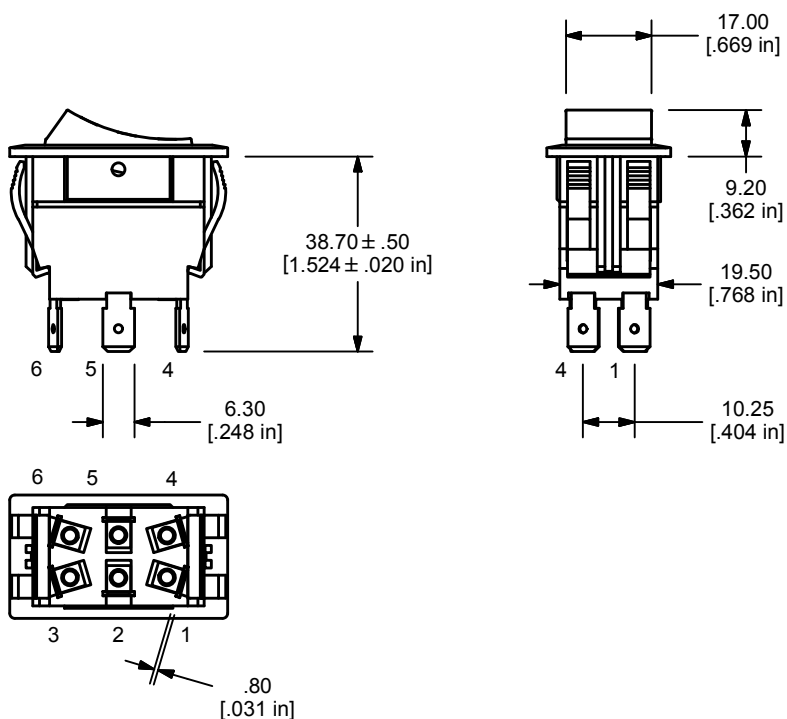

**DOUBLE POLE SHOWN WITH
6.3MM TABS**



E-SWITCH®

www.e-switch.com


800.867.2717

4


ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS

RVW SERIES ROCKER SWITCH

TERMINAL OPTIONS

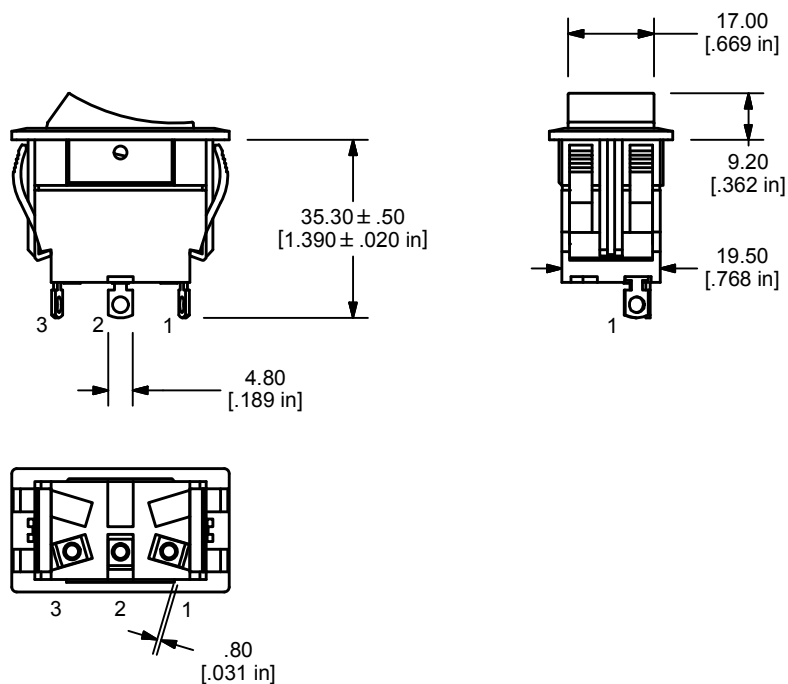

SINGLE POLE SHOWN WITH
SOLDER TERMINALS

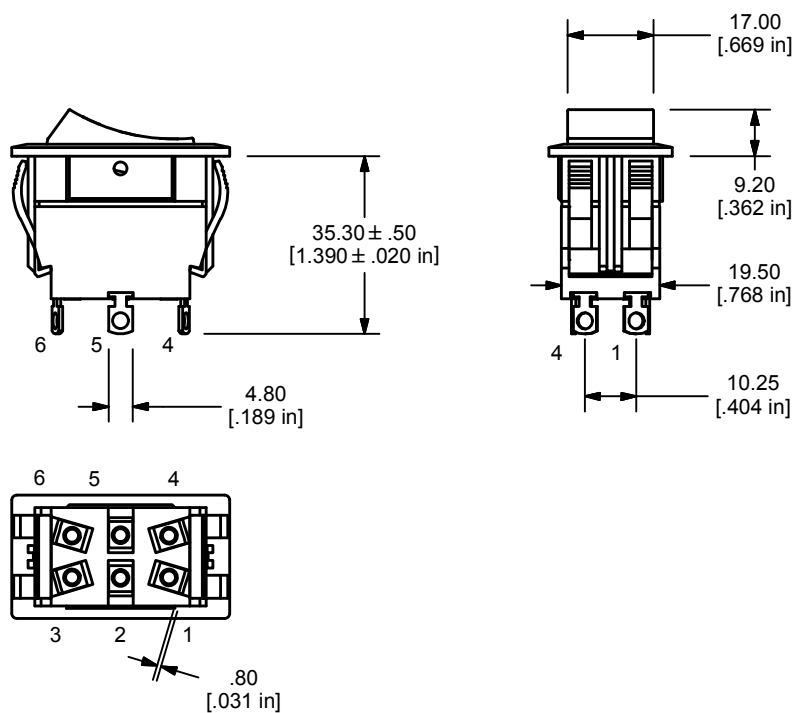

DOUBLE POLE SHOWN WITH
SOLDER TERMINALS



E-SWITCH®


www.e-switch.com

800.867.2717


5

RVW SERIES ROCKER SWITCH

TERMINAL OPTIONS

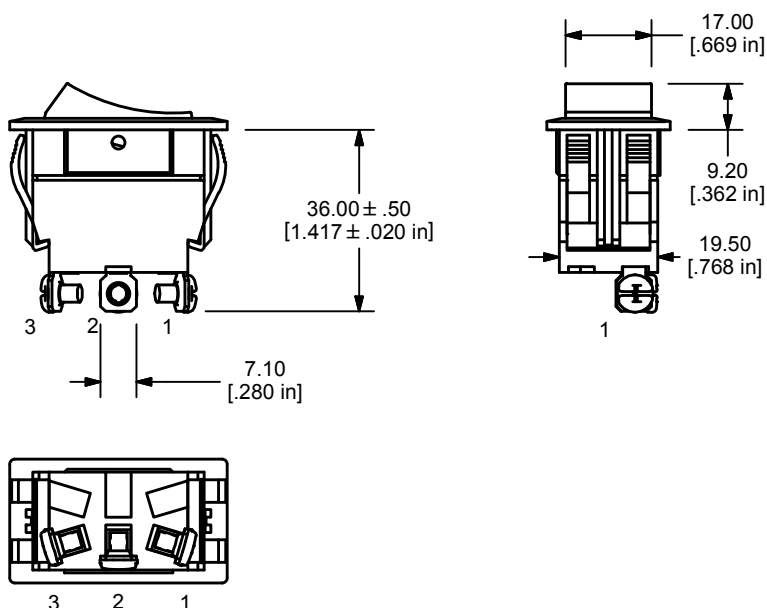

SINGLE POLE SHOWN WITH
SCREW TERMINALS

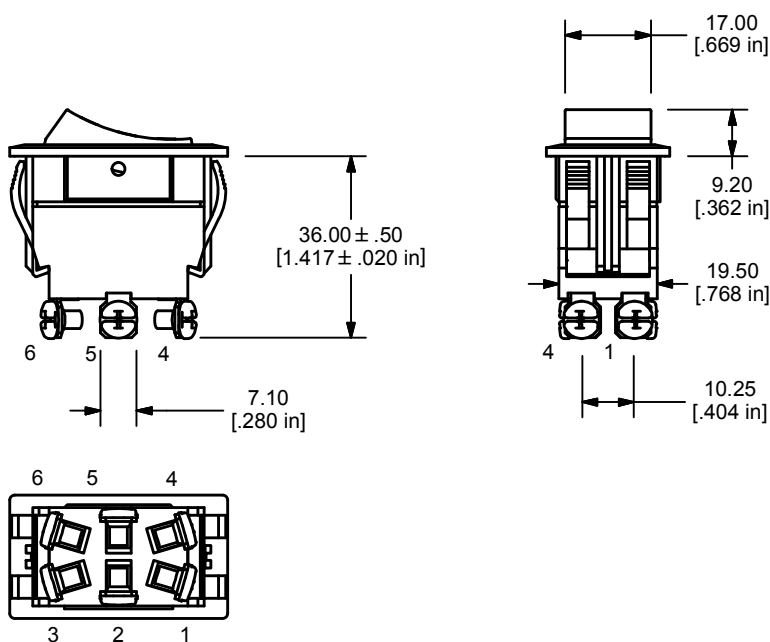

DOUBLE POLE SHOWN WITH
SCREW TERMINALS



E-SWITCH®

www.e-switch.com


800.867.2717

6


ANTI-VANDAL
SWITCHES
DETECTOR
SWITCHES
DIP
SWITCHES
KEYLOCK
SWITCHES
NAVIGATION
SWITCHES
PUSHBUTTON
SWITCHES
ROCKER
SWITCHES
ROTARY
SWITCHES
SLIDE
SWITCHES
SNAP ACTION
SWITCHES
TACTILE
SWITCHES
TOGGLE
SWITCHES
CAP
OPTIONS

RVW SERIES ROCKER SWITCH


MARKING OPTIONS

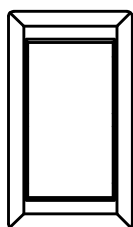


"0"
NONE

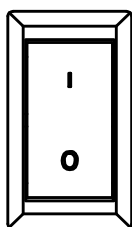


"1"
I/O
Vertical

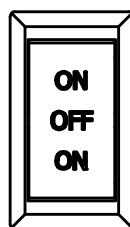


"2"
On-Off-On
Vertical

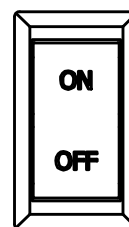


"3"
ON-OFF
Vertical

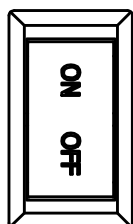


"4"
On-Off
Horizontal

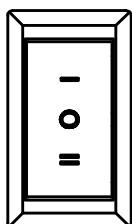

"9"
I/O/II
Horizontal




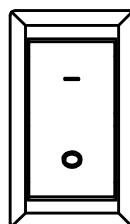


"R"
I/O
Horizontal

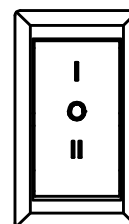


"S"
I/O/II
Vertical

SCHEMATICS

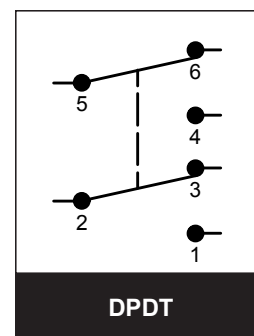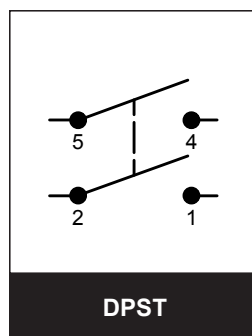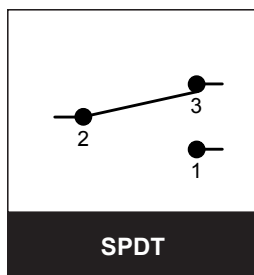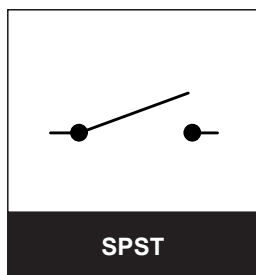

PANEL CUTOUT

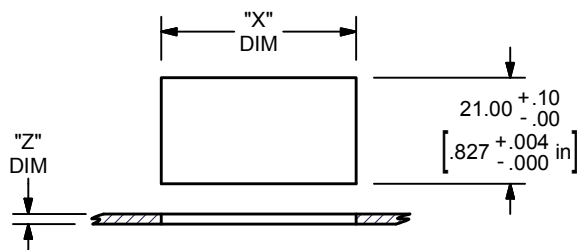

PANEL THICKNESS "Z"	"X" DIM
2.50 - 3.50 [0.98 - 0.138]	37.00 ^{+.10} / _{-.00} [1.457 ^{+.004} / _{-.000} in]
3.50 - 4.50 [0.138 - 0.177]	37.50 ^{+.10} / _{-.00} [1.476 ^{+.004} / _{-.000} in]



E-SWITCH®

www.e-switch.com

800.867.2717

7

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[RVW41D1123](#) [RVW41D192R](#) [RVW44D1100-116](#) [RVW45D112S](#) [RVW46D112S](#) [RVW46D1200](#) [RVW4KD1122](#)
[RVW42D1124](#) [RVW4JD1122](#) [RVW46D1122](#) [RVW46D2200](#)