

TACT
SWITCHESNAVIGATION
SWITCHESPUSHBUTTON
SWITCHESTOGGLE
SWITCHESROCKER
SWITCHESSLIDE
SWITCHESSNAP-ACTION
SWITCHESDIP
SWITCHESKEYLOCK
SWITCHESROTARY
SWITCHESDETECTOR
SWITCHESCAP
OPTIONS

SERIES TL 1260 SWITCHES

TACT SWITCHES - ILLUMINATED RIGHT ANGLE



FEATURES & BENEFITS

- ▶ Illuminated
- ▶ Right angle thru-hole tact switch
- ▶ Multiple colors available

APPLICATIONS/MARKETS

- ▶ Telecommunications
- ▶ Consumer Electronics
- ▶ Audio/visual
- ▶ Medical
- ▶ Testing/instrumentation
- ▶ Computer/servers/peripherals

SPECIFICATIONS


Contact Rating:	50mA @ 12 VDC
Life Expectancy:	50,000 cycles
Contact Resistance:	100mΩ
Insulation Resistance:	100MΩ
Dielectric Strength:	500 VAC
Actuation Force:	160 gf ± 50 gf
Operating Temperature:	-20°C to 70°C
Travel:	0.20 ±.01mm

MATERIALS

Actuator:	PBT
Housing:	POM
Terminals:	Brass, silver plated
Moving Contact:	Stainless Steel, silver plated
Button:	Nylon



HOW TO ORDER


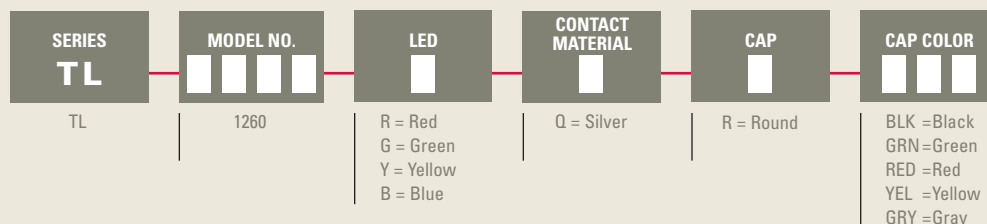


Example Ordering Number


TL-1260-G-Q-R-BLK

Specifications subject to change without notice.

TL 1260

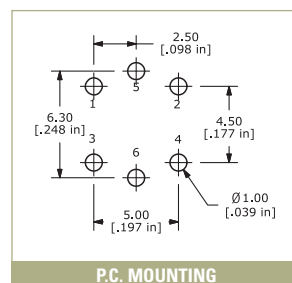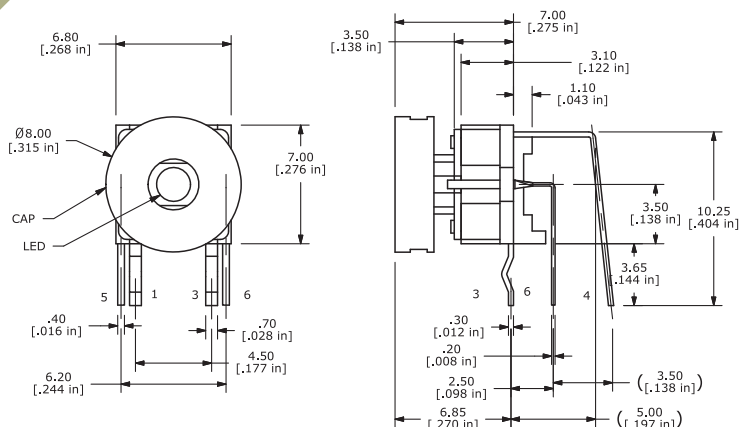

P.C. MOUNTING

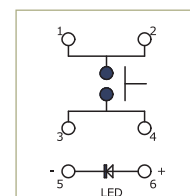

SCHEMATIC

LED Specifications	Units	Blue	Green	Red	Yellow
Forward Current	mA	30	30	30	30
Forward Voltage	V	3.5-4.0	2.0-2.5	3.3-3.8	2.0-2.5
Luminous Intensity @ 20mA	mcd	230	120	50	200

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[TL1260RQRGRY](#) [TL1260BQRBLK](#) [TL1260GQNOCAP](#) [TL1260GQRBLK](#) [TL1260GQRGRY](#) [TL1260QRYEL](#)
[TL1260GYQRBLK](#) [TL1260RQRBLK](#) [TL1260YQRBLK](#) [TL1260YQRGRY](#) [TL1260YQRYEL](#) [TL1260BQSCLR](#)
[TL1260GYRHCLR](#) [TL1260BRHCLR](#) [TL1260GQSCLR](#) [TL1260GQRGRN](#) [TL1260GQSBLK-PWRVERT](#)
[TL1260GYQC1GRY-PWRVERT](#) [TL1260GYQSGRY-PWRVERT](#)