


TL3300 SERIES TACT SWITCH

APPLICATIONS / MARKETS

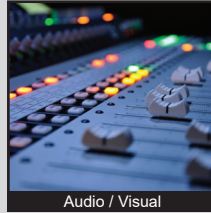

Audio / Visual



Computer Peripherals



Consumer Electronics



Instrumentation



Medical Equipment



Telecommunication

RoHS

SPECIFICATIONS

Electrical Rating: 50mA, 12VDC
Life Expectancy: up to 200,000 Cycles
Contact Resistance: 100mΩ Max.
Insulation Resistance: 100MΩ Min. at 500VDC
Dielectric Strength: 250VAC for 1 Minute
Operating Temperature: -25°C to 70°C
Operating Force: 160gf (200,000 cycles)
260gf (100,000 cycles)
320gf, 520gf (50,000 cycles)
Travel: 0.35mm
Function: SPST, Off-(On), Momentary

FEATURES & BENEFITS

- Up to 200,000 cycle life expectancy
- Multiple actuator options
- Multiple force options

PART NUMBER CONFIGURATOR

Series	Circuit	Actuator "L"	Operating Force	Plating
TL	3300 - Off-(On)	A - 7.3mm (Knob: 3.8mm Sq.)
C - 8.5mm
D - 4.3mm	F160 - 160 gf
F260 - 260 gf
F320 - 320 gf
F520 - 520 gf	Q - Silver

Specifications subject to change without notice 2.19.2019



E-SWITCH®







www.e-switch.com

800.867.2717

1







TL3300 SERIES TACT SWITCH

BODY DIMENSIONS ACTUATOR OPTION A

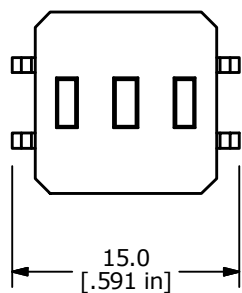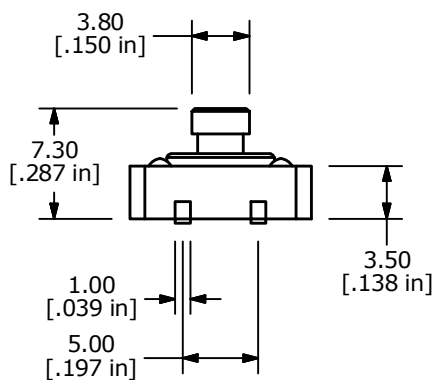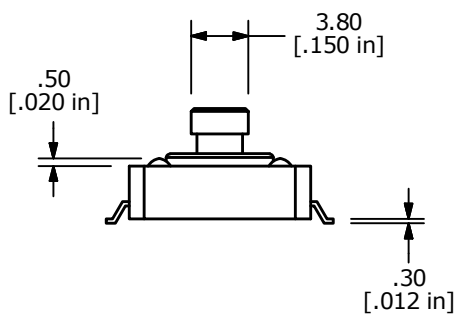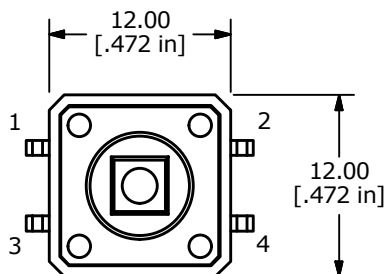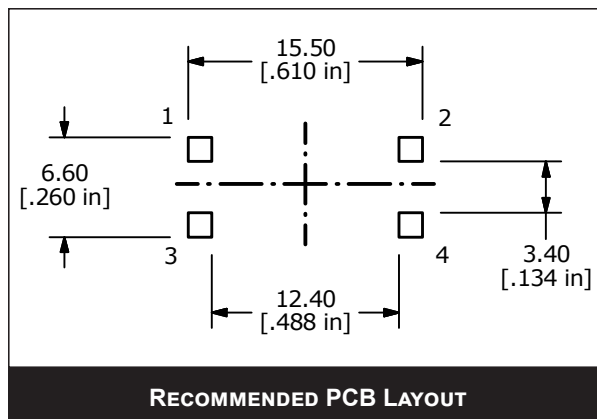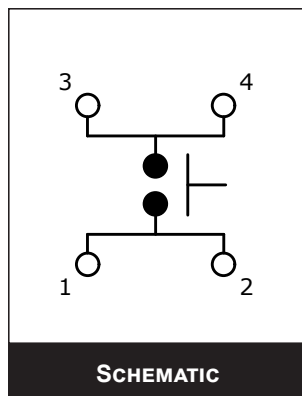

TL3300 SERIES TACT SWITCH

BODY DIMENSIONS ACTUATOR OPTION C

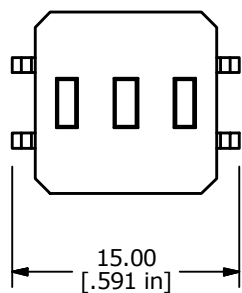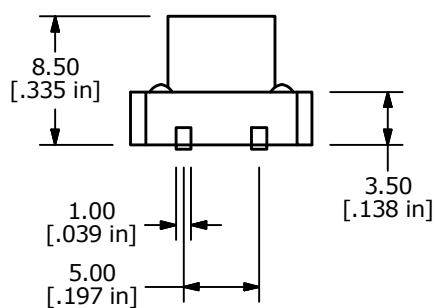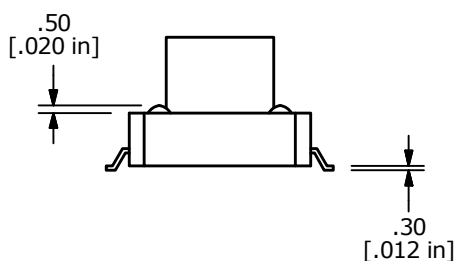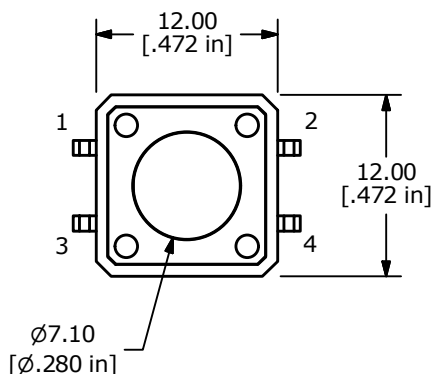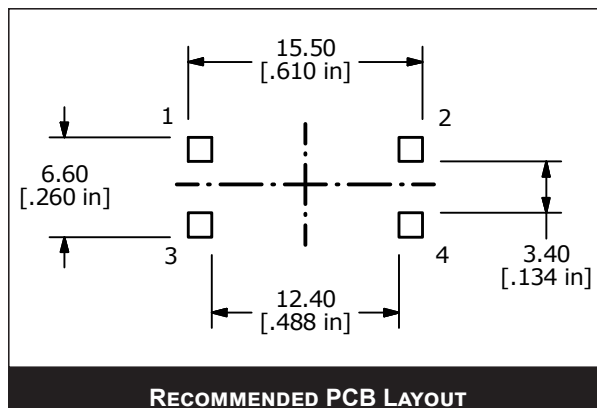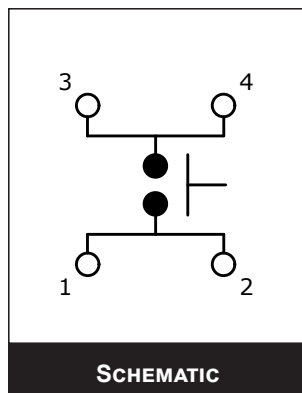

E-SWITCH®







www.e-switch.com

800.867.2717

3

TL3300 SERIES TACT SWITCH

BODY DIMENSIONS ACTUATOR OPTION D

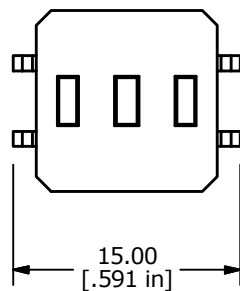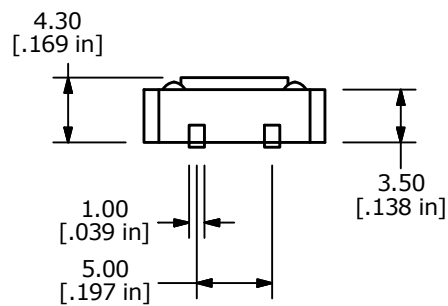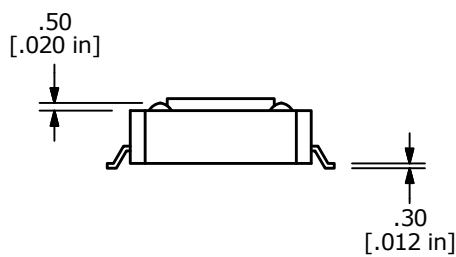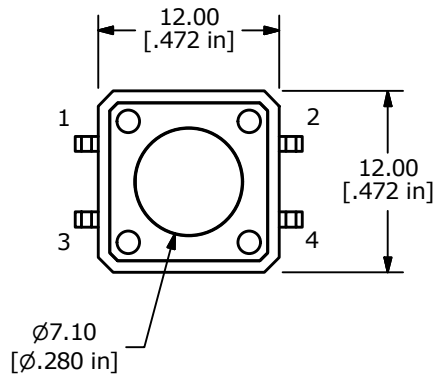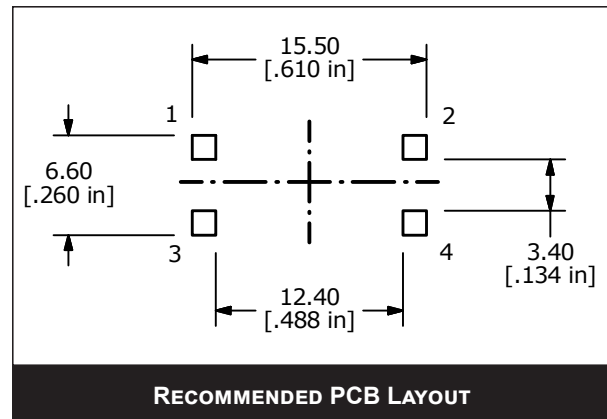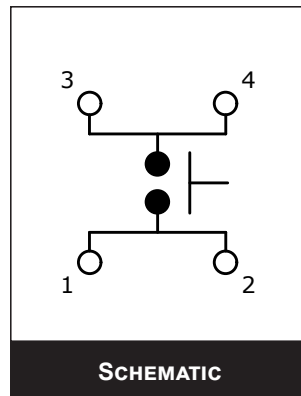

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[TL3300AF160Q](#) [TL3300AF160QSSDOME](#) [TL3300AF260Q](#) [TL3300CF160Q](#) [TL3300CF260Q](#) [TL3300DF160Q](#)
[TL3300DF260Q](#) [TL3300DF320Q](#) [TL3300DF160QSPECIAL](#) [TL3300RBLK](#) [TL3300RWHT](#) [TL3300SBLK](#)
[TL3300SRED](#) [TL3300SWHT](#)