


TL4110 SERIES TACT SWITCH

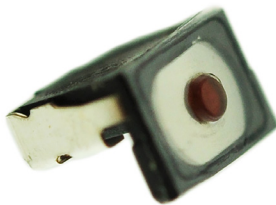

APPLICATIONS / MARKETS



Wearable Electronics



Internet of Things



Handheld Devices



Medical / Dental



Smart Home



Telecommunication

RoHS

SPECIFICATIONS

Contact Rating: 20mA @ 15VDC
Electrical Life: 300,000 gf
Contact Resistance: 500mΩ Max
Insulation Resistance: 50MΩ Min @ 100VDC
Dielectric Strength: 250VAC for 1 Minute
Operating Temperature: -40°C to 85°C
Storage Temperature: -40°C to 85°C
Travel: 0.13mm
Contact Arrangement: SPST
Actuation Force: 160gf

FEATURES & BENEFITS

- Surface Mount Switch
- Long Cycle Life of 300,000 Cycles
- Extremely Small Surface profile of 2.0mm x 2.8mm
- Switch Mounts along the edge of the PCB for Right Angle Actuation
- 160 gram force

PART NUMBER CONFIGURATOR

Series



TL4110

Actuator



A - 0.65mm

Actuation Force



F160 - 160 gf

Contact Material



Q - Silver

Specifications subject to change without notice



E-SWITCH®






www.e-switch.com

800.867.2717

1

ANTI-VANDAL SWITCHES	DETECTOR SWITCHES	DIP SWITCHES	KEYLOCK SWITCHES	NAVIGATION SWITCHES	PUSHBUTTON SWITCHES	ROCKER SWITCHES	ROTARY SWITCHES	SLIDE SWITCHES	SNAP ACTION SWITCHES	TACTILE SWITCHES	TOGGLE SWITCHES	CAP OPTIONS
----------------------	-------------------	--------------	------------------	---------------------	---------------------	-----------------	-----------------	----------------	----------------------	------------------	-----------------	-------------

SCHEMATIC

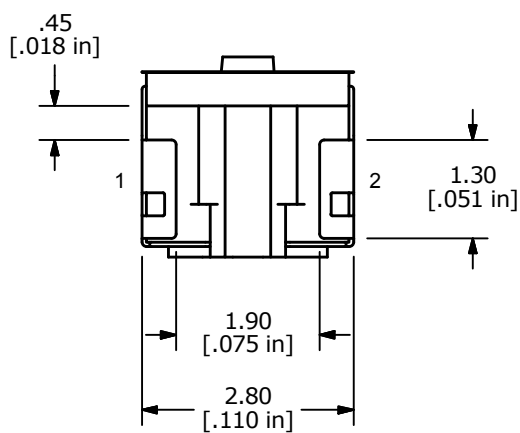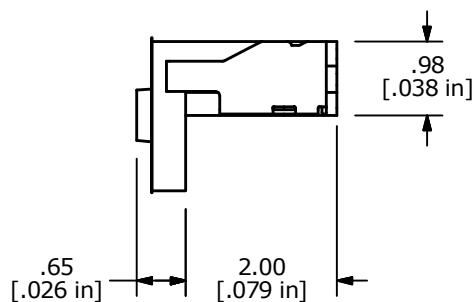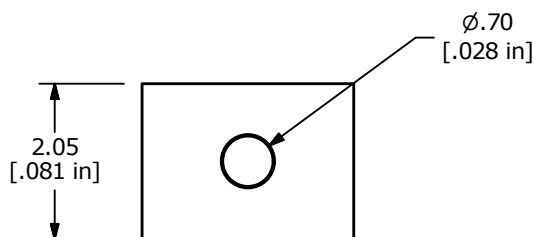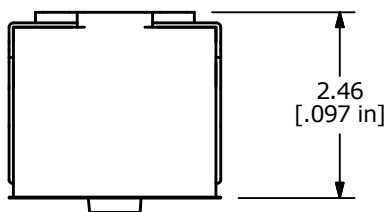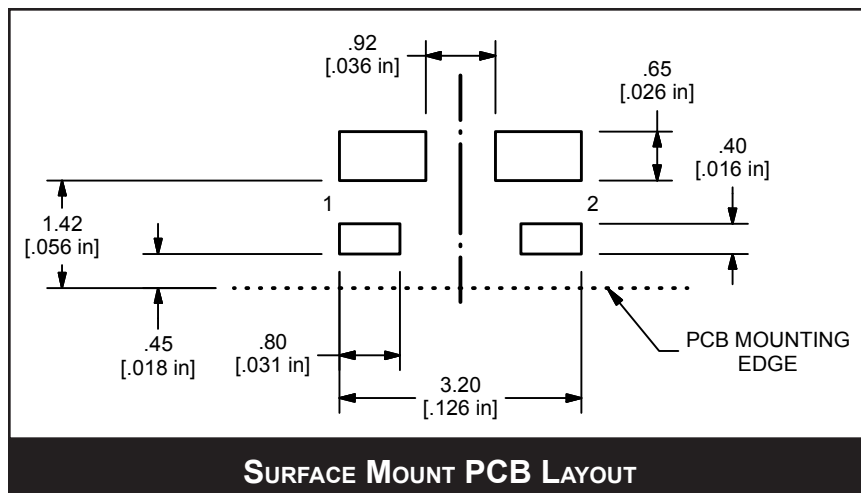

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[E-Switch:](#)

[TL4110AF160Q](#)