


ULV7 SERIES ANTI-VANDAL SWITCH

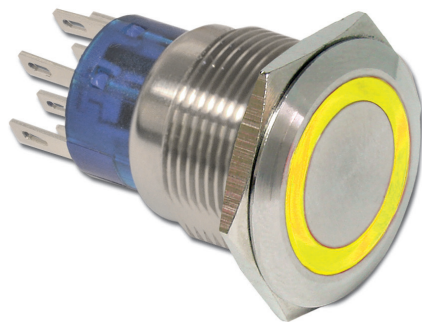

APPLICATIONS / MARKETS



Commercial Appliances



Security Devices



Industrial Controls



Kiosks



Electrical Housewares



Medical Equipment



RoHS

SPECIFICATIONS

Electrical Rating: 3A, 125/250VAC
Mechanical Life: 1,000,000 cycles (momentary); 500,000 cycles (latching)
Electrical Life: 50,000 Cycles
Contact Resistance: 50mΩ Max. at 1A 12VDC
Insulation Resistance: 1,000MΩ min. @ 500 VDC
Dielectric Strength: 2,000V RMS at sea level
Operating/Storage Temperature: -20°C to 55°C
Travel: 3.2mm
Moisture Protection: IP67
Contact Arrangement: SPDT or DPDT
Actuation Force: SPDT: 2.5N; DPDT: 3.5N,
 Molded Back: SPDT & DPDT: 5.5N
Panel Thickness: 1-10mm
Hex Nut Torque: 5-14Nm
Mechanical Impact Protection: IK10 (Stainless)
Agency Approvals: cURus

FEATURES & BENEFITS

- 22mm diameter panel cutout
- Ring or Ring/Power symbol illumination
- Multiple switch functions available
- Multiple illumination voltage options
- IP67 rated
- SPDT or DPDT
- UL Certified
- Custom graphics available
- Soldered wire leads (300mm long) optional
- Detachable socket w/ wire leads (500mm long) optional
- Molded back w/ wire leads (500mm long) optional

PART NUMBER CONFIGURATOR

Series	Actuator	Terminal	Function	Body Finish	Actuator Finish	Contact Material	Lens Style	LED Color	Illumination Voltage	Graphic Options
ULV7	F - Flat	2 - Solder Lug	3 - 1P ON-ON	S - Stainless Steel	S - Stainless Steel	None - Silver	3 - Ring Illumination, movable with actuator	0 - White	1 - 3V	L17 - Bluetooth
		W - Wire Leads 300mm long	B - 1P ON-(ON)*	1 - Black Anodized	1 - Black Anodized	G - Gold	6 - Ring / Power Symbol Illumination, movable with actuator (Stainless Steel only)	1 - Red	3 - 6V	L18 - Wifi
		P - Detachable Socket w/ Wire Leads 500mm long	H - 2P ON-(ON)*		L - Silver for Graphic		L - Graphic Illumination (Only Available with L Actuator Finish)	2 - Orange	4 - 12V	L20 - START
		M - Molded Back w/ Wire Leads 500mm long						3 - Green	5 - 24V	L21 - OFF
								4 - Blue	6 - 110V	L22 - ON
								5 - Yellow	7 - 220V	L35 - STOP
								F - Red / Orange		
								G - Red / Green		
								H - Red / Blue		
								J - Red / Yellow		
								K - Orange / Green		
								N - Blue / Green		
								P - Green / Yellow		
								Q - Blue / Yellow		

NOTES:

*() denotes function is momentary
 Call us for custom graphic options 800-867-2717

Specifications subject to change without notice 12.16.2021



E-SWITCH®


www.e-switch.com

800.867.2717


1

ULV7 SERIES ANTI-VANDAL SWITCH

BODY DIMENSIONS - SPDT

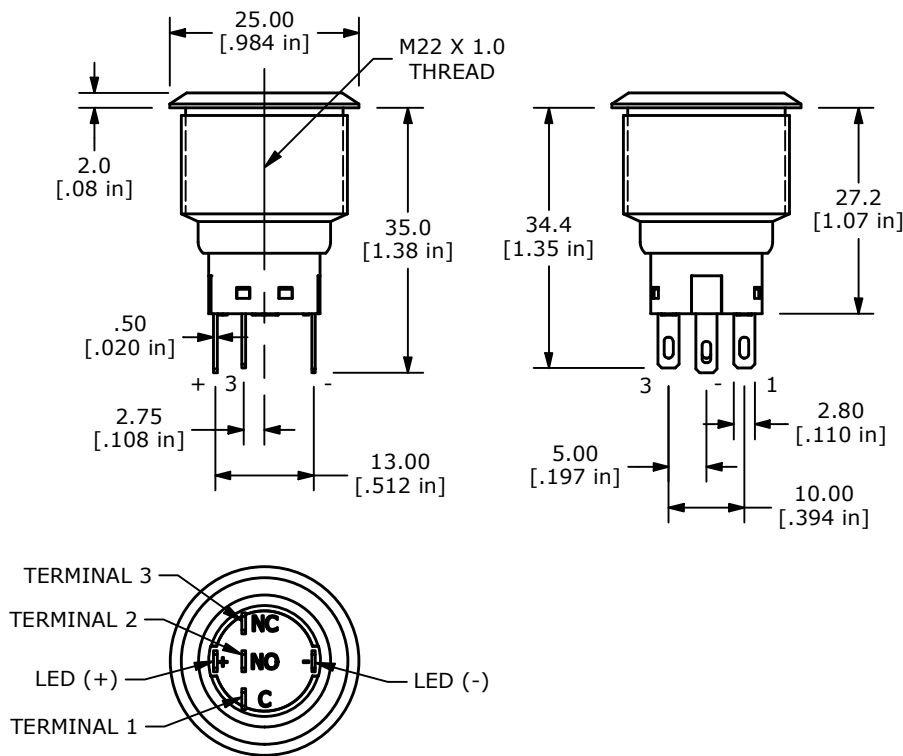



SPDT SWITCH DIMENSIONS

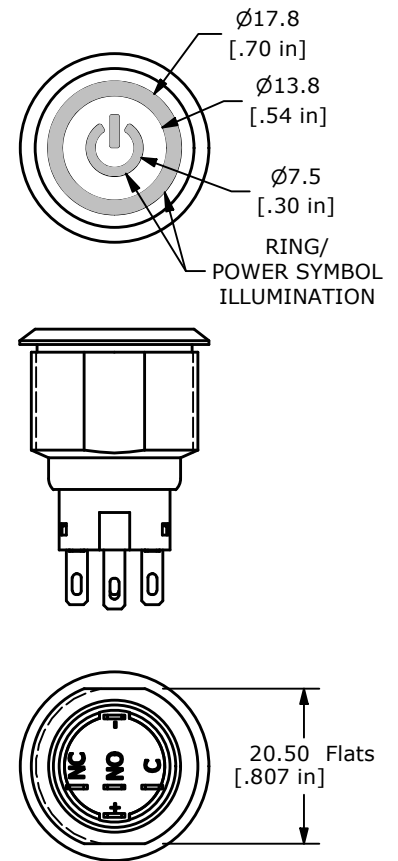

HOUSING WITH FLATS (SPDT OR DPDT) USED ON SWITCHES WITH RING/POWER SYMBOL OR OTHER CUSTOM GRAPHICS (SPDT SHOWN)


(SEE STANDARD SPDT OR DPDT DIMENSIONAL LAYOUT FOR OTHER DIMENSIONS)

GRAPHIC OPTIONS

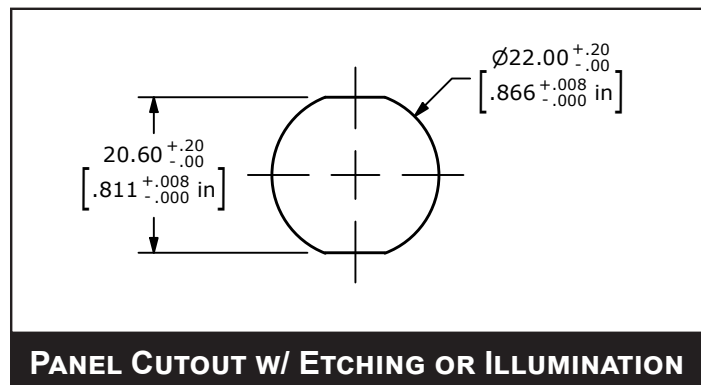
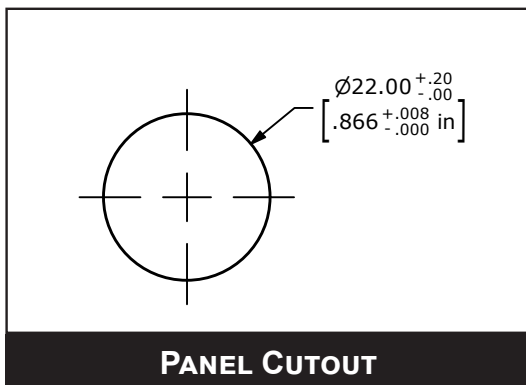


ULV7 SERIES ANTI-VANDAL SWITCH

BODY DIMENSIONS - DPDT

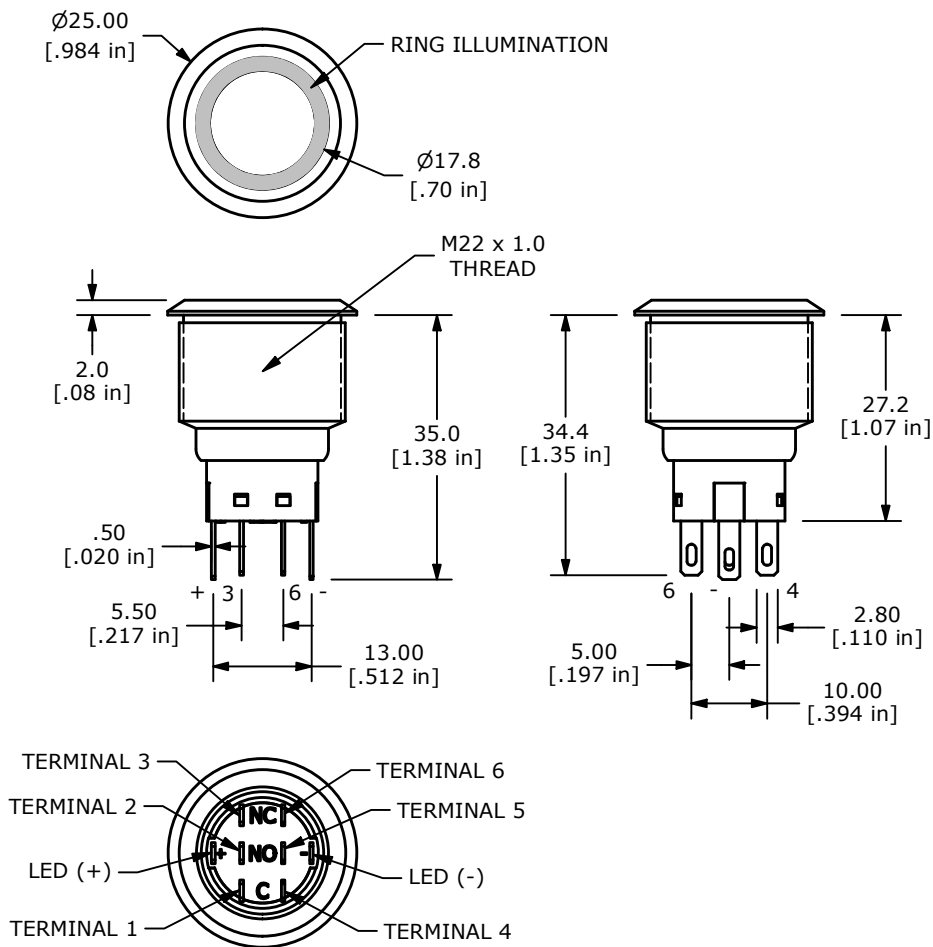

DPDT Switch Dimensions

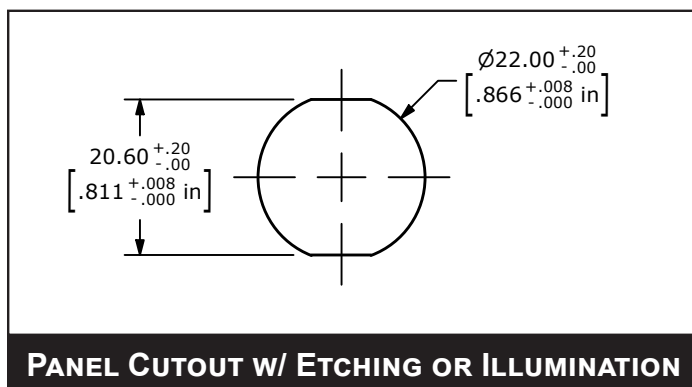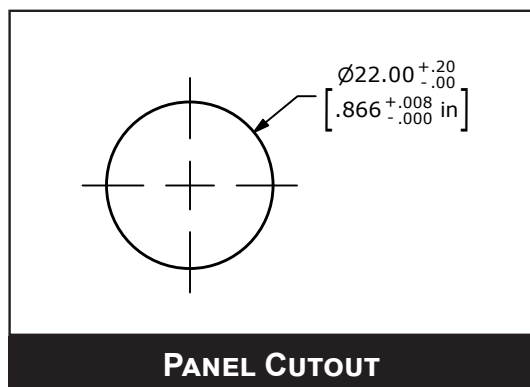

E-SWITCH®



www.e-switch.com

800.867.2717


3

ULV7 SERIES ANTI-VANDAL SWITCH


SCHEMATICS

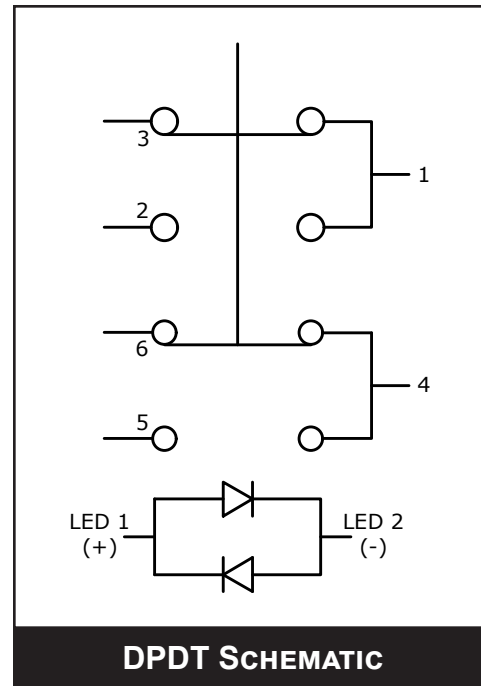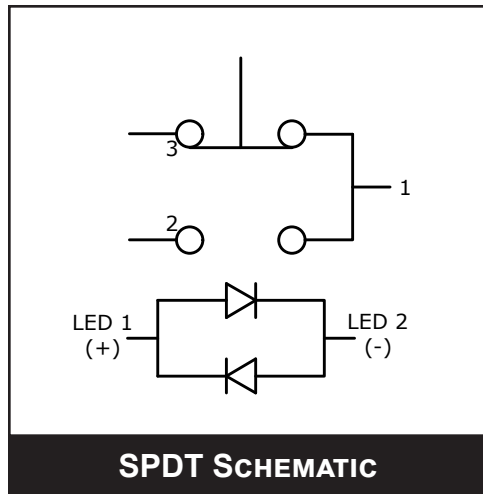

ACTUATOR OPTIONS

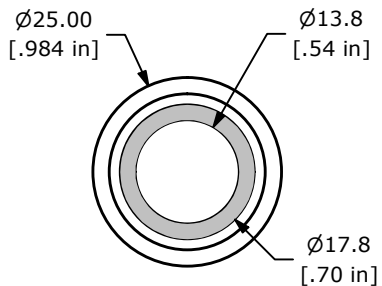

RING ILLUMINATED

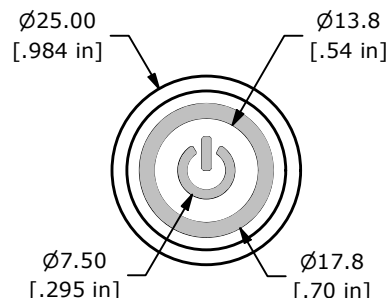

RING / POWER SYMBOL ILLUMINATED



E-SWITCH®

www.e-switch.com

800.867.2717

4

ANTI-VANDAL
SWITCHES

DETECTOR
SWITCHES

DIP
SWITCHES

KEYLOCK
SWITCHES

NAVIGATION
SWITCHES

PUSHBUTTON
SWITCHES

ROCKER
SWITCHES

ROTARY
SWITCHES

SLIDE
SWITCHES

SNAP ACTION
SWITCHES

TACTILE
SWITCHES

TOGGLE
SWITCHES

CAP
OPTIONS


ULV7 SERIES ANTI-VANDAL SWITCH

WIRE OPTIONS

W - Wire Leads
300mm long

SWITCH	WIRE	LENGTH
SW1-1	WIRE, 24AWG AWM UL1015, BLUE	300.0 [11.8 in]
SW1-2	WIRE, 24AWG AWM UL1015, PURPLE	300.0 [11.8 in]
SW1-3	WIRE, 24AWG AWM UL1015, GREEN	300.0 [11.8 in]
SW1-4	WIRE, 24AWG AWM UL1015, WHITE	300.0 [11.8 in]
SW1-5	WIRE, 24AWG AWM UL1015, ORANGE	300.0 [11.8 in]
SW1-6	WIRE, 24AWG AWM UL1015, YELLOW	300.0 [11.8 in]
SW1- (-)	WIRE, 24AWG AWM UL1015, BLACK	300.0 [11.8 in]
SW1- (+)	WIRE, 24AWG AWM UL1015, RED	300.0 [11.8 in]


** WIRE LEADS PROVIDED ARE DEPENDENT ON THE FUNCTION SELECTED **

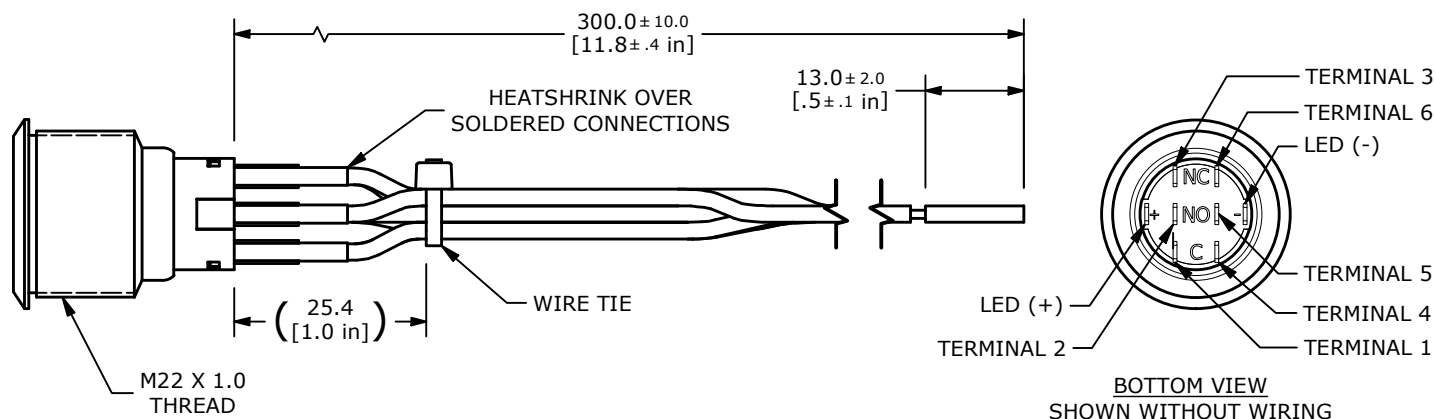

M - Molded Back
w/ Wire Leads
500mm long

SWITCH	WIRE	LENGTH
SW1-1	WIRE, 18 AWG AWM UL3385, YELLOW	500.0 [19.7 in]
SW1-2	WIRE, 18 AWG AWM UL3385, PURPLE	500.0 [19.7 in]
SW1-3	WIRE, 18 AWG AWM UL3385, GREEN	500.0 [19.7 in]
SW1-4	WIRE, 18 AWG AWM UL3385, YELLOW	500.0 [19.7 in]
SW1-5	WIRE, 18 AWG AWM UL3385, PURPLE	500.0 [19.7 in]
SW1-6	WIRE, 18 AWG AWM UL3385, GREEN	500.0 [19.7 in]
SW1- (-)	WIRE, 18 AWG AWM UL3385, BLACK	500.0 [19.7 in]
SW1- (+)	WIRE, 18 AWG AWM UL3385, RED	500.0 [19.7 in]

** WIRE LEADS PROVIDED ARE DEPENDENT ON THE FUNCTION SELECTED **

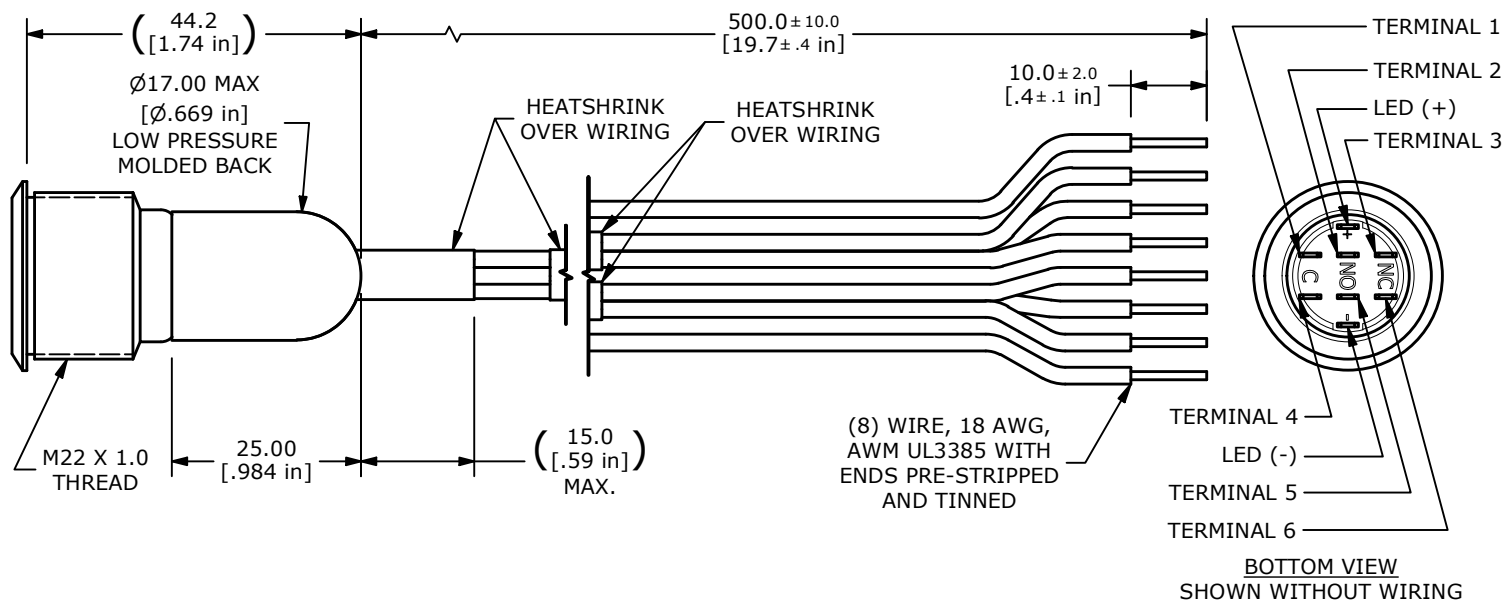

E-SWITCH®

www.e-switch.com

800.867.2717

5


ULV7 SERIES ANTI-VANDAL SWITCH

WIRE OPTIONS

P - Detachable Socket
w/ Wire Leads
500mm long

SWITCH	WIRE	LENGTH
SW1-1	WIRE, 18 AWG AWM UL3385, GREEN	500.0 [19.7 in]
SW1-2	WIRE, 18 AWG AWM UL3385, PURPLE	500.0 [19.7 in]
SW1-3	WIRE, 18 AWG AWM UL3385, YELLOW	500.0 [19.7 in]
SW1-4	WIRE, 18 AWG AWM UL3385, GREEN	500.0 [19.7 in]
SW1-5	WIRE, 18 AWG AWM UL3385, PURPLE	500.0 [19.7 in]
SW1-6	WIRE, 18 AWG AWM UL3385, YELLOW	500.0 [19.7 in]
SW1- (-)	WIRE, 18 AWG AWM UL3385, BLACK	500.0 [19.7 in]
SW1- (+)	WIRE, 18 AWG AWM UL3385, RED	500.0 [19.7 in]

** WIRE LEADS PROVIDED ARE DEPENDENT ON THE FUNCTION SELECTED **

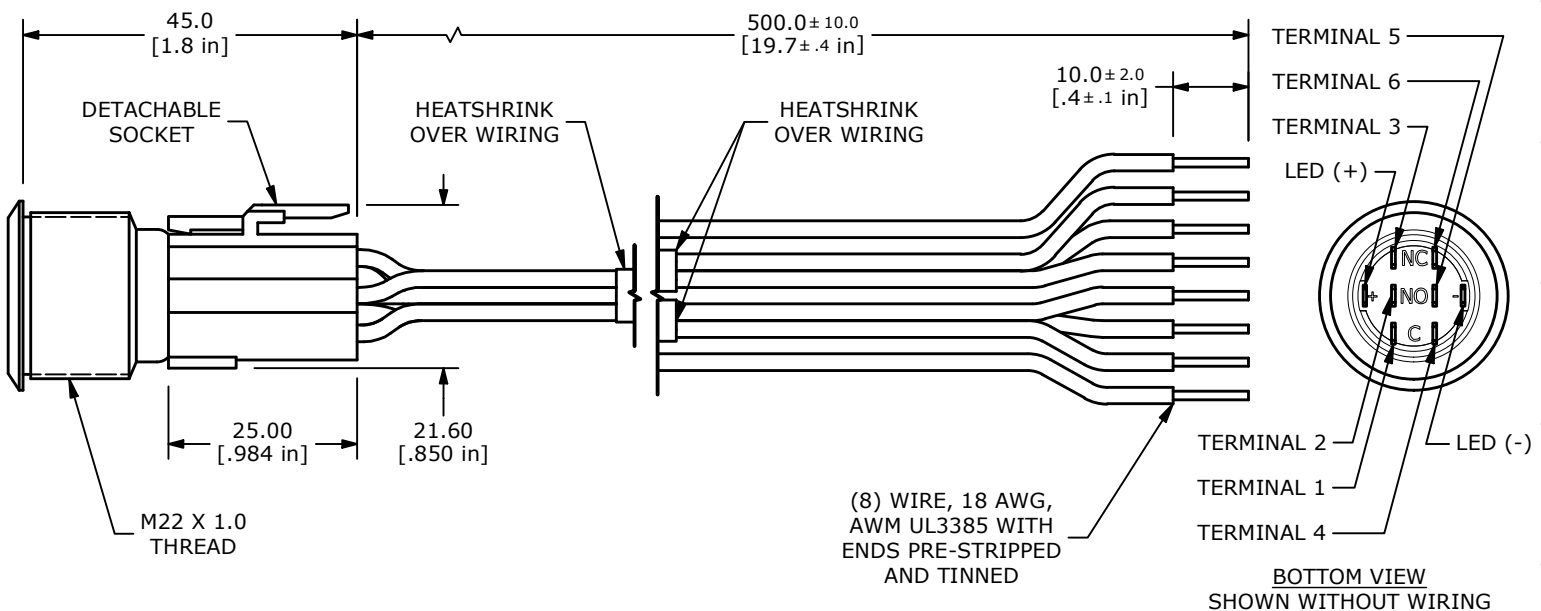

E-SWITCH®

www.e-switch.com

800.867.2717

6

ANTI-VANDAL
SWITCHES

DETECTOR
SWITCHES

DIP
SWITCHES

KEYLOCK
SWITCHES

NAVIGATION
SWITCHES

PUSHBUTTON
SWITCHES

ROCKER
SWITCHES

ROTARY
SWITCHES

SLIDE
SWITCHES

SNAP ACTION
SWITCHES

TACTILE
SWITCHES
















TOGGLE
SWITCHES

CAP
OPTIONS

ULV7 SERIES ANTI-VANDAL SWITCH

GRAPHIC OPTIONS

** REFER TO BODY DIMENSION PAGES 2 & 3 FOR GRAPHIC ORIENTATION **

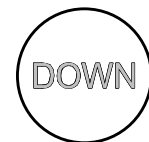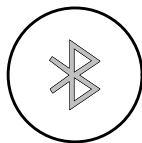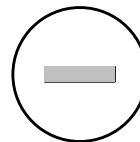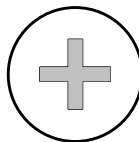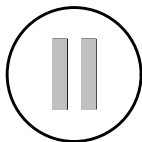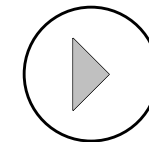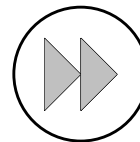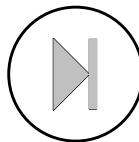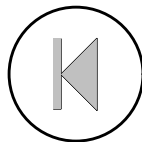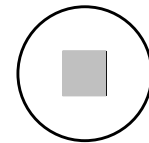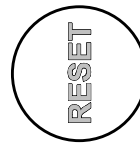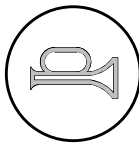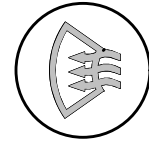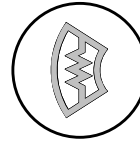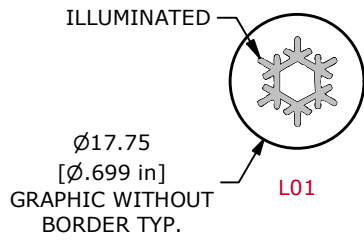

E-SWITCH®

www.e-switch.com


800.867.2717

7

ULV7 SERIES ANTI-VANDAL SWITCH

GRAPHIC OPTIONS (CONT.)

** REFER TO BODY DIMENSION PAGES 2 & 3 FOR GRAPHIC ORIENTATION **

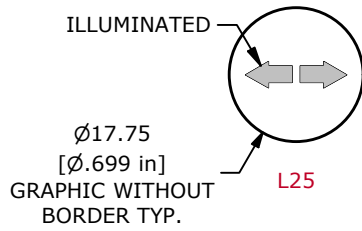


L26



L27




L28

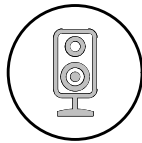

L29



L30

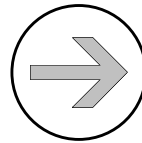

L31




L32




L35



L36

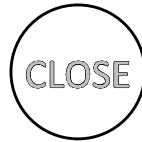

L37

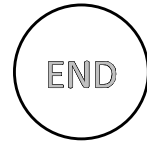


L38




L42




L43

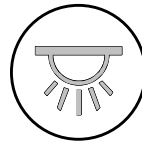

L44

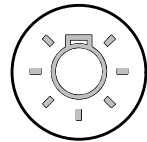


L45

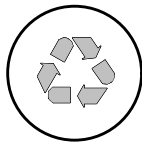

L46



L47

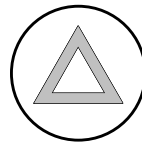

L48

ANTI-VANDAL
SWITCHES

DETECTOR
SWITCHES

DIP
SWITCHES

KEYLOCK
SWITCHES

NAVIGATION
SWITCHES

PUSHBUTTON
SWITCHES

ROCKER
SWITCHES

ROTARY
SWITCHES

SLIDE
SWITCHES

SNAP ACTION
SWITCHES

TACTILE
SWITCHES

TOGGLE
SWITCHES

CAP
OPTIONS



E-SWITCH®

www.e-switch.com

800.867.2717

8

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[ULV7F2HSS341](#) [ULV7F23SS344](#) [ULV7F2H11341](#) [ULV7F2G11311](#) [ULV7F2BSS331](#) [ULV7F2H11311](#)
[ULV7F23SS311](#) [ULV7F2GSS341](#) [ULV7F2G11341](#) [ULV7F2H11G341](#) [ULV7F2H11G301](#) [ULV7F2H11G331](#)
[ULV7F2BSS351](#) [ULV7F2BSSG641](#) [ULV7FWGSS341](#) [ULV7FWG11311](#) [ULV7FWBSS331](#) [ULV7FWG11341](#)
[ULV7FWHSS341](#) [ULV7F23SS3K5](#) [ULV7F2G11331](#) [ULV7F2B11301](#) [ULV7F2BSS301](#) [ULV7F2BSS634](#)
[ULV7F23SS331](#) [ULV7F23SS3G5](#) [ULV7F2311336](#) [ULV7F23SS314](#) [ULV7F2BSS314](#) [ULV7F2B11G341](#)
[ULV7F23SS635](#) [ULV7F23SS645](#) [ULV7F2B113G1](#) [ULV7F2BSS305](#) [ULV7F2BSS341](#) [ULV7F2311306](#)
[ULV7F2HSS335](#) [ULV7F2GSS311](#) [ULV7F2H11301](#) [ULV7F23SS316](#) [ULV7F2BSS321](#) [ULV7F2BSS3P1](#)
[ULV7F2G11344](#) [ULV7F2GSS313](#) [ULV7F2GSS335](#) [ULV7F2GSS647](#) [ULV7F2GSSG335](#) [ULV7F2311341](#)
[ULV7F2G11314](#) [ULV7F2GSS347](#) [ULV7F23SS647](#) [ULV7F2HSS634](#) [ULV7F2HSSG311](#) [ULV7F2BSS](#)
[ULV7F2HSS641](#) [ULV7F2HSS644](#) [ULV7F2HSS647](#) [ULV7FWHSS345](#) [ULV7F2311307](#) [ULV7F2BSS316](#)
[ULV7FWBSSG301](#) [ULV7FPHSS645](#) [ULV7FWBSS601](#) [ULV7FPG11311](#) [ULV7FPGSS341](#) [ULV7F2GSS607](#)
[ULV7FMG11341](#) [ULV7FMGSS341](#) [ULV7FMHSS341](#) [ULV7FPB11345](#) [ULV7FPBSS331](#) [ULV7FPBSS3G5](#)
[ULV7F2BSS601](#) [ULV7F2BSS605](#) [ULV7FMBSS316](#) [ULV7FMBSS331](#) [ULV7FMBSS341](#) [ULV7FMG11311](#)
[ULV7FWG11315](#) [ULV7FWGSS355](#) [ULV7FW3SS301](#) [ULV7FWBSS316](#) [ULV7FWHSS3P5](#) [ULV7F2BSS3G5](#)
[ULV7F2GSS357](#) [ULV7F2HSS305](#) [ULV7F2HSS337](#) [ULV7F2HSS347](#) [ULV7F2HSS3P5](#) [ULV7F2GSS344](#)
[ULV7F2HSS345](#) [ULV7FWGSS307](#) [ULV7FW3SS3G1](#) [ULV7FWHSS307](#) [ULV7FMBSS6G1](#) [ULV7F2HSL16L21](#)
[ULV7F2HSL137L22](#) [ULV7F2BSS345](#) [ULV7FWBSS3G1](#) [ULV7FPBSS345](#)