

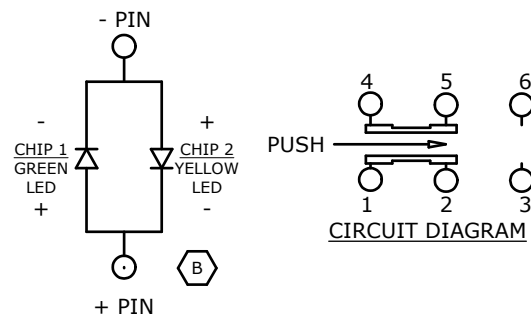
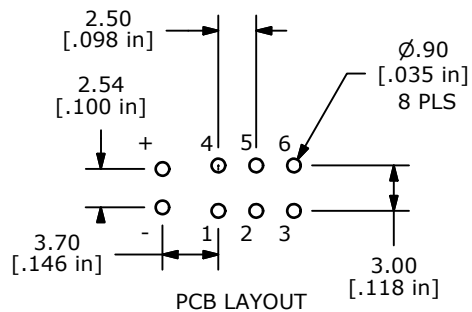
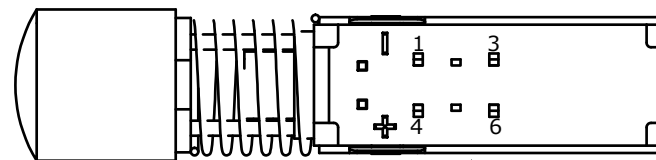


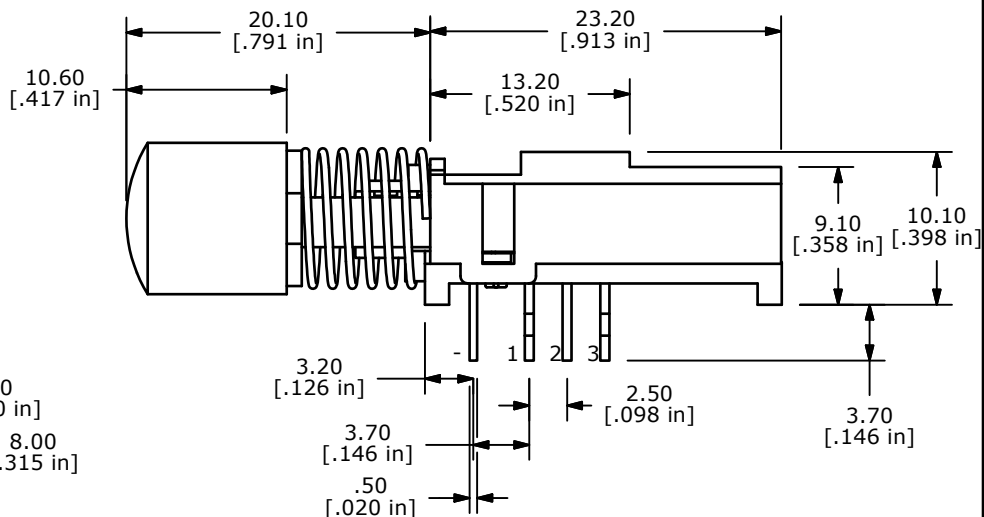


NOTES:

1. ALL DIMENSIONS IN MM [INCH]
2. GENERAL TOLERANCE: x.x=±0.4mm
x.xx=±0.25mm
3. RATING: DC 30V, 0.3A
4. OPERATING FORCE: 200±100gf
- ▲ 5. TRAVEL: FULL: 3.3mm, LOCK: 2.5mm
6. LIFE CYCLES: 10,000 CYCLES
7. OPERATING TEMPERATURE: -20°C TO 70°C
8. CONTACT RESISTANCE: 20mΩ MAX.
9. INSULATION RESISTANCE: 100MΩ MIN@ 500VDC.
- ▲ 10. LED COLOR: GREEN / YELLOW
11. ▲ DENOTES CRITICAL PARAMETER.
12. 2002/95/EC (RoHS) COMPLIANT.

▲
R05 BUTTON
TRANSPARENT
(B410000)

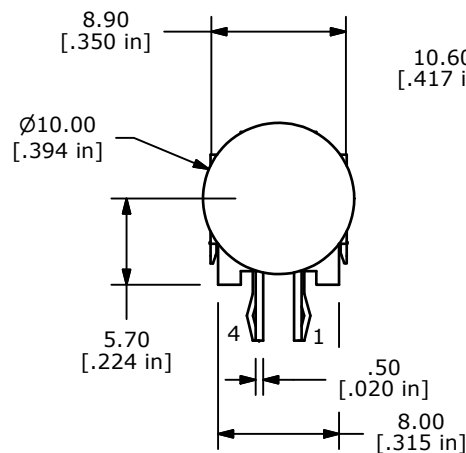

▲ WBL2UEEGYQ
(B400010)

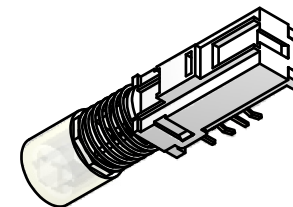

LED SPECS	UNITS	GREEN	YELLOW
FORWARD CURRENT	mA	20	20
FORWARD VOLTAGE @20mA	V	1.7 Typ-2.6 Max	1.7 Typ - 2.6 Max
LUMINOUS INTENSITY @ 10mA	MCD	4.7 - 7.8	4.7 - 7.8



B	19872	EDIT LED CIRCUIT	4/25/11	BGL
A	19754	RELEASE FOR PRODUCTION	3/11/11	BGL
REV	PCR NO	DESCRIPTION	DATE	BY

THE INFORMATION CONTAINED IN THIS DOCUMENT IS PROPRIETARY
TO E-SWITCH AND IS NOT TO BE COPIED OR TRANSFERRED

TITLE WBL2UEEGYQR05CLR

SCALE 2:1

DATE 3/11/2011

DR BGL

DWG XB0932P

REV B

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[E-Switch:](#)

[WBL2UEEGYQR05CLR](#)