

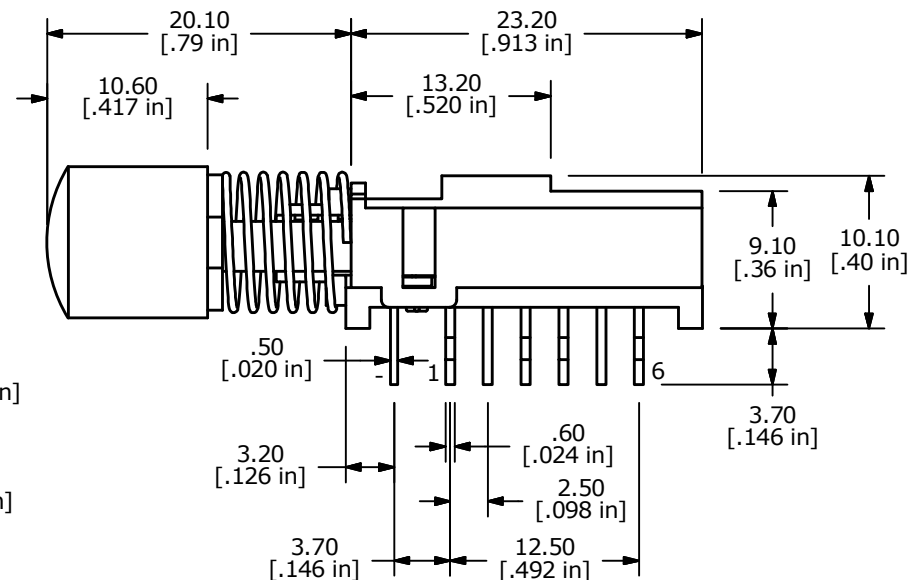
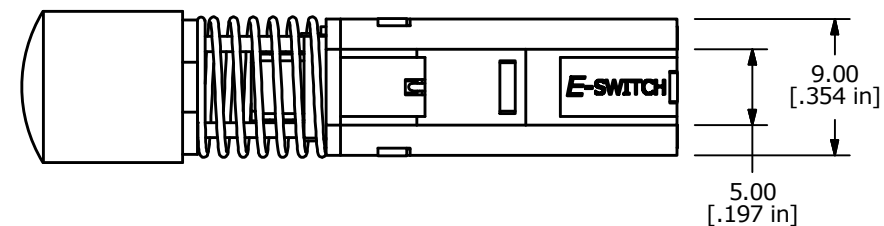
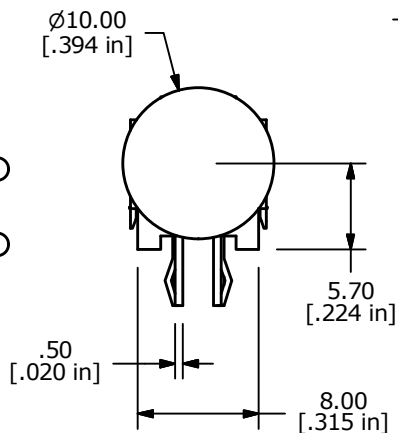
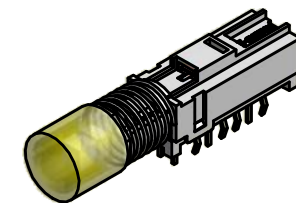
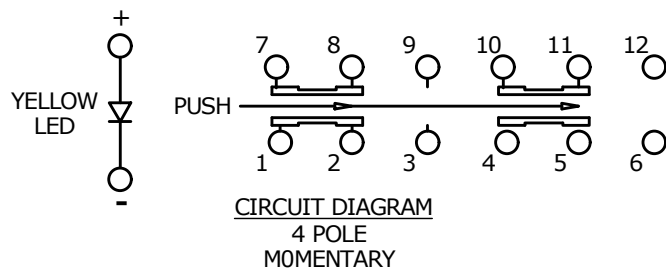


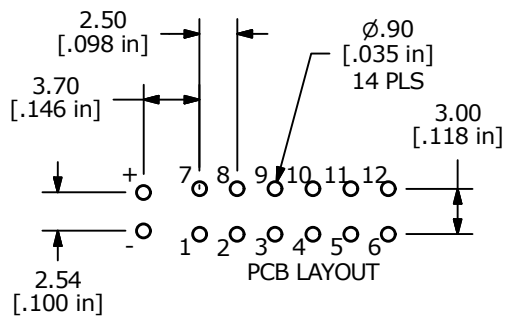

▲ TRANSPARENT BUTTON  
LED COLOR: YELLOW

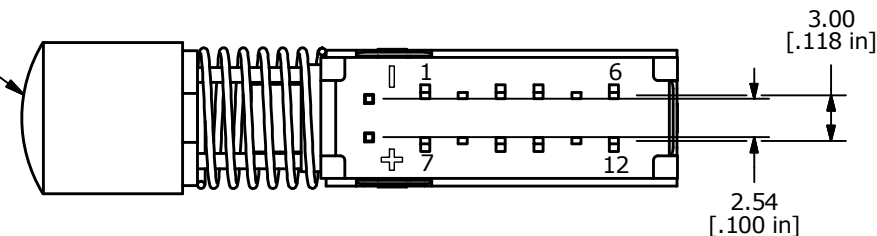

## NOTES:

1. ALL DIMENSIONS IN MM [INCH]
2. GENERAL TOLERANCE: X.X =  $\pm 0.4\text{mm}$   
X.XX =  $\pm 0.25\text{mm}$
3. RATING: DC 30V, 0.3A
4. OPERATING FORCE: 200  $\pm 100\text{gf}$
5. TRAVEL: 3.3mm FULL TRAVEL
6. LIFE CYCLES: 10,000 CYCLES
7. OPERATING TEMPERATURE: -20~C to 70~C
8. CONTACT RESISTANCE: 20mW MAX.
9. INSULATION RESISTANCE: 100MW MIN@ 500VDC
10. ▲ DENOTES CRITICAL PARAMETER.
11. 2011/65/EU (RoHS) COMPLIANT.

| LED SPECS                 | UNITS | YELLOW          |
|---------------------------|-------|-----------------|
| FORWARD CURRENT           | mA    | 20              |
| FORWARD VOLTAGE @20mA     | V     | 2.0 TYP-2.5 MAX |
| LUMINOUS INTENSITY @ 20mA | mcd   | 1300 TYP        |



E-SWITCH®

TITLE WBL4UOAYQR05CLR

SCALE

2:1

DATE

3/14/2017

DR

MW

DWG

B400018

REV

A

THE INFORMATION CONTAINED IN THIS DOCUMENT IS PROPRIETARY  
TO E-SWITCH AND IS NOT TO BE COPIED OR TRANSFERRED

|     |        |             |         |    |
|-----|--------|-------------|---------|----|
| A   | 22760  | New Release | 3/14/17 | MW |
| REV | PCR NO | DESCRIPTION | DATE    | BY |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[E-Switch:](#)

[WBL4UOAYQR05CLR](#)