


PB400 SERIES PUSHBUTTON SWITCH

ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS



APPLICATIONS / MARKETS

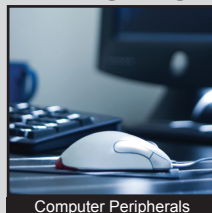

Computer Peripherals



Telecommunication



Security Devices



Consumer Electronics



Instrumentation



Testing Equipment

RoHS

SPECIFICATIONS

Electrical Rating: 3A @ 30 VDC
Electrical Life: 6,000 Cycles
Contact Resistance: 30mΩ Max. Initial
Insulation Resistance: 500MΩ Min. @ 500VDC
Dielectric Strength: 500VAC for 1 minute
Operating Temperature: -5°C to 60°C
Terminal: Copper, Silver Plated
Travel: Switch to make: 1.8mm
 Latch: 2.2mm (Latching)
 Full Actuation: 3.2mm
Contact Arrangement: DPST
Actuation Force: 3N~7N

FEATURES & BENEFITS

- Low cost
- Right Angle pushbutton switch
- DPST
- Momentary or Latching function
- 3.2mm travel
- Optional black cap

PART NUMBER CONFIGURATOR

Series



PB400

Mechanical Configuration



EE - Latching
OA - Momentary

Contact Material



 
Q - Silver

Cap



X - No Cap
R1 - Cap (8.8mm)

Cap Color



BLK - Black

Specifications subject to change without notice 12.19.2017



E-SWITCH®




www.e-switch.com

800.867.2717

1




PB400 SERIES PUSHBUTTON SWITCH

BODY DIMENSIONS - WITH CAP

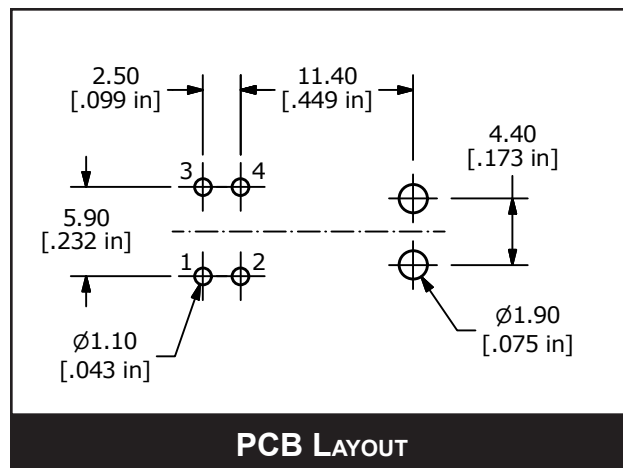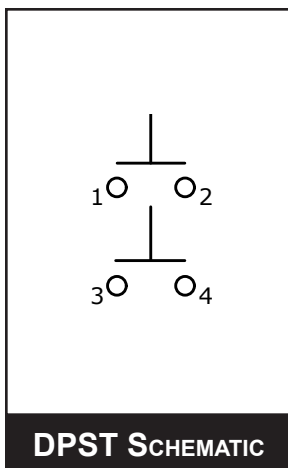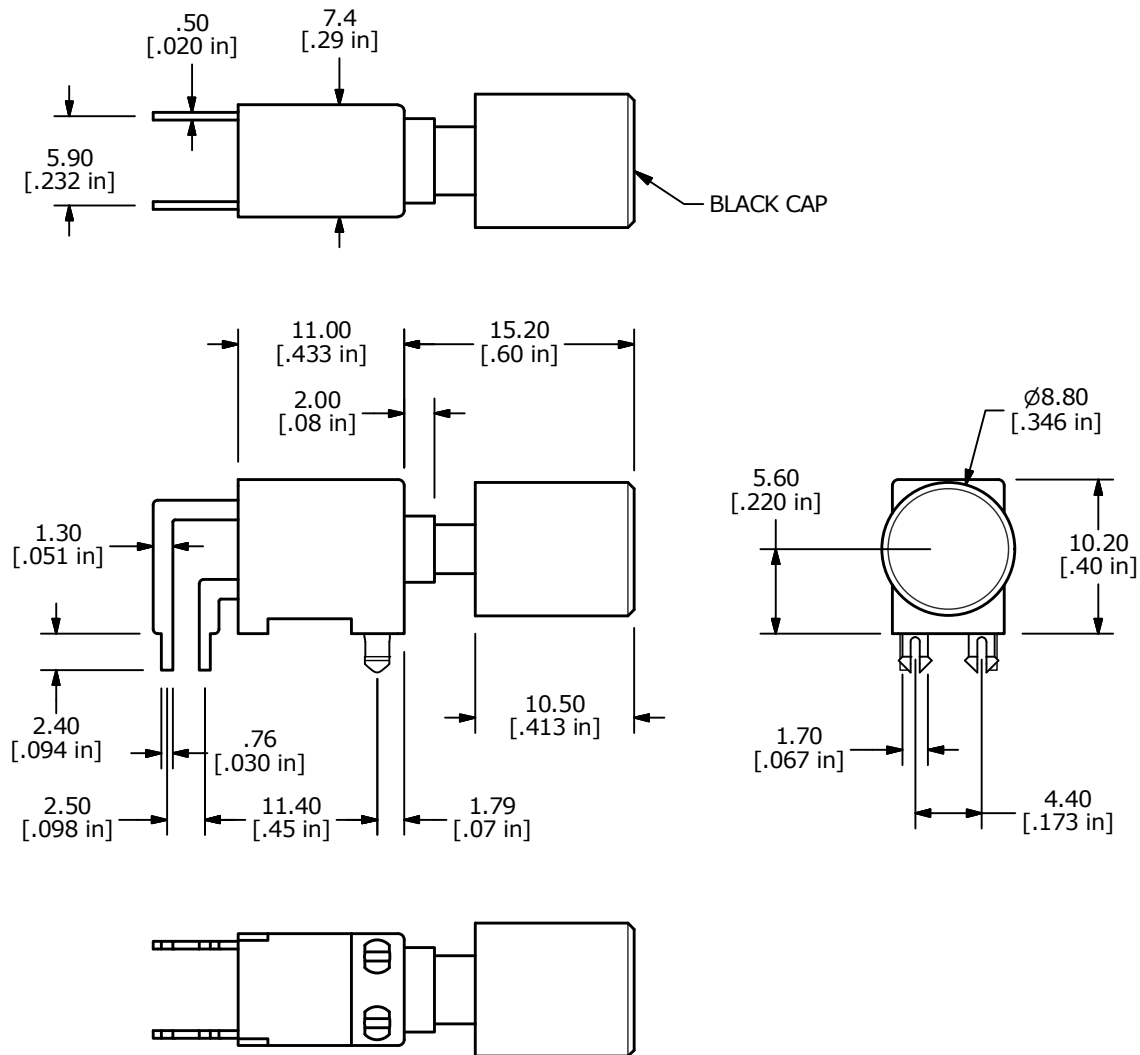

PB400 SERIES PUSHBUTTON SWITCH

BODY DIMENSIONS - WITHOUT CAP

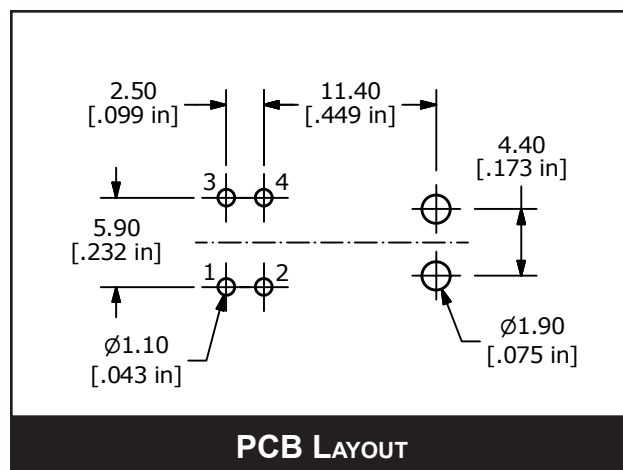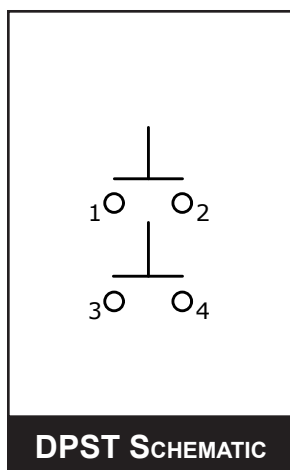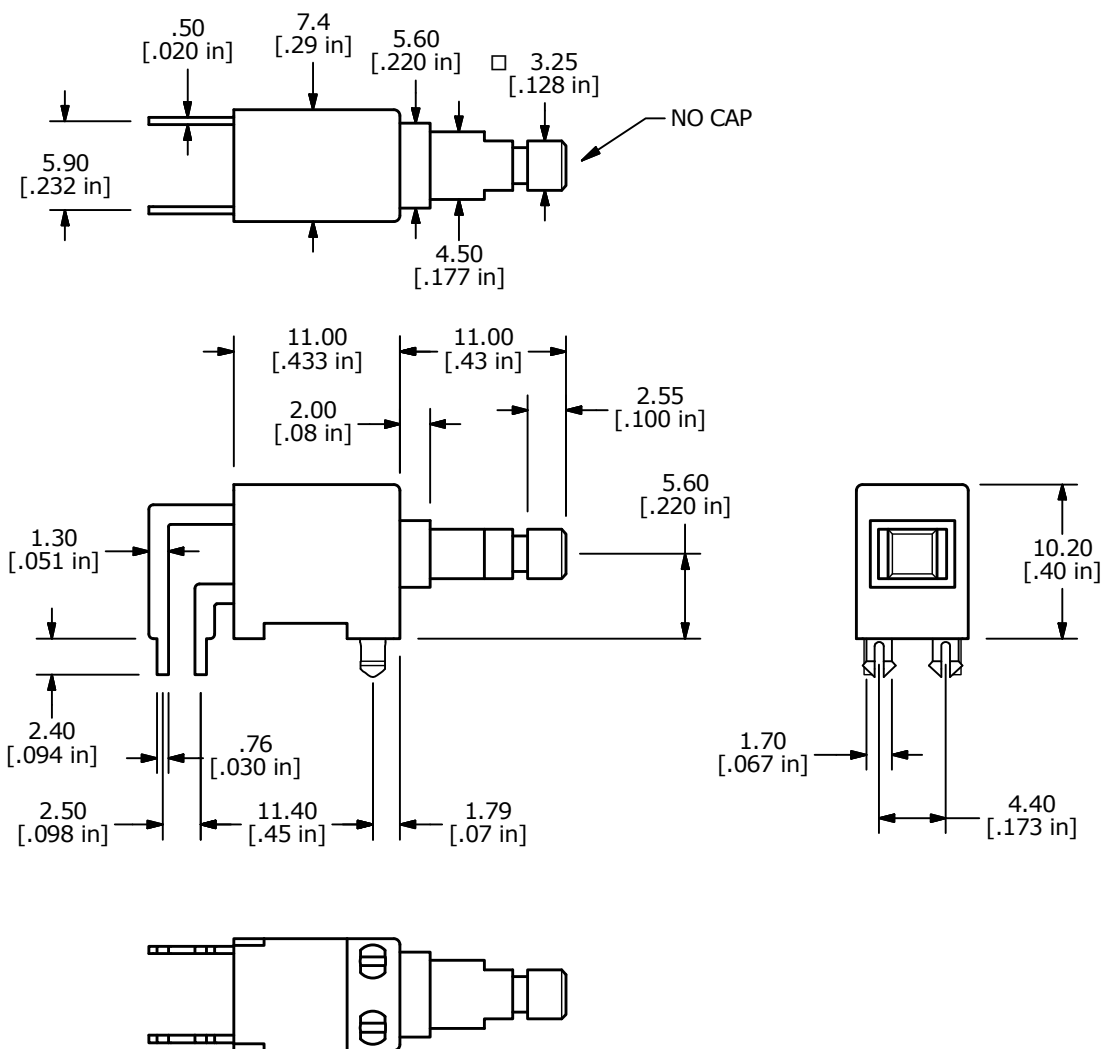

E-SWITCH®

www.e-switch.com

800.867.2717

3

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

E-Switch:

[PB400OAQR1BLK](#) [PB400EEQX](#) [PB400OAQX](#) [PB400EEQR1BLK](#)