


Push Buttons & Signaling Devices

30mm Water, Oil Tight & Corrosion Resistant – Class 52

Push Button

Selection Guid


Momentary Push Button - Non-Illuminated

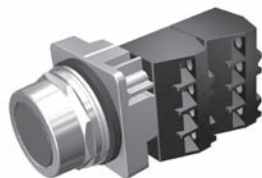

Flush Head



Extended Head

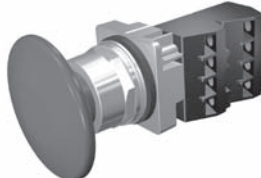

Large Mushroom Head 2 1/2"



Small Mushroom Head 1 3/4"

Part Number	52	a	M b	c	d	e ¹
-------------	----	---	--------	---	---	----------------

a	Code	Finish
	P	Chrome - Command 52
	B	Epoxy Coated - Black Max

b	Code	Type
	M	Momentary Push Button

c	Code	Style / Head Type
		Flush / Extended Cap
	8A	Flush
	8B	Extended
		Mushroom Head Metal
	9A	Small Mushroom Head 1 3/4" (44.5mm)
		Mushroom Head Plastic
	9W	Small Mushroom Head 1 3/4" (44.5mm)
	9V	Large Mushroom Head 2 1/2" (63.5mm)

d	Code	Plastic	Metal
	1	Black	—
	2	Red	Red
	3	Green	Green
	4	Yellow	—
	5	Blue	—
	6	Gray	—
	7	All Color Caps	—
	8	Orange	—
	C	—	Chrome

e ¹	Code	Contact Blocks
	A	1 NO + 1 NC
	B	2 NO + 2 NC
	C	3 NO + 3 NC
	D	4 NO + 4 NC
	E	1 NC (LB)
	F	2 NO
	G	2 NC
	H	1NO (EM)
	J	1 NC
	K	1 NO

¹ For operator without contact blocks leave position e blank.

Push Buttons & Signaling Devices

30mm Water, Oil Tight & Corrosion Resistant – Class 52

Push Buttons

1
2
3
4
5
6
7
8
9
10

Selection Tables

Momentary Push Button - Non-Illuminated

Head Style	Contacts	Color	Finish	
			Chrome	Black Max
Flush	—	Less cap	52PM8	52BM8
		Black	52PM8A1	52BM8A1
		Red	52PM8A2	52BM8A2
		Green	52PM8A3	52BM8A3
		Yellow	52PM8A4	52BM8A4
	1 NO - 1 NC	Black	52PM8A1A	52BM8A1A
		Red	52PM8A2A	52BM8A2A
		Green	52PM8A3A	52BM8A3A
	1 NO	Black	52PM8A1K	52BM8A1K
		Red	52PM8A2K	52BM8A2K
		Green	52PM8A3K	52BM8A3K
	1 NC	Red	52PM8A2J	52BM8A2J
Extended	—	Black	52PM8B1	52BM8B1
		Red	52PM8B2	52BM8B2
		Green	52PM8B3	52BM8B3
	1 NO	Black	52PM8B1K	52BM8B1K
	1 NC	Red	52PM8B2K	52BM8B2K
Mushroom Head Plastic Ø 1 3/4"	—	Less cap	52PM9	52BM9
		Red	52PM9W2	52BM9W2
	1 NO	Green	52PM9W3K	52BM9W3K
	1 NO - 1 NC	Black	52PM9W1A	52BM9W1A
		Red	52PM9W2A	52BM9W2A
	1 NO - 1 NC	Green	52PM9W3A	52BM9W3A
Mushroom Head Plastic Ø 2 1/2"	—	Red	52PM9V2	52BM9V2
	1 NO - 1 NC	Black	52PM9V1A	52BM9V1A
		Red	52PM9V2A	52BM9V2A
		Green	52PM9V3A	52BM9V3A

Readily available items are in **bold**.
This is a small representation of stocked items.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Siemens:

[52BM8A2G](#) [52BM8A4G](#) [52BM8A4J](#) [52BM8A8F](#) [52BM8B1B](#) [52BM8B1D](#) [52BM8B4C](#) [52BM8B6D](#) [52BM9V6](#)
[52BM9V6B](#) [52BM9V6J](#) [52BM9W2H](#) [52BM9W2K](#) [52BM9W5](#) [52BM9W5J](#) [52C104S](#) [52C307S](#) [52NA10](#) [52NA34](#)
[52NA36](#) [52NA47](#) [52NL08](#) [52NL109730](#) [52NL37](#) [52PM8A8](#) [52BM8A5F](#) [52BM8A6B](#) [52BM8B2A](#) [52BM8B4D](#)
[52BM8B5G](#) [52BM9V1F](#) [52BM9V2B](#) [52BM9V4E](#) [52BM9V5A](#) [52BM9V6A](#) [52BM9V6H](#) [52BM9W4C](#) [52BM9W5C](#)
[52BM9W6F](#) [52C307A](#) [52MB2A1A2](#) [52NA35](#) [52NL09](#) [52NL109731](#) [52NL27](#) [52BM8A1C](#) [52BM8A1G](#) [52BM8A5J](#)
[52BM8A6](#) [52BM8A8](#) [52BM8B4E](#) [52BM8B8D](#) [52BM9V1](#) [52BM9V1B](#) [52BM9V2F](#) [52BM9V4A](#) [52BM9V5E](#)
[52BM9V5J](#) [52BM9V8B](#) [52BM9W3A](#) [52BM9W4G](#) [52BM9W4J](#) [52BM9W6D](#) [52C159A](#) [52C224X](#) [52C334S](#)
[52NA02B](#) [52NL109732](#) [52NL24](#) [52NL44](#) [52BM8A3F](#) [52BM8A3K](#) [52BM8A5](#) [52BM8A6H](#) [52BM8B6H](#) [52BM8B6J](#)
[52BM8B7A](#) [52BM9V6C](#) [52BM9V6F](#) [52BM9W4A](#) [52BM9W5D](#) [52C116S](#) [52C202X](#) [52MP2A1W2](#) [52NA05](#) [52NA23](#)
[52NA41](#) [52NL32](#) [52NL33](#) [52PM8A7](#) [52BM8A1K](#) [52BM8A2F](#) [52BM8A3B](#) [52BM8A4A](#) [52BM8A6D](#) [52BM8A8C](#)
[52BM8B1C](#) [52BM8B1K](#) [52BM8B2K](#) [52BM8B4B](#)