


3-phase feed-in terminal, for contactors 3RT201

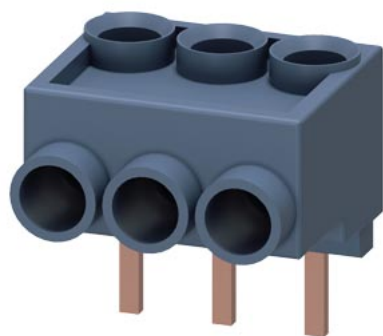

product brand name	SIRIUS
product designation	3-phase infeed terminals
General technical data	
size of contactor	S00
insulation voltage with degree of pollution 3 at AC rated value	690 V
certificate of suitability	CE / UL / CSA / CCC
Substance Prohibitance (Date)	10/01/2009
ampacity maximum	22 A
Ambient conditions	
ambient temperature	
• during operation	-40 ... +60 °C
• during storage	-50 ... +80 °C
Installation/ mounting/ dimensions	
height	30.4 mm
width	25.9 mm
depth	28.4 mm
Connections/ Terminals	
type of electrical connection	
• for main current circuit	screw-type terminals with box terminals
type of connectable conductor cross-sections	
• for main contacts	
— solid	1x (2.5 ... 6.0 mm²)
— stranded	1x (2.5 ... 6.0 mm²)
— finely stranded with core end processing	1x (2.5 ... 10.0 mm²)
• for AWG cables for main contacts	1x (12 ... 8)
connectable conductor cross-section for main contacts	
• solid or stranded	2.5 ... 6 mm²
• stranded	2.5 ... 6 mm²
• finely stranded with core end processing	2.5 ... 10 mm²
AWG number as coded connectable conductor cross section	
• for main contacts	12 ... 8
Approvals Certificates	
General Product Approval	
Declaration of Conformity	



[Confirmation](#)



[Special Test Certificate](#)

[Type Test Certificates/Test Report](#)



Marine / Shipping

other

Railway



[Confirmation](#)

[Vibration and Shock](#)

Further information

Siemens has decided to exit the Russian market (see here).

<https://press.siemens.com/global/en/pressrelease/siemens-wind-down-russian-business>

Siemens is working on the renewal of the current EAC certificates.

Please contact your local Siemens office on the status of validity of the EAC certification if you intend to import or offer to supply these products to an EAC relevant market (other than the sanctioned EAEU member states Russia or Belarus).

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RA2913-3K>

Cax online generator



<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RA2913-3K>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RA2913-3K>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RA2913-3K&lang=en

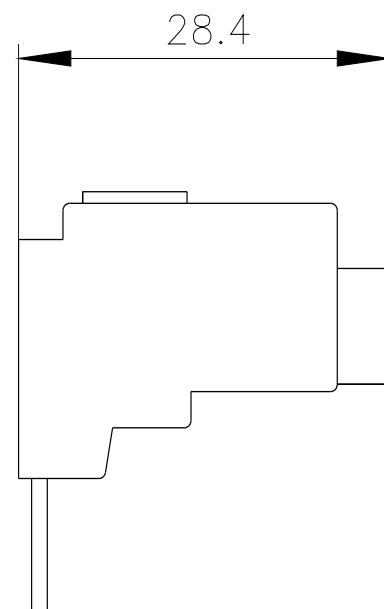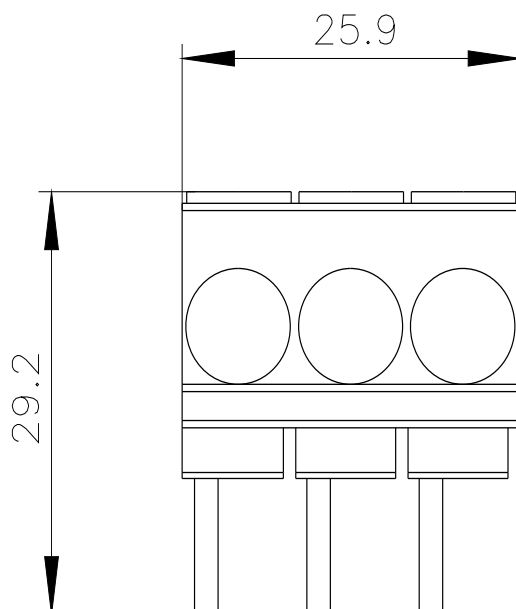

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Siemens:

3RA29133K