

Current transformer 20...200 A for 3RB22/23/24 Size S6 Contactor
mounting/stand-alone installation Main circuit: busbar connection Auxiliary circuit: --



product brand name	SIRIUS
product designation	Current measuring module
product type designation	3RB29
General technical data	
Substance Prohibittance (Date)	07/01/2006
SVHC substance name	Lead - 7439-92-1 Lead monoxide (lead oxide) - 1317-36-8
Weight	1 kg
Main circuit	
adjustable current response value current of the current-dependent overload release	20 ... 200 A
operating voltage	
• at AC-3e rated value maximum	1 000 V
operational current rated value	200 A
operational current at AC-3e at 400 V rated value	200 A
Installation/ mounting/ dimensions	
fastening method	Contactor mounting/stand-alone installation
Connections/ Terminals	
type of electrical connection	
• for main current circuit	screw-type terminals
Electrical Safety	
protection class IP on the front according to IEC 60529	IP00; IP20 with box terminal/cover
touch protection on the front according to IEC 60529	finger-safe, for vertical contact from the front with box terminal/cover
Approvals Certificates	
General Product Approval	For use in hazardous locations



For use in hazardous locations	Test Certificates	Marine / Shipping
--------------------------------	-------------------	-------------------



[Special Test Certificate](#)

[Type Test Certificates/Test Report](#)



Marine / Shipping	other	Environment
-------------------	-------	-------------

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RB2956-2TH2>

Cax online generator

<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RB2956-2TH2>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RB2956-2TH2>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)



http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RB2956-2TH2&lang=en


Characteristic: Tripping characteristics, I²t, Let-through current

<https://support.industry.siemens.com/cs/ww/en/ps/3RB2956-2TH2/char>

Further characteristics (e.g. electrical endurance, switching frequency)

<http://www.automation.siemens.com/bilddb/index.aspx?view=Search&mlfb=3RB2956-2TH2&objecttype=14&gridview=view1>

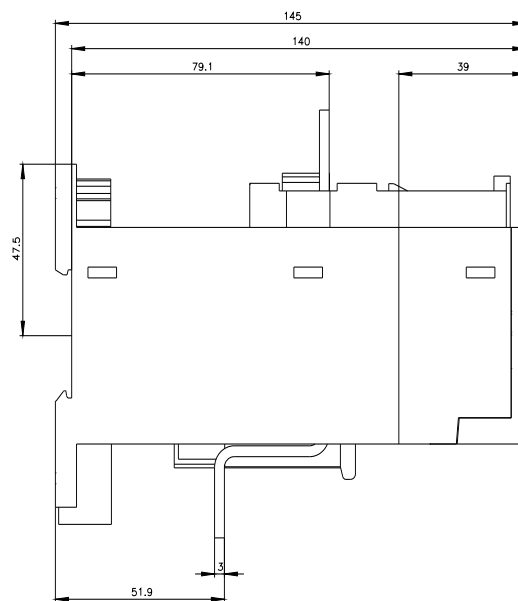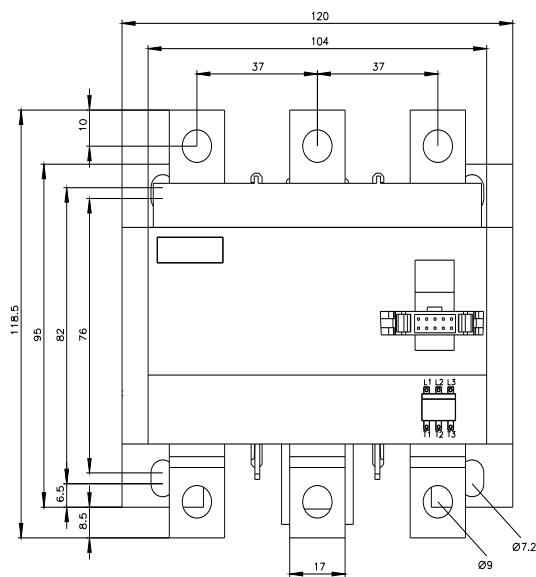

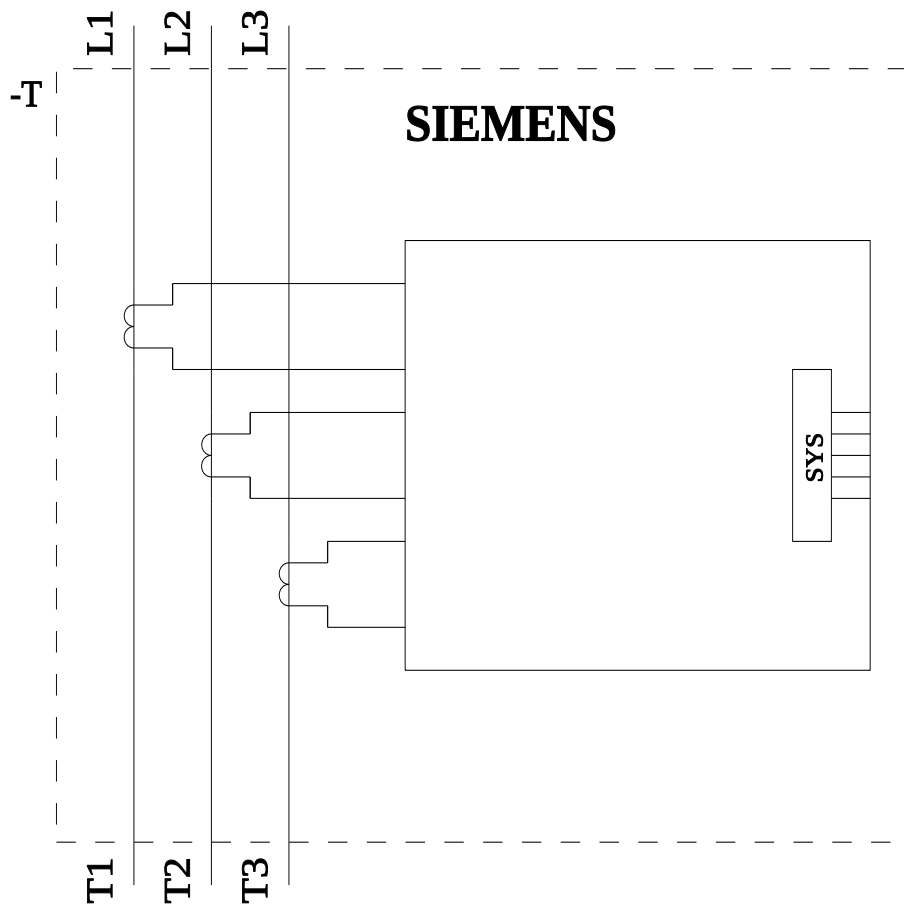

last modified:

4/2/2025 [↗](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Siemens:](#)

[3RB29562TH2](#)