



AS-Interface function module LOGO! standard slave IP20 4 DI/4 DQ Can be used for device series LOGO! 6 and LOGO! 7

General technical data		
design of the product		AS-Interface connection for LOGO!
Type		4 inputs (virtual) / 4 outputs (virtual)
design of the slave type		standard slave
Supply voltage DC	V	24
Status display display of AS-Interface/diagnostics		green/red dual LED
Inputs		
number of digital inputs		4
Outputs		
number of digital outputs		4
Ambient conditions		
ambient temperature during operation	°C	0 ... 55
protection class IP		IP20
Mechanical data		
width	mm	36
height	mm	90
depth	mm	58
fastening method		on standard rail
Certificates/ approvals		
General Product Approval		EMV

[Confirmation](#)



Test Certificates	Marine / Shipping	other	Environment
Special Test Certificate	 DNV	 PRS	Confirmation Miscellaneous Environmental Confirmations

Industrial Communication


ASi

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RK1400-0CE10-0AA2>

Cax online generator


<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RK1400-0CE10-0AA2>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RK1400-0CE10-0AA2>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RK1400-0CE10-0AA2&lang=en

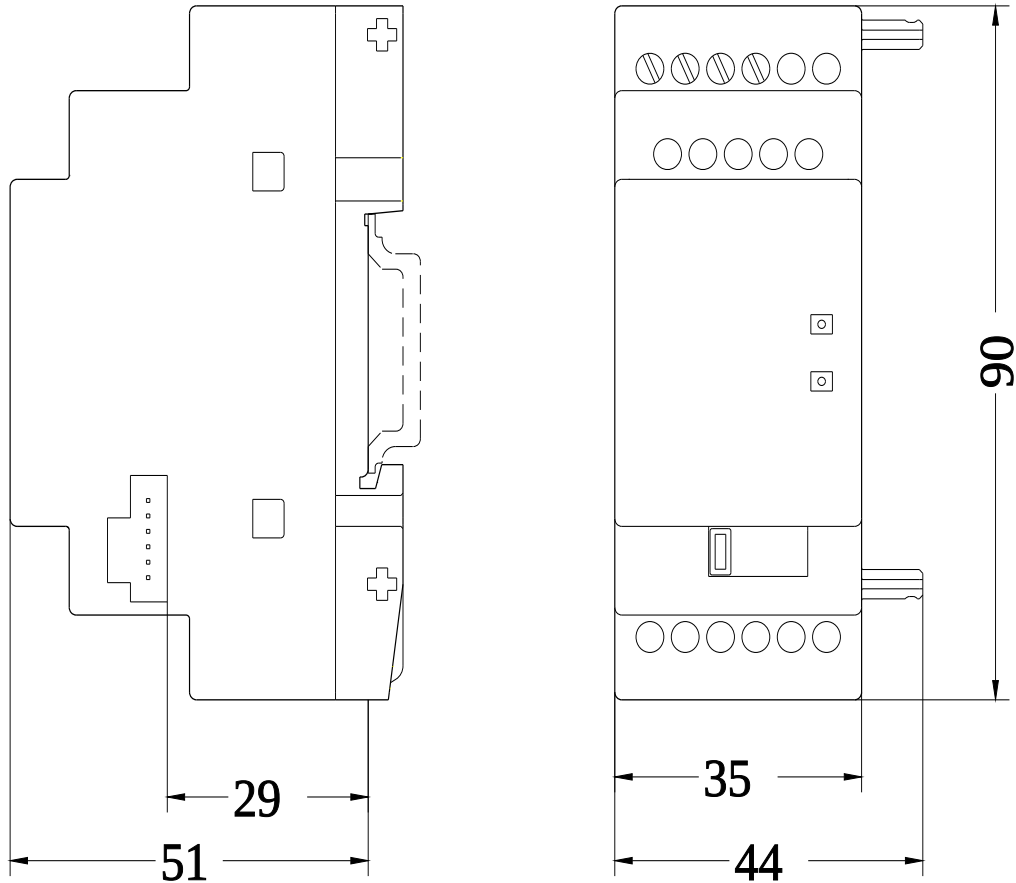

last modified:

3/11/2024 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Siemens:](#)

[3RK14000CE100AA2](#)