

AS-i compact module K60 digital 2 DI/2 DQ, IP67 2 x 1 input, max. 200 mA 2 x 1 output, 2 A, 24 V DC 2 x M12 standard socket Y assignment Mounting plate 3RK1901-0CA00 must be ordered separately

Mechanical data	
shock resistance	15g / 11 ms
Certificates/ approvals	
General Product Approval	EMV





[Confirmation](#)



EMV	Test Certificates	Marine / Shipping	other
KC	Special Test Certificate		Confirmation
			Miscellaneous

Environment	Industrial Communication
Environmental Confirmations	

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875
Information- and Downloadcenter (Catalogs, Brochures,...) https://www.siemens.com/ic10
Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RK1400-1BQ00-0AA3
Cax online generator http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RK1400-1BQ00-0AA3
Service&Support (Manuals, Certificates, Characteristics, FAQs,...) https://support.industry.siemens.com/cs/ww/en/ps/3RK1400-1BQ00-0AA3
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...) http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RK1400-1BQ00-0AA3&lang=en

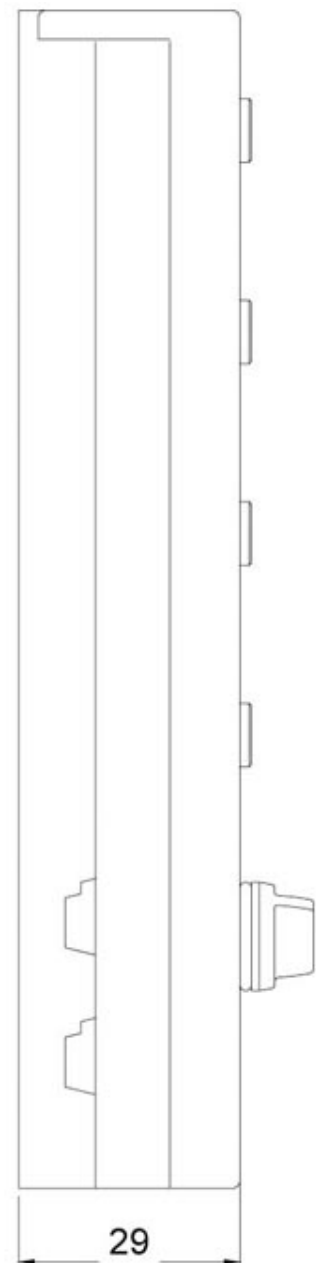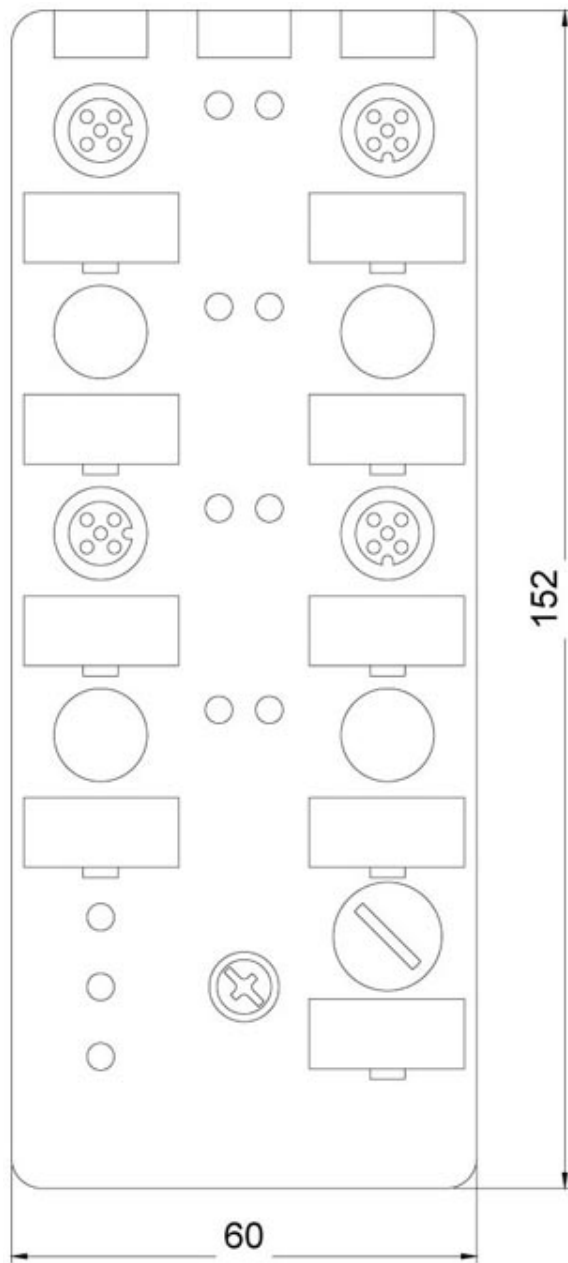

last modified:

3/11/2024 [🔗](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Siemens:](#)

[3RK14001BQ000AA3](#)