



AS-i Extension Plug Compact Doubling of the cable length to 200 m per AS-Interface segment Degree of protection IP67 Connection directly to AS-i Flat ribbon cable

General technical data			
design of the product		AS-Interface extension plug compact	
design of the slave type		no slave integrated	
Voltage supply using AS-Interface		Yes	
operating voltage according to AS-Interface specification	V	26.5 ... 31.6	
Status display • U AS-Interface		none	
Connections/ Terminals			
design of the AS-Interface connection		Direct connection to AS-i ribbon cable	
AS interface • Connection Polarity reversal protection • total current input max	mA	yes 15	
Ambient conditions			
ambient temperature during operation	°C	-25 ... +70	
protection class IP		IP67	
Certificates/ approvals			
General Product Approval	EMV	Marine / Shipping	other



[Confirmation](#)

Environment

[Environmental Conformations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RK1901-1MX02>



Cax online generator

<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RK1901-1MX02>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RK1901-1MX02>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

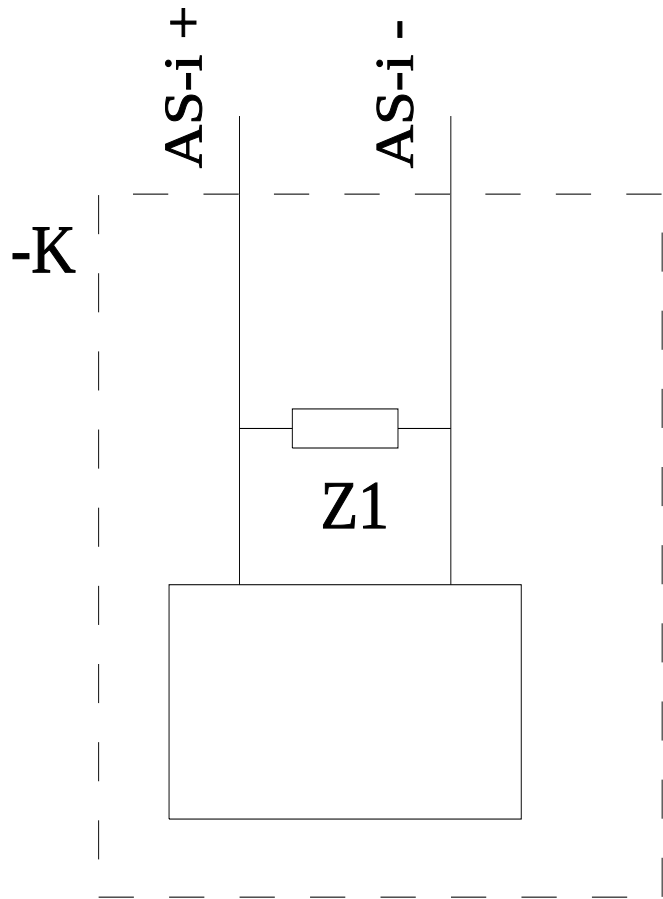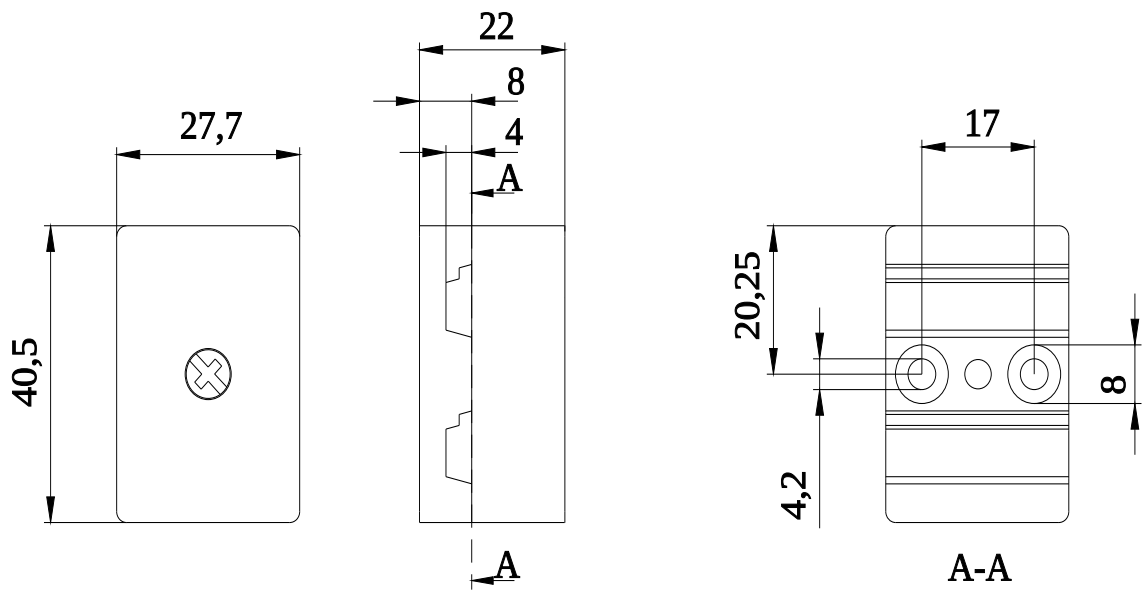

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Siemens:](#)

[3RK19011MX02](#)