



AS-Interface distributor compact for AS-i shaped cable
IP67/IP68/IP69K, max. 8 A

General technical data			
Type of device		AS-Interface accessories	
Function		distribution function for AS-i flat cables	
operating voltage according to AS-Interface spezification	V	26.5 ... 31.6	
operational current rated value	A	8	
Note		cable must not end in the feeder	
Connections/ Terminals			
type of electrical connection		insulation piercing method for AS-Interface flat cable	
Mechanical data			
Type of mounting		screw fixing	
tightening torque of fixing screw	N·m	1.65 ... 1.65	
Contacts Load rating max	A	12	
Ambient conditions			
ambient temperature	°C	-25 ... +75	
ambient temperature during storage	°C	-25 ... +85	
degree of protection		IP67/68/69K	
Certificates/ approvals			
General Product Approval	EMV	Marine / Shipping	other



[Confirmation](#)

Environment

[Environmental Conformations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)


<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RK1901-2NN10>

Cax online generator

<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RK1901-2NN10>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RK1901-2NN10>

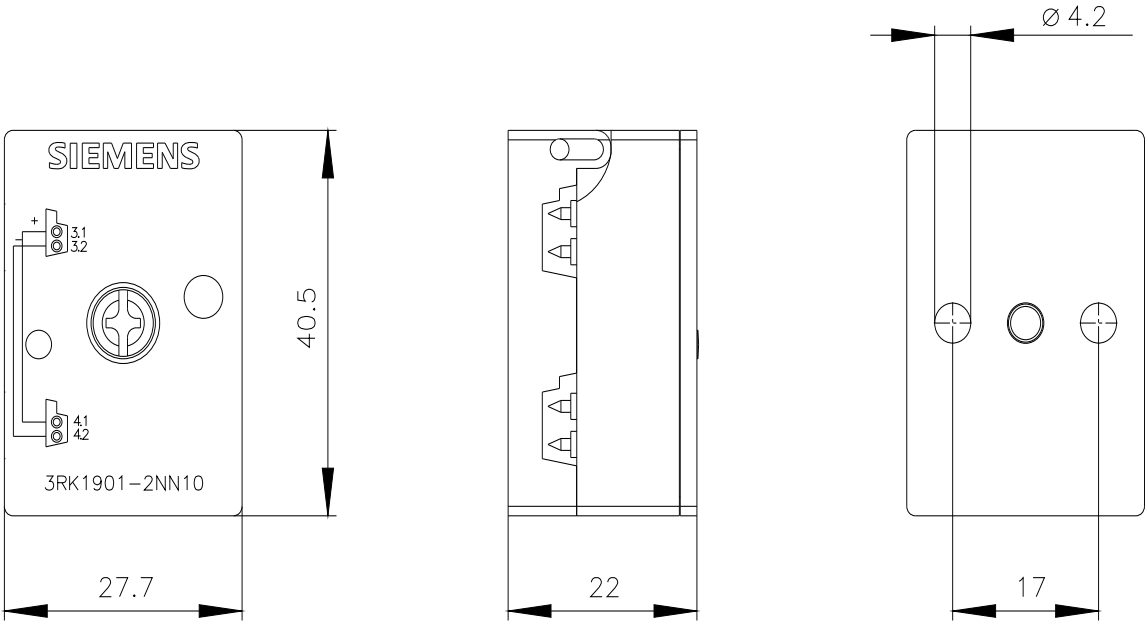

last modified:

4/1/2025

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Siemens:](#)

[3RK19012NN10](#)