

ECOFAST Energy T clamping connector for feeder 6 mm²

product category	Miscellaneous accessories
product designation	Power T terminal connector
General technical data	
degree of pollution	3
surge voltage resistance rated value	6 000 V
protection class IP	IP65
Substance Prohibittance (Date)	05/01/2012
Weight	0.344 kg
operating voltage rated value maximum	690 V
operational current at AC at 400 V rated value	40 A
Ambient conditions	
ambient temperature during operation	-40 ... +125 °C
Installation/ mounting/ dimensions	
height	55 mm
width	112 mm
length	158 mm
Approvals Certificates	
General Product Approval	EMV



[Confirmation](#)



other	Environment
Confirmation	Environmental Confirmations

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RK1911-2BF02>

Cax online generator



<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RK1911-2BF02>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RK1911-2BF02>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RK1911-2BF02&lang=en

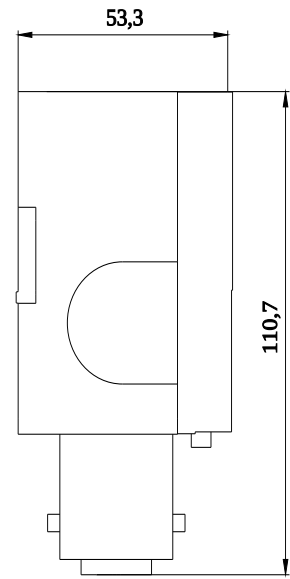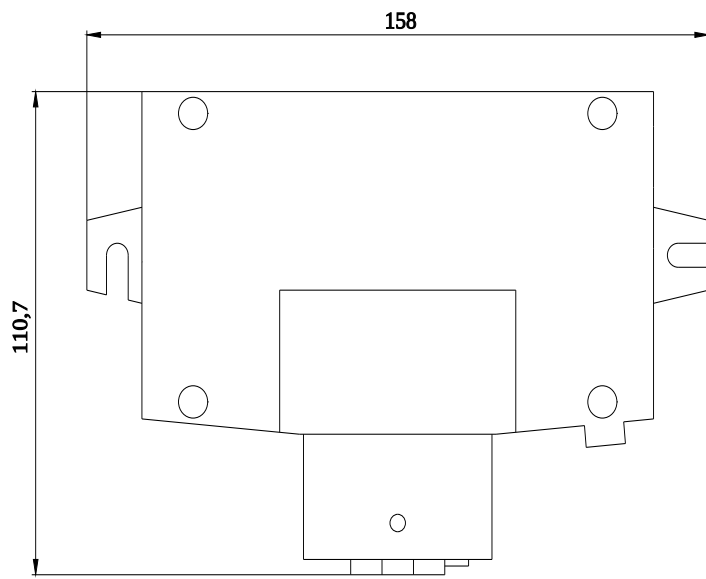

last modified:

1/10/2024 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Siemens:](#)

[3RK19112BF02](#)