



accessories for SIRIUS 3RM1 fuse module with GG fuses 20 A for use according to IEC for 22.5 mm busbar adapter 8US1216.., 8US1616.., 8US1716..

| General technical data | | |
|--|-----|---------------------------|
| product brand name | | SIRIUS |
| product designation | | Fuse module |
| design of the product | | With 3NW6007-1 fuse |
| suitability for use | | Motor starter 3RM1 |
| product function short circuit protection | | Yes |
| installation altitude at height above sea level maximum | m | 2 000 |
| ambient temperature | | |
| • during operation | °C | -25 ... +60 |
| • during transport | °C | -40 ... +70 |
| • during storage | °C | -40 ... +70 |
| relative humidity during operation | % | 10 ... 95 |
| shock resistance | | 15g / 11 ms |
| vibration resistance | | 2g |
| surge voltage resistance rated value | V | 6 000 |
| insulation voltage rated value | V | 690 |
| reference code according to IEC 81346-2 | | X |
| Main circuit | | |
| number of poles for main current circuit | | 3 |
| operating voltage rated value maximum | V | 500 |
| relative symmetrical tolerance of the operating voltage | % | 10 |
| operating frequency 1 rated value | Hz | 50 |
| operating frequency 2 rated value | Hz | 60 |
| operational current at AC at 400 V rated value | A | 16 |
| ampacity maximum | A | 25 |
| operational current at AC at 480 V according to UL 508 | A | 16 |
| power loss [W] for rated value of the current at AC in hot operating state | W | 3 |
| Installation/ mounting/ dimensions | | |
| mounting position | | any |
| fastening method | | snap-on mounting |
| width | mm | 22.5 |
| height | mm | 182.1 |
| depth | mm | 82.5 |
| Certificates/ approvals | | |
| General Product Approval | EMC | Declaration of Conformity |

[Confirmation](#)



Test Certificates

other

[Type Test Certificates/Test Report](#)

[Confirmation](#)

Further information

Siemens has decided to exit the Russian market (see here).

<https://press.siemens.com/global/en/pressrelease/siemens-wind-down-russian-business>

Siemens is working on the renewal of the current EAC certificates.

Please contact your local Siemens office on the status of validity of the EAC certification if you intend to import or offer to supply these products to an EAC relevant market (other than the sanctioned EAEU member states Russia or Belarus).

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RM1932-1AB>

Cax online generator


<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RM1932-1AB>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RM1932-1AB>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RM1932-1AB&lang=en

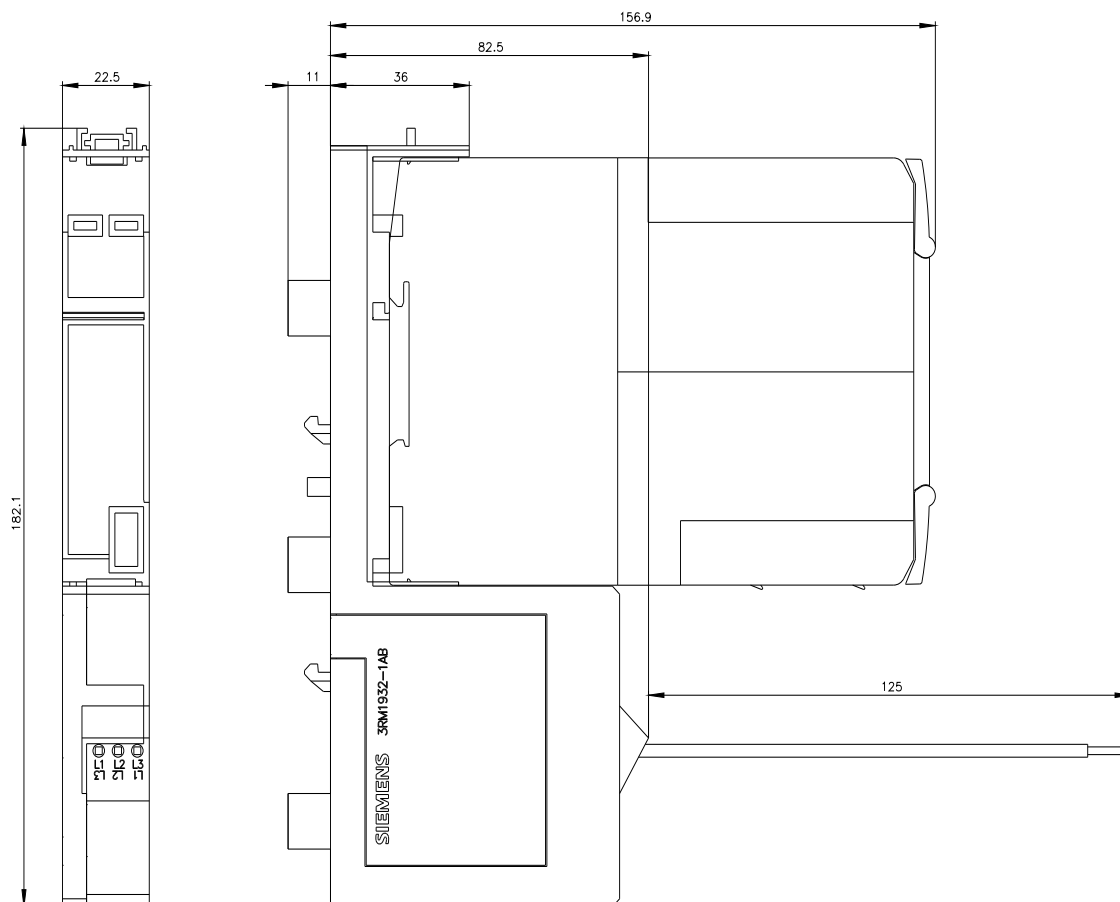

last modified:

12/16/2020

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Siemens:

3RM19321AB