

3-phase supply terminal Size S2 for 3-phase busbar connection from top

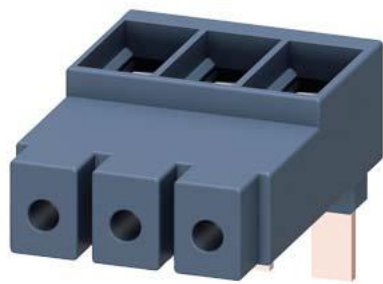


Figure similar

product brand name		SIRIUS	
product designation		3-phase supply terminal	
design of the product		Size S2	
General technical data			
size of the circuit-breaker		S2	
insulation voltage with degree of pollution 3 at AC rated value		690 V	
certificate of suitability		CE / UL / CSA / CCC	
Substance Prohibitance (Date)		07/01/2006	
ampacity maximum		108 A	
Ambient conditions			
ambient temperature			
• during operation		-20 ... +60 °C	
• during storage		-50 ... +80 °C	
Safety related data			
protection class IP on the front according to IEC 60529		IP20	
touch protection on the front according to IEC 60529		finger-safe, for vertical contact from the front	
Installation/ mounting/ dimensions			
height		59 mm	
width		54 mm	
depth		44 mm	
Connections/ Terminals			
type of electrical connection for main current circuit		screw-type terminals	
type of connectable conductor cross-sections			
• for main contacts			
— solid		1x (10 ... 50 mm²)	
— stranded		1x (10 ... 50 mm²)	
• for AWG cables for main contacts		1x (8 ... 0)	
connectable conductor cross-section for main contacts			
• solid or stranded		10 ... 50 mm²	
• stranded		10 ... 50 mm²	
AWG number as coded connectable conductor cross section for main contacts		8 ... 0	
Approvals Certificates			
General Product Approval		Declaration of Conformity	Marine / Shipping

[Confirmation](#)



other

[Confirmation](#)



#### Further information

Siemens has decided to exit the Russian market (see here).

<https://press.siemens.com/global/en/pressrelease/siemens-wind-down-russian-business>

Siemens is working on the renewal of the current EAC certificates.

Please contact your local Siemens office on the status of validity of the EAC certification if you intend to import or offer to supply these products to an EAC relevant market (other than the sanctioned EAEU member states Russia or Belarus).

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RV1935-5A>

Cax online generator


<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RV1935-5A>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RV1935-5A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

[http://www.automation.siemens.com/bilddb/cax\\_de.aspx?mlfb=3RV1935-5A&lang=en](http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RV1935-5A&lang=en)

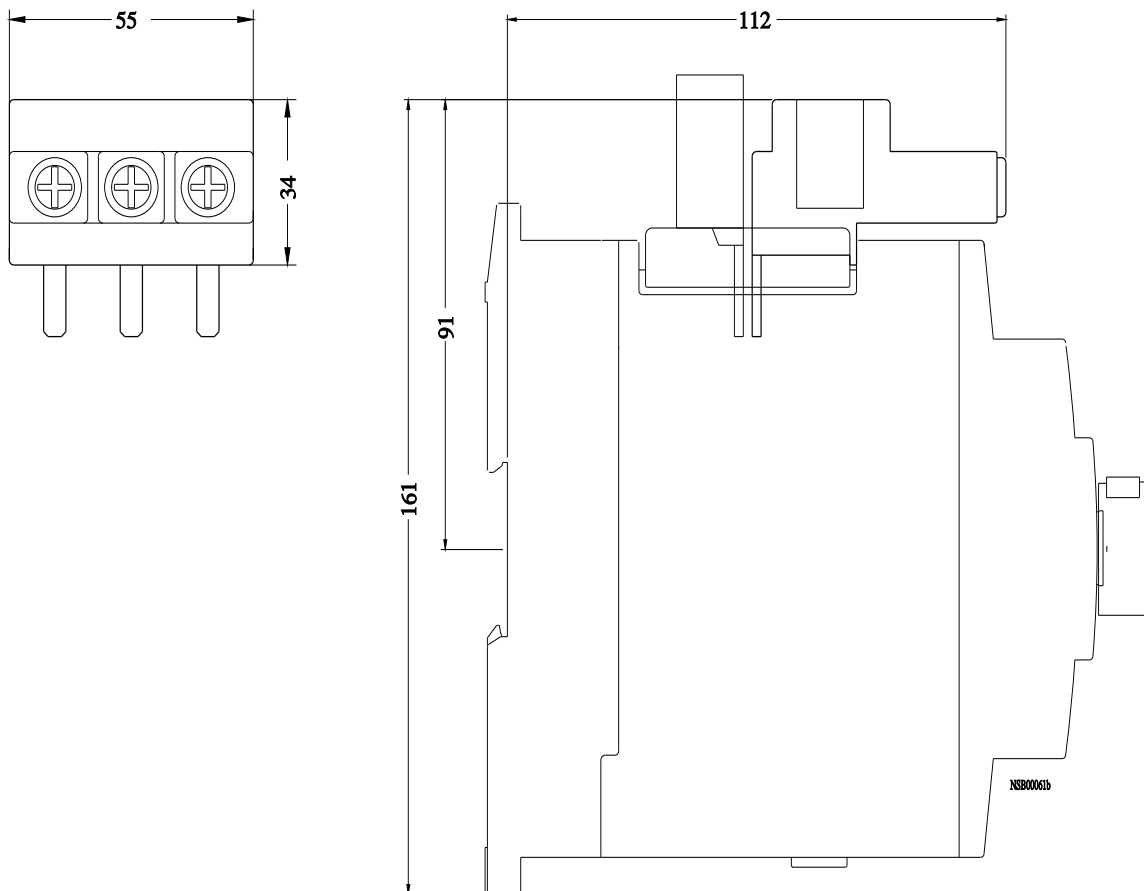

last modified:

1/27/2022

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Siemens:

3RV19355A