



Undervoltage release 24 V DC with screw terminal for circuit breaker 3RV2

product brand name	SIRIUS
product category	Auxiliary release
product designation	undervoltage release
suitability for use	motor circuit breaker
General technical data	
size of the circuit-breaker	S00, S0, S2, S3
operating power at DC maximum	2.1 W
insulation voltage	
• rated value	690 V
• with degree of pollution 3 at AC rated value	690 V
degree of pollution	3
break time maximum	20 ms
reference code according to DIN 40719 extended according to IEC 204-2 according to IEC 750	F
reference code according to EN 61346-2	F
Substance Prohibitance (Date)	05/01/2012
SVHC substance name	Lead - 7439-92-1
type of voltage of the control supply voltage	DC
control supply voltage 1 at DC	
• rated value	24 V
number of NC contacts for auxiliary contacts instantaneous contact	0
number of NO contacts for auxiliary contacts	
• instantaneous contact	0
• leading contact	0
number of CO contacts of auxiliary contacts instantaneous contact	0
Ambient conditions	
ambient temperature	
• during operation	-20 ... +60 °C
• during storage	-50 ... +80 °C
Electrical Safety	
protection class IP on the front according to IEC 60529	IP20
touch protection on the front according to IEC 60529	finger-safe, for vertical contact from the front
Short-circuit protection	
design of short-circuit protection	fuse
Installation/ mounting/ dimensions	
fastening method	snap-on mounting
height	90 mm
width	19 mm
depth	68 mm

Connections/ Terminals

type of electrical connection for auxiliary and control circuit screw-type terminals

Approvals Certificates

General Product Approval	Test Certificates
--------------------------	-------------------



[Confirmation](#)



[Special Test Certificate](#)

Test Certificates	Marine / Shipping
-------------------	-------------------

[Type Test Certificates/Test Report](#)



Marine / Shipping	other	Railway	Environment
-------------------	-------	---------	-------------



[Miscellaneous](#)

[Confirmation](#)



[Special Test Certificate](#)

[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RV2902-1AB4>

Cax online generator




<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RV2902-1AB4>


Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RV2902-1AB4>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RV2902-1AB4&lang=en

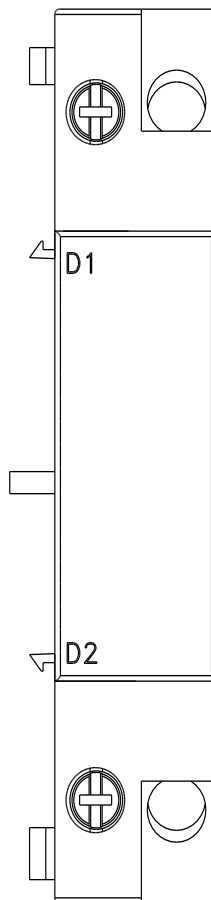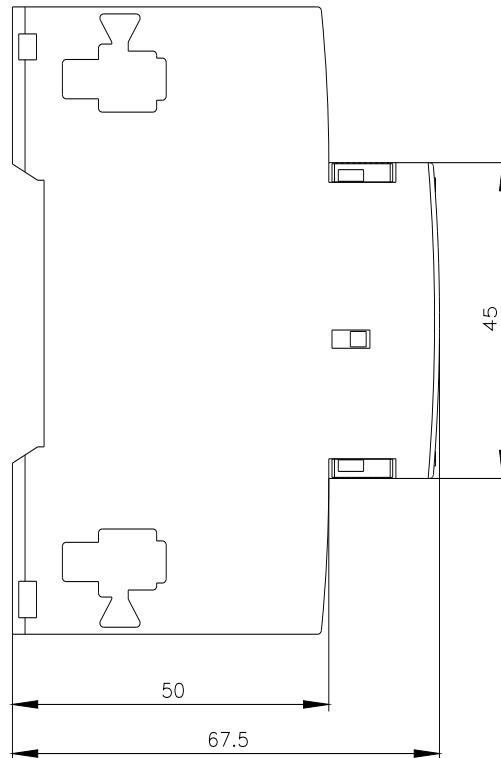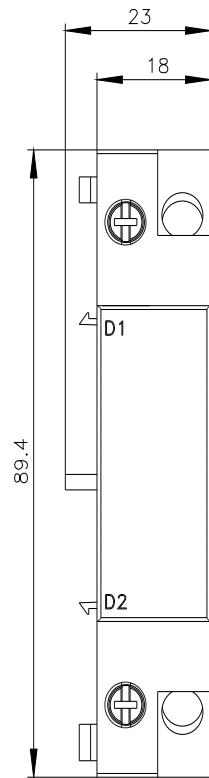

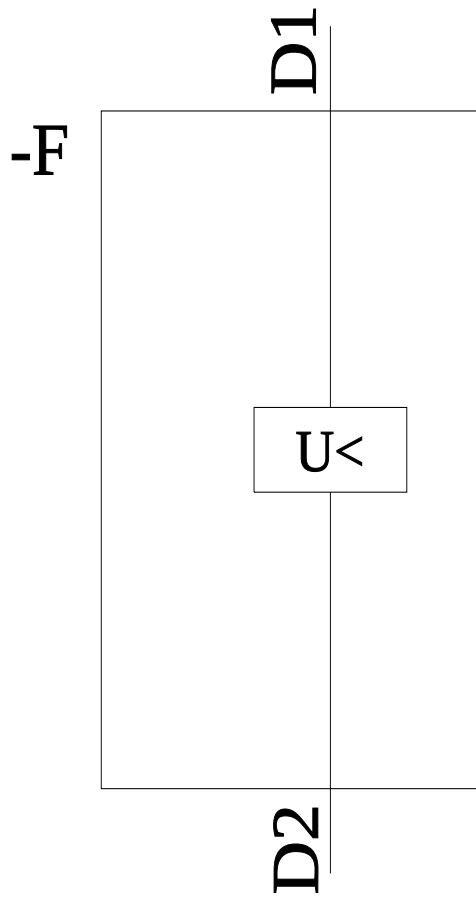

last modified:

3/11/2024 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Siemens:](#)

[3RV29021AB4](#)