



AS-Interface M12 branch U_ASI without Uaux, with M12 socket

General technical data		
Type of device		AS-Interface accessories
design of the product		AS-i M12 branch
Function		AS-i flat cable transition to M12
operating voltage according to AS-Interface specification	V	26.5 ... 31.6
Number sockets		1
Connections/ Terminals		
type of electrical connection		insulation piercing method for AS-Interface flat cable
AS interface		
• Connection		1x M12 socket
Inputs		
Inputs socket assignment		1 = AS-i "+" 3=AS-i "-"
Mechanical data		
Type of mounting		screw fixing
Contacts Load rating max	A	2
Ambient conditions		
ambient temperature	°C	-25 ... +60
ambient temperature during storage	°C	-25 ... +85
degree of protection		IP67
Certificates/ approvals		
General Product Approval		Marine / Shipping
		other

[Confirmation](#)




[Confirmation](#)

Environment

[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<https://www.siemens.com/ic10>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RX9801-0AA00>

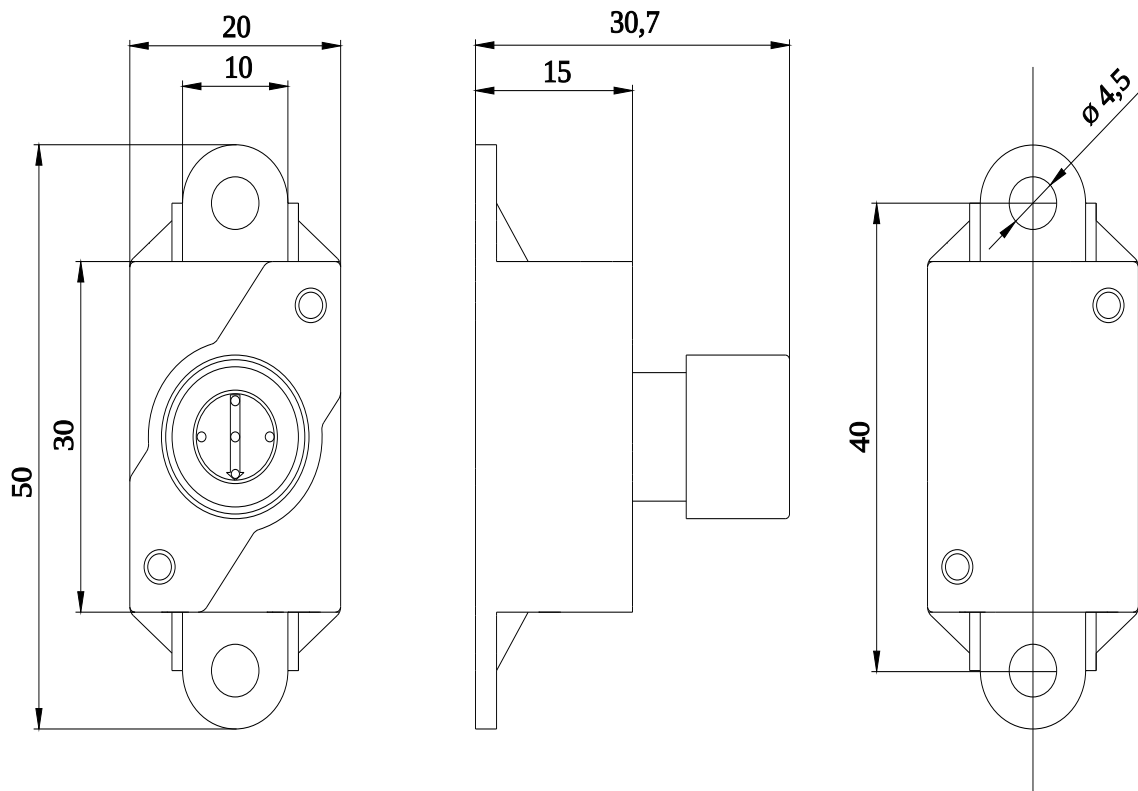

last modified:

12/23/2020 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Siemens:](#)

[3RX98010AA00](#)