








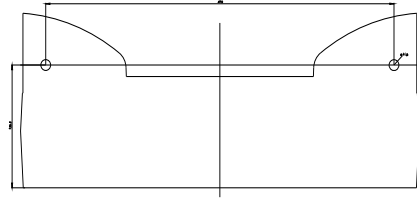
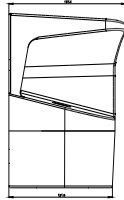
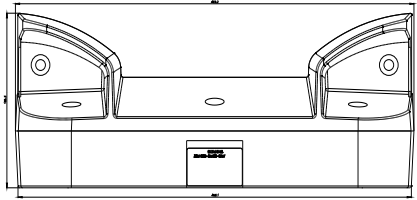


two-hand operation console for command devices, 22 mm, round, enclosure material plastic, enclosure top part gray, 3 holes for command points, 8 additional preset breaking points for 22 mm command devices, without equipment, with cable cut-outs for metric screw connections



product brand name	SIRIUS ACT
product designation	Two-hand operation console
product type designation	3SU1
<b>Enclosure</b>	
design of the housing	Two-hand operating console without standard equipment
material of the enclosure	plastic
number of command points	3
color of the enclosure top part	grey
delivery state	
• as a kit	No
• pre-wired on strip terminal	No
fastening method of the enclosure	Horizontal
<b>Actuator</b>	
design of the actuating element	Unequipped
principle of operation of the actuating element	without
product feature	
• lockout	No
• staggered switching	No
number of contact modules	0
<b>General technical data</b>	
product function	
• positive opening	No
• EMERGENCY OFF function	No
• EMERGENCY STOP function	No
product component stand/pedestal	No
protection class IP	IP66
degree of protection NEMA rating	1, 4X, 12K, indoor use only, 13
shock resistance according to IEC 60068-2-27	sinusoidal half-wave 15g / 11 ms
vibration resistance according to IEC 60068-2-6	10 ... 500 Hz: 5g
reference code according to IEC 81346-2	U
Substance Prohibitance (Date)	10/01/2014
<b>Auxiliary circuit</b>	
number of NC contacts for auxiliary contacts	0
number of NO contacts for auxiliary contacts	0
<b>Connections/ Terminals</b>	
type of electrical connection on enclosure	Cable routing at the rear 2 x M25
<b>Ambient conditions</b>	
ambient temperature	
• during operation	-25 ... +70 °C
• during storage	-40 ... +80 °C

environmental category during operation according to IEC 60721		3M6, 3S2, 3B2, 3C3, 3K6 (with relative air humidity of 10 ... 95%, no condensation in operation permitted for all devices behind front panel)					
Installation/ mounting/ dimensions							
height		185.3 mm					
width		469.2 mm					
depth		137.4 mm					
Accessories							
number of backing plates		0					
Certificates/ approvals							
General Product Approval			Declaration of Conformity				
<a href="#">Confirmation</a>							
Test Certificates		Marine / Shipping					
<a href="#">Special Test Certificate</a>		<a href="#">Type Test Certificates/Test Report</a>					
other		Environment					
<a href="#">Confirmation</a>		<a href="#">Environmental Confirmations</a>					
Further information							
<p>Siemens has decided to exit the Russian market (see here). <a href="https://press.siemens.com/global/en/pressrelease/siemens-wind-down-russian-business">https://press.siemens.com/global/en/pressrelease/siemens-wind-down-russian-business</a></p> <p>Siemens is working on the renewal of the current EAC certificates. Please contact your local Siemens office on the status of validity of the EAC certification if you intend to import or offer to supply these products to an EAC relevant market (other than the sanctioned EAEU member states Russia or Belarus).</p> <p>Information on the packaging <a href="https://support.industry.siemens.com/cs/ww/en/view/109813875">https://support.industry.siemens.com/cs/ww/en/view/109813875</a></p> <p>Information- and Downloadcenter (Catalogs, Brochures,...) <a href="https://www.siemens.com/ic10">https://www.siemens.com/ic10</a></p> <p>Industry Mall (Online ordering system) <a href="https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3SU1803-3AA00-0AA1">https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3SU1803-3AA00-0AA1</a></p> <p>Cax online generator <a href="http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&amp;mlfb=3SU1803-3AA00-0AA1">http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&amp;mlfb=3SU1803-3AA00-0AA1</a></p> <p>Service&amp;Support (Manuals, Certificates, Characteristics, FAQs,...) <a href="https://support.industry.siemens.com/cs/ww/en/ps/3SU1803-3AA00-0AA1">https://support.industry.siemens.com/cs/ww/en/ps/3SU1803-3AA00-0AA1</a></p> <p>Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...) <a href="http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3SU1803-3AA00-0AA1&amp;lang=en">http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3SU1803-3AA00-0AA1&amp;lang=en</a></p>							



---

last modified:

1/26/2022 

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Siemens:

[3SU18033AA000AA1](#)