



communication module COM060 accessory for: 3VA2 100/160/250

Model	
product brand name	SETRON
product designation	COM060 communication module
design of the product	Accessories for 3VA
accessories	Communication and measurement function
General technical data	
suitability for operation	3VA2 100/160/250 and COM800
mounting position	Right switch pocket
degree of pollution	3
overvoltage category	I
operating resource protection class	III according to IEC61558
protection class IP	IP20 according to IEC60529
Mechanical Design	
product function	
<ul style="list-style-type: none"> • electronic tripping unit power supply 	Yes
<ul style="list-style-type: none"> • detection of switch position: On, Off, Tripped 	Yes
<ul style="list-style-type: none"> • communication with function module 	Yes
<ul style="list-style-type: none"> • communication with residual current equipment 	Yes
<ul style="list-style-type: none"> • data exchange with the electronic tripping unit 	Yes
number of interfaces / of the circuit breaker communication system	1
length / of the supplied connecting cable / for circuit breaker communication system	0.15 m
type of electrical connection / of the circuit breaker communication interface	Spur line via T feeder
total length / of the circuit breaker communication system	20 m
power loss [W] / rated value	2.4 W
consumed current / maximum	0.1 A
height	63 mm
width	29 mm
number of slots	4
depth	33 mm
net weight	90 g
ambient temperature / during operation	
<ul style="list-style-type: none"> • minimum 	-25 °C
<ul style="list-style-type: none"> • maximum 	70 °C
ambient temperature / during transport	
<ul style="list-style-type: none"> • minimum 	-40 °C
<ul style="list-style-type: none"> • maximum 	80 °C
ambient temperature / during storage	
<ul style="list-style-type: none"> • minimum 	-40 °C

Further information

Siemens has decided to exit the Russian market (see here).

<https://press.siemens.com/global/en/pressrelease/siemens-wind-down-russian-business>

Siemens is working on the renewal of the current EAC certificates.

Please contact your local Siemens office on the status of validity of the EAC certification if you intend to import or offer to supply these products to an EAC relevant market (other than the sanctioned EAEU member states Russia or Belarus).

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9187-0TB10>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9187-0TB10>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9187-0TB10


CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

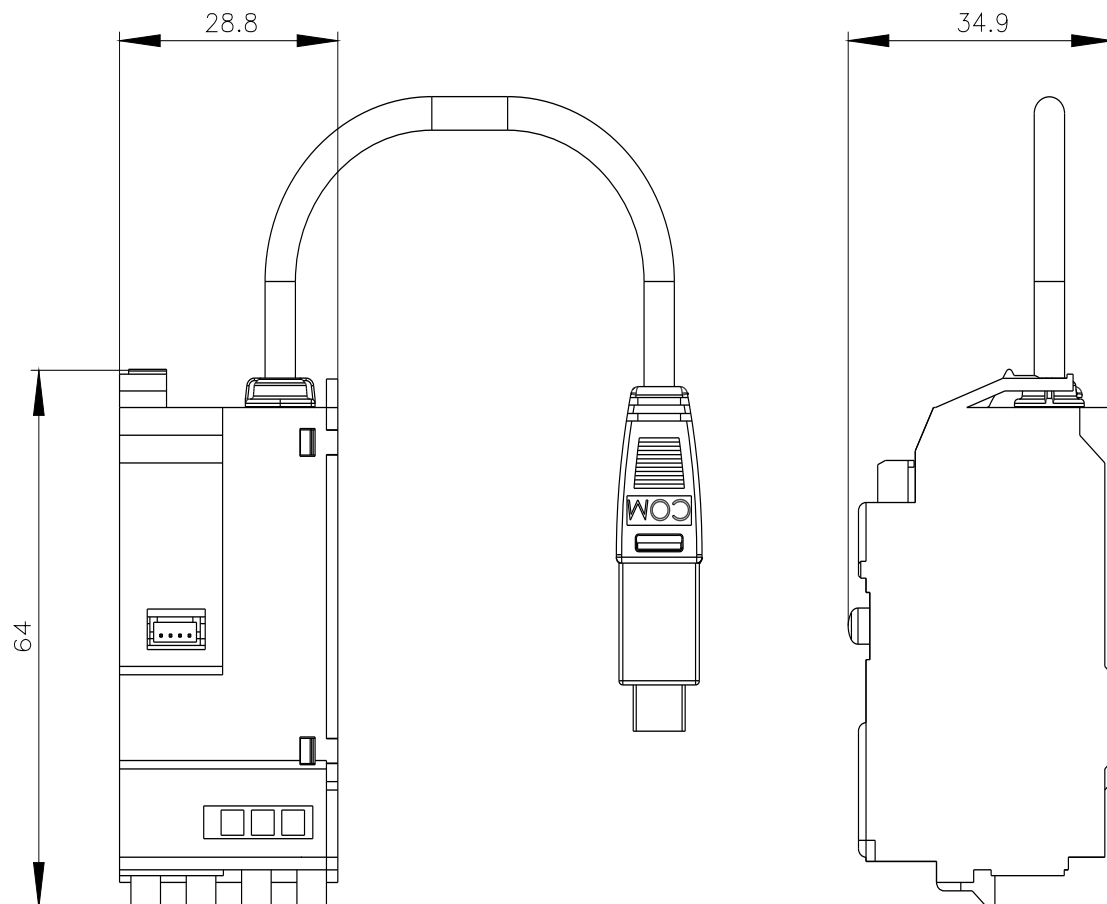

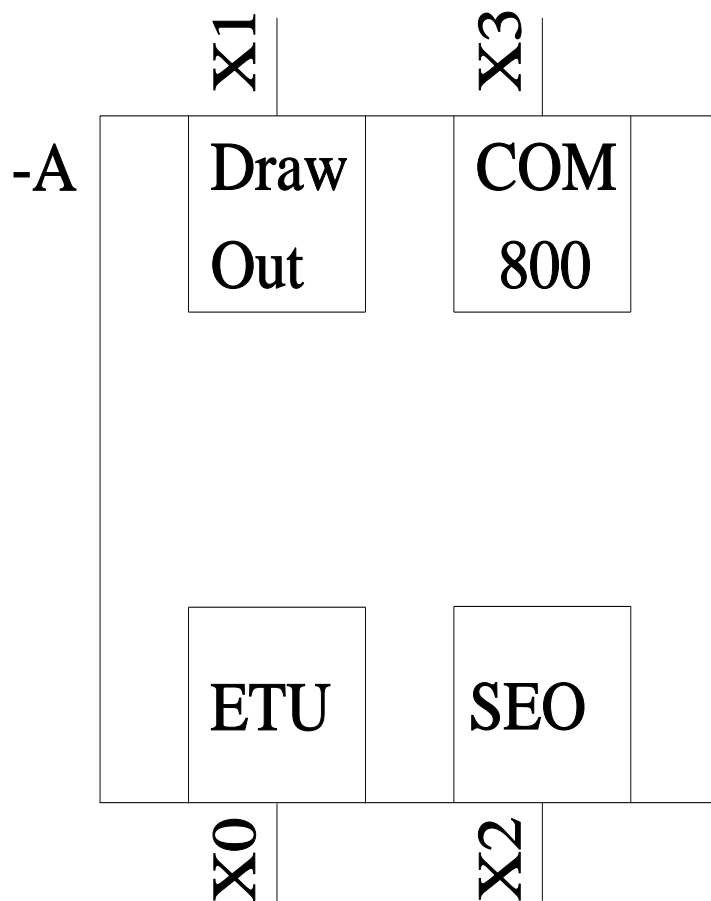

last modified:

8/15/2023 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Siemens:

[3VA91870TB10](#)