

Box terminal TS1.4 3 units 25...185 mm² accessories for: 3VA2 250



Model	
product brand name	SENTRON
product designation	accessories
design of the product	box terminal 3 units
accessories	Box terminal
General technical data	
designation / of the terminal	TS1.4
type of electrical connection / with control wire tap	No
Connections according IEC	
connectable conductor cross-section	
• for copper cable / stranded / minimum	25 mm ²
• for copper cable / stranded / maximum	185 mm ²
type of connectable conductor cross-sections / of the laminated conductor rails	
• minimum	4 - 6 x 15.5 mm x 0.8 mm
• maximum	4 - 6 x 20 mm x 1 mm
stripped length	20 mm
tightening torque / when using copper cables	
• stranded	25 - 35 mm ² : 6 Nm 50 - 185 mm ² : 12 Nm
• finely stranded	35 mm ² : 6 Nm 50 -150 mm ² : 12 Nm
Connections according UL	
stripped length	0.8 in
connectable conductor cross-section	
• for copper cable / stranded / minimum	4 AWG
• for copper cable / stranded / maximum	350 kcmil
• for copper cable / finely stranded / minimum	4 AWG
• for copper cable / finely stranded / maximum	350 kcmil
• for copper cable / finely stranded / with core end processing / minimum	4 AWG
• for copper cable / finely stranded / with core end processing / maximum	350 kcmil
tightening torque / when using copper cables	
• stranded	4 - 1 AWG: 70 lb-in 1/0 - 350 kcmil: 140 lb-in
• finely stranded	4 - 1 AWG: 70 lb-in 1/0 - 350 kcmil: 140 lb-in
Further information	

Siemens has decided to exit the Russian market (see here).

<https://press.siemens.com/global/en/pressrelease/siemens-wind-down-russian-business>

Siemens is working on the renewal of the current EAC certificates.

Please contact your local Siemens office on the status of validity of the EAC certification if you intend to import or offer to supply these products to an EAC relevant market (other than the sanctioned EAEU member states Russia or Belarus).

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9263-0JA12>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9263-0JA12>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9263-0JA12

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

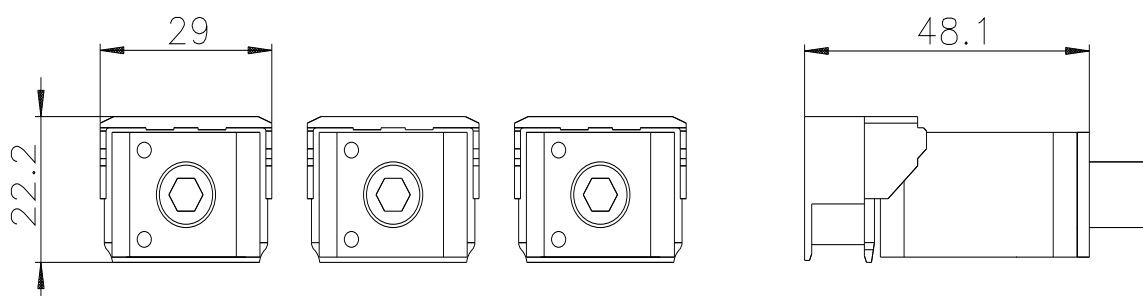

last modified:

8/19/2022 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Siemens:

[3VA92630JA12](#)