



synchronizable motor operator 24 V DC accessory for: 3VA6 150/250 3VA5 250

| Model | |
|--|--|
| product brand name | SETRON |
| product designation | Accessories |
| design of the product | Motorized operating mechanism with stored energy mechanism (SEO) |
| General technical data | |
| make time / typical | 0.08 s |
| break time / typical | 0.08 s |
| Voltage | |
| type of voltage / of the operating voltage / for actuation | DC |
| Rated control supply voltage U_s with DC | |
| • minimum | 24 V |
| • maximal | 24 V |
| operating apparent power | 300 VA |
| Mechanical Design | |
| height | 118.7 mm |
| width | 105 mm |
| depth | 162.8 mm |
| connectable conductor cross-section / solid | |
| • minimum | 1.5 mm ² |
| • maximum | 2.5 mm ² |
| connectable conductor cross-section / finely stranded / with core end processing | |
| • minimum | 1.5 mm ² |
| • maximum | 2.5 mm ² |
| connectable conductor cross-section / stranded | |
| • minimum | 1.5 mm ² |
| • maximum | 2.5 mm ² |
| ambient temperature / during operation | |
| • minimum | -25 °C |
| • maximum | 70 °C |
| tightening torque | |
| • minimum | 0.36 N·m |
| • maximum | 0.44 N·m |
| ambient temperature / during storage | |
| • minimum | -40 °C |
| • maximum | 80 °C |
| Connections according IEC | |
| stripped length | 7 mm |
| Further information | |

Siemens has decided to exit the Russian market (see here).
<https://press.siemens.com/global/en/pressrelease/siemens-wind-down-russian-business>

Siemens is working on the renewal of the current EAC certificates.

Please contact your local Siemens office on the status of validity of the EAC certification if you intend to import or offer to supply these products to an EAC relevant market (other than the sanctioned EAEU member states Russia or Belarus).

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9277-0HC10>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9277-0HC10>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)



http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9277-0HC10


CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

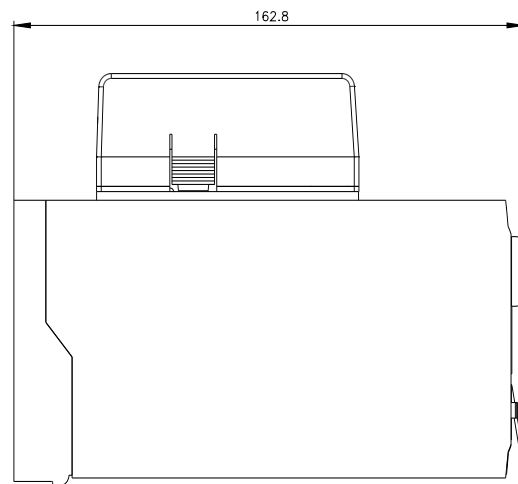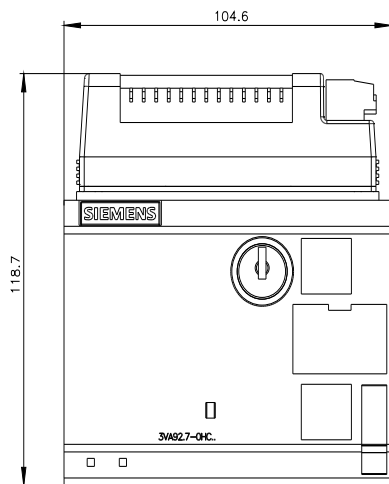

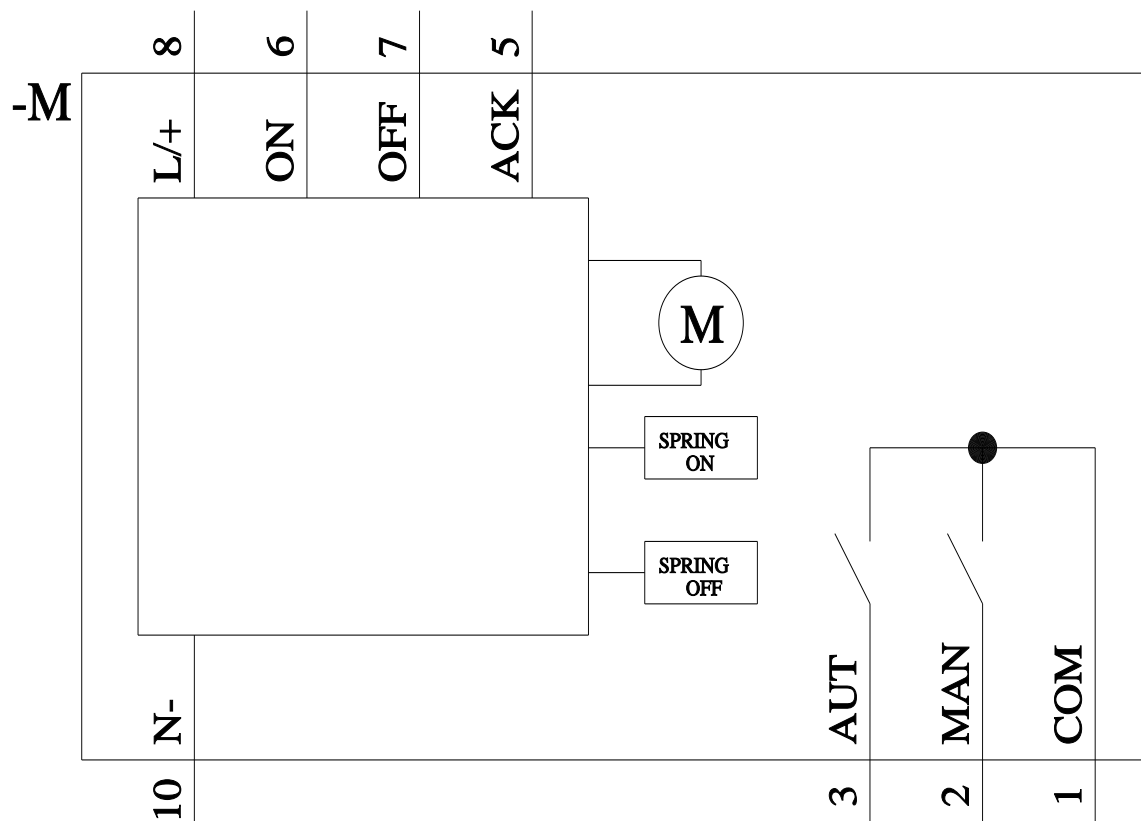

last modified:

8/15/2023 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Siemens:

[3VA92770HC10](#)