

SUPPRESSOR FOR CONTACTORS



RC, 48 VAC/DC, 15 VA/W

Art.No.: 20001  
Weight: 0.014  
Country of origin: CZ  
Model designation: RC-A 12/48

48 V AC/DC  
RC  
For other configurations and voltages, please inquire.

Link to Product

Illustration

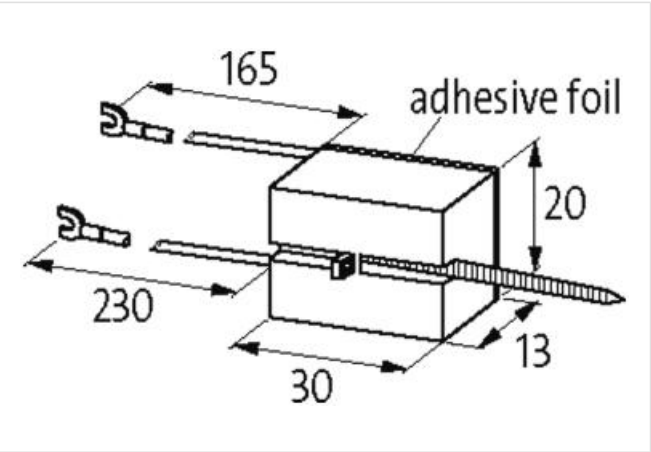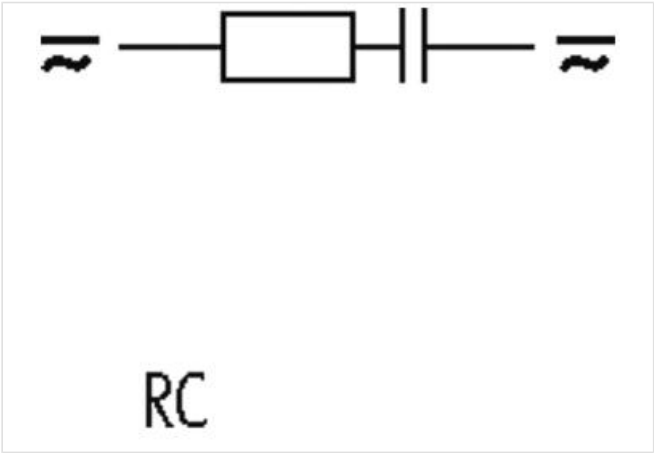

Product may differ from Image



Commercial data	
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013

ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC002498
customs tariff number	85363010
GTIN	4048879020749
Packaging unit	1

**Compatibility | Compatible with**

Appropriate contactors	universal
------------------------	-----------

**Electrical data**

Damping factor	1.5× UN
Holding power max.	15 W

**Electrical data | Input**

Input voltage AC min.	24 V
Input voltage AC max.	60 V
Input voltage DC min.	24 V
Input voltage DC max.	60 V

**Installation | Connection**

Connection information	self-securing cable forks
------------------------	---------------------------

**Device protection | Media**

Flame resistance	flame retardant
------------------	-----------------

**Mechanical data | Material data**

Combustibility class housing (UL94)	V-0
Material housing	Plastic

**Mechanical data | Mounting data**

Height	30 mm
Width	20 mm
Depth	13 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	70 °C

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Murrelektronik:](#)

[20001](#)