

SUPPRESSOR FOR CONTACTORS

Diode, 24....240 VDC, 50 W

Art.No.: 26020

Weight: 0.017

Country of origin: CZ

Model designation: LG-BU 1/240



24...240 V DC

Diode

For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

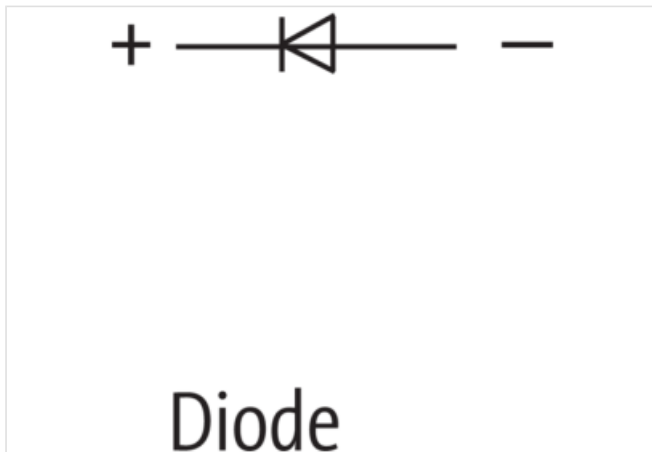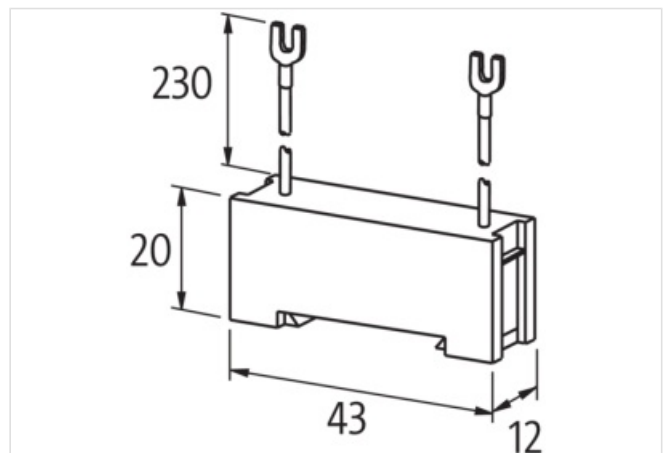

Product may differ from Image



Commercial data

URL Webshop	https://shop.murrelektronik.com/26020
GTIN	4048879018647
ECLASS-6.0	27371013
ECLASS-6.1	27371013

ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
EAN	4048879018647

Electrical data

Holding power max.	50 W
--------------------	------

Electrical data | Input

Input voltage DC min.	24 V
Input voltage DC max.	240 V

Mechanical data | Mounting data

Height	20 mm
Width	43 mm
Depth	12 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Murrelektronik:](#)

[26020](#)