


## Modlight Illumix Classic Line 12W

LED machine lamp, IP67, 24VDC, M12 connection

Modlight Illumix Classic Line  
12 W

### [Link to Product](#)

#### Illustration

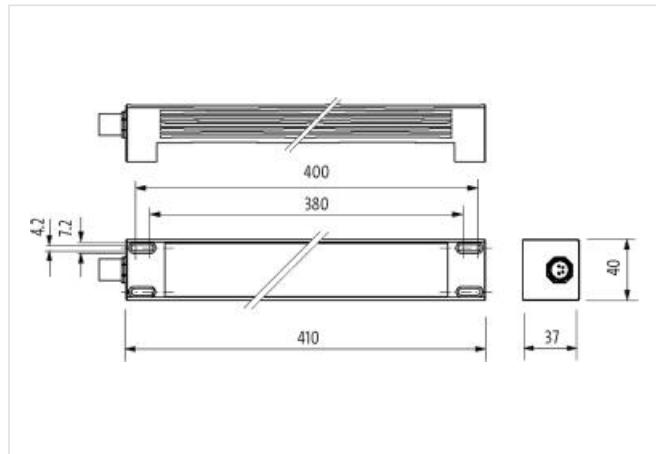

Product may differ from Image



#### Technical Data

Operating voltage	24 V DC (21.6...27.6 V DC)
No. of poles	4-pole
Coding	A-coded
Connection	M12 (male)
Luminaire light yield	approx. 105 lm/W
Luminaire light current	approx. 1260 lm
Color reproduction (Ra)	> 80
Light color	Daylight white, approx. 5500 K

The information in this brochure has been compiled with the utmost care.

Liability for the correctness, completeness and topicality of the information is restricted to gross negligence. Version: 2022-09-02

Murrelektronik Inc. | 1327 Northbrook Parkway, Suite 460 | Suwanee, GA 30024 | Fon +1 770 497-9292 | Fax +1 770 497-9391 | [shop@murrinc.com](mailto:shop@murrinc.com) | [shop.murrinc.com](http://shop.murrinc.com)

Lighting angle	> 120°
Input current	12 W

**General data**

Mounting method	rotatable
Temperature range	-30...+50 °C
Material (housing)	Anodized aluminum
Material (light cover)	diffuse single-pane safety glass (ESG), 4 mm
Installation altitude	Operation up to 2 000 m
Vibration stress	2...9 Hz/10 mm; 9...200 Hz/3 g
Screw head-Ø	max. 12 mm/M5
Relative humidity	5...95%
Protection	IP67
Dimensions H×W×D	37×410×40 mm (1.46×16.14×1.57 in)
Shock load	50 g, 11 ms

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Murrelektronik:](#)

[4000-75801-1415012](#)