

EOL - K 4-24 PLUG-IN RELAY




Product discontinued, no alternative

Art.No.: 61422
Weight: 0.03
Country of origin: SI
Model designation: 4-24

4 NO/NC contacts
24 V DC
Relays with other voltage available on request.

Link to Product

Illustration

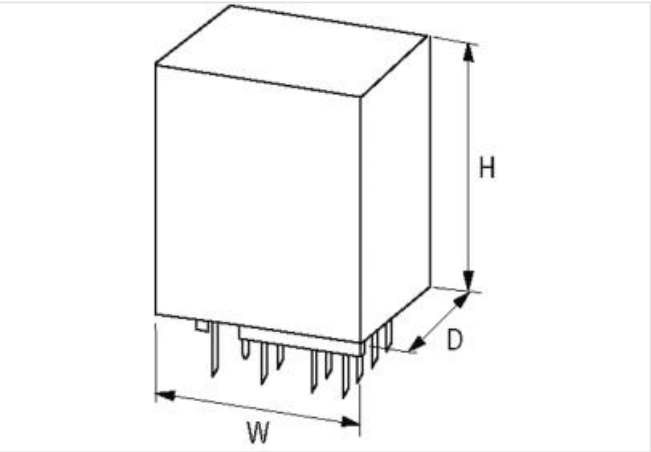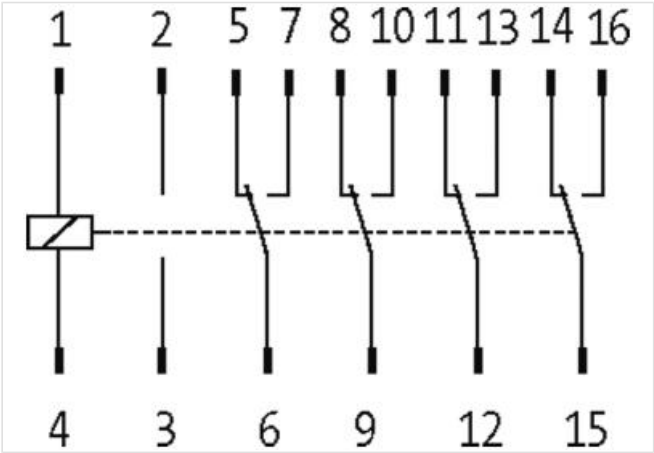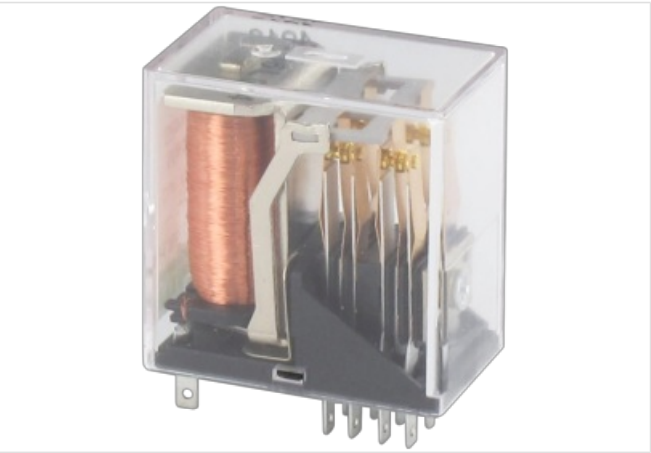

Product may differ from Image

Commercial data	
ECLASS-6.0	27371001
ECLASS-7.0	27371001
ECLASS-8.0	27371001
ECLASS-9.0	27371001
ETIM-5.0	EC001437
customs tariff number	85364900
GTIN	4048879025713
Packaging unit	1

Electrical data

Holding power max.	0,9 W
--------------------	-------

Electrical data | Output

Power rating AC max.	50 VA
----------------------	-------

Power rating DC max.	35 W
----------------------	------

Switching voltage AC max.	125 V
---------------------------	-------

Switching voltage DC max.	250 V
---------------------------	-------

Switching current max.	2 A
------------------------	-----

Mechanical data | Material data

Material contact	AgHv, AgNi
------------------	------------

Mechanical data | Mounting data

Height	30 mm
--------	-------

Width	30 mm
-------	-------

Depth	19 mm
-------	-------

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Murrelektronik:](#)

[61422](#)