


EZ-SCREEN LS Side Brackets


Supplement

Guide to mounting the EZS LS side brackets. Refer to the EZ-SCREEN LS installation manual (p/n [179480](#)) for complete mounting, alignment, and installation instructions, including dimensional information.

- 1 Adjust clamp screw to loosen or tighten clamp.




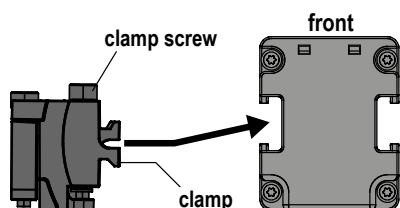


- 2 Slide inner bracket assembly into outer bracket groove.

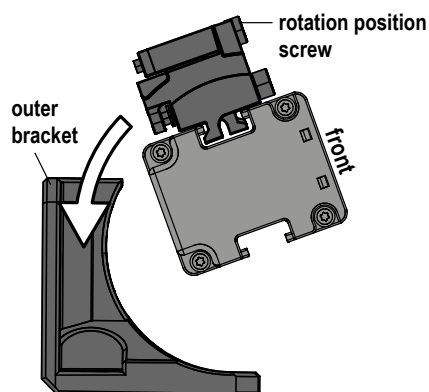

(Depending on your configuration, it may be helpful to mount the outer bracket to the mount surface first before Step 2 process)

- 3 With the light screen aligned, tighten rotation position screw to complete installation.

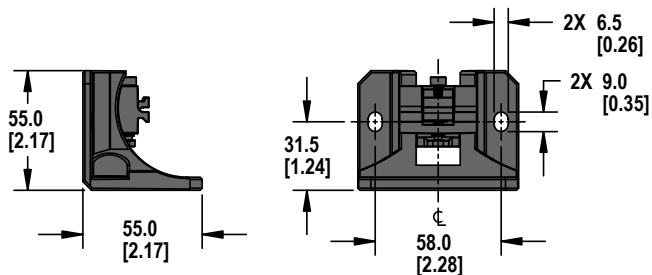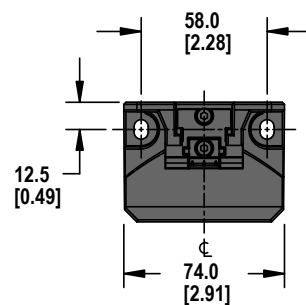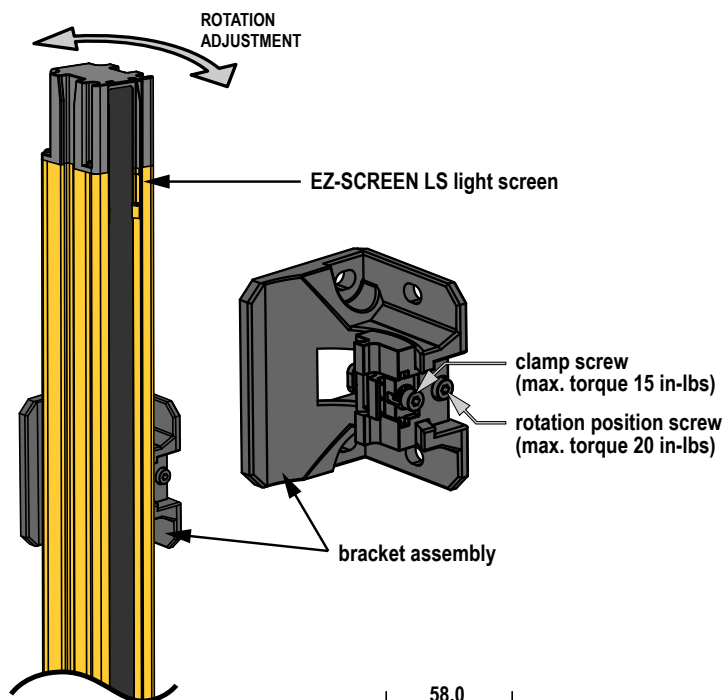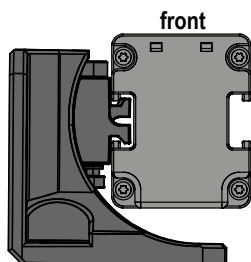

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Banner Engineering:](#)

[EZLSA-MBK-16](#) [SLLCE23-1820-S](#) [SLLCE23-420-S](#) [SLLCE23-560-S](#) [SLLCE23-630-S](#) [SLLCE40-1190-S](#) [SLLCE40-630-S](#) [SLLCP14-1050P55](#) [SLLCP14-420P88](#) [SLLCP14-560](#) [SLLCP23-1050](#) [SLLCP23-1120-B16](#) [SLLCP23-420-B16](#) [SLLCP23-630](#) [SLLCP23-700P88](#) [SLLCP23-770-B16](#) [SLLCR23-1820-S](#) [SLLCR23-420-S](#) [SLLCR23-560-S](#) [SLLCR23-630-S](#) [SLLCR40-1190-S](#) [SLLCR40-630-S](#) [SLLR14-1260-S](#) [SLLR14-350-S](#) [SLLR14-630-S](#) [SLLR23-1470-S](#) [SLLR23-840-S](#) [SLLR40-1540-S](#) [SLLP14-630P88](#) [SLLP14-840P88](#) [SLLR14-1260-S](#) [SLLR14-350-S](#) [SLLR14-630-S](#) [SLLR23-1470-S](#) [SLLR23-840-S](#) [SLLR40-1540-S](#) [SLLCE14-1120-S](#) [SLLCE14-1190-S](#) [SLLCE14-1260-S](#) [SLLCE14-1330-S](#) [SLLCE14-1400-S](#) [SLLCE14-1470-S](#) [SLLCE14-1540-S](#) [SLLCE14-1610-S](#) [SLLCE14-1680-S](#) [SLLCE14-1750-S](#) [SLLCE14-1820-S](#) [SLLCE14-350-S](#) [SLLCE14-420-S](#) [SLLCE14-490-S](#) [SLLCE14-560-S](#) [SLLCE14-630-S](#) [SLLCE14-700-S](#) [SLLCE14-770-S](#) [SLLCE14-840-S](#) [SLLCE14-910-S](#) [SLLCE14-980-S](#) [SLLCE23-1050-S](#) [SLLCE23-1120-S](#) [SLLCE23-1190-S](#) [SLLCE23-1260P8](#) [SLLCE23-1260-S](#) [SLLCE23-1330-S](#) [SLLCE23-1400-S](#) [SLLCE23-1470-S](#) [SLLCE23-1540-S](#) [SLLCE23-1610-S](#) [SLLCE23-1680-S](#) [SLLCE23-1750-S](#) [SLLCE23-1820P8](#) [SLLCE23-350-S](#) [SLLCE23-490-S](#) [SLLCE23-700-S](#) [SLLCE23-770-S](#) [SLLCE23-840-S](#) [SLLCE23-910P8](#) [SLLCE23-910-S](#) [SLLCE23-980-S](#) [SLLCE40-1050-S](#) [SLLCE40-1120-S](#) [SLLCE40-1260-S](#) [SLLCE40-1330-S](#) [SLLCE40-1400-S](#) [SLLCE40-1470-S](#) [SLLCE40-1540-S](#) [SLLCE40-1610-S](#) [SLLCE40-1680-S](#) [SLLCE40-1750-S](#) [SLLCE40-1820P8](#) [SLLCE40-1820-S](#) [SLLCE40-350-S](#) [SLLCE40-420-S](#) [SLLCE40-490-S](#) [SLLCE40-560-S](#) [SLLCE40-700-S](#) [SLLCE40-770-S](#) [SLLCE40-840-S](#) [SLLCE40-910-S](#) [SLLCE40-980-S](#) [SLLCP14-1050](#)