


# Bocube

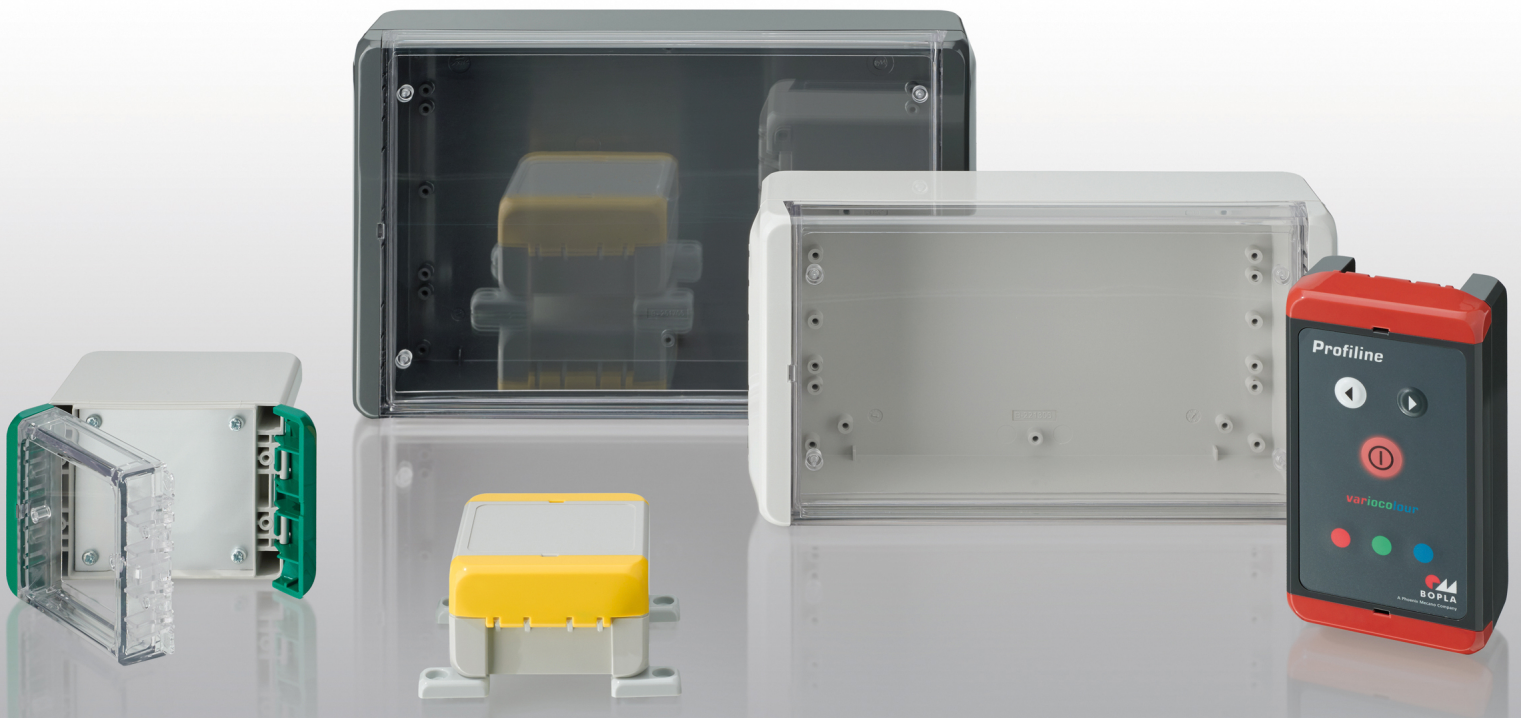

Detailed product information  
can be found on  
[www.bopla.de](http://www.bopla.de)



- Patented, innovative, hinged quick-release catch technology without screws: open with a screwdriver, close by hand
- 23 sizes, 138 standard combinations possible
- 2 material types: ABS or PC UL 94 V0, flame-resistant and self-extinguishing
- Captive lid with membrane keypad area, available in 2 variants: grey or crystal-clear
- Elegant design, hinged quick-release catches available in different colours
- Excellent recyclability because of mono-material plastics without injection-moulded metal parts

## Colour:

Graphite grey, similar to RAL 7024; light grey, similar to RAL 7035; special colours on request

## Protection class:

IP 66/IP 68 - 1,2m (2 hours) DIN EN 60529

## Enclosure material:

ABS or PC UL 94 V0 (material is suitable for outdoor use; f1-listing according to UL 746C)

PU seal, foamed; for details please see Technical Information



**BOPLA**

A Phoenix Mecano Company

## Unique, innovative, versatile enclosure made of ABS or polycarbonate UL 94 V0



Bocube consists of few parts, so it can easily be mounted by hand. Open it by means of a screwdriver (size 3).



The hinged catch ensures that the lid is captive and can be used ideally as a display enclosure.



As an alternative to the hinged catch, the enclosures can be screwed. The hinged catch conceals the screws.



Wall brackets can be used for all Bocube sizes and are screwed into the drilling holes on the back of the enclosure base.



The blanking plugs allow the hinged side to be selected as required.



Rectangular front panels or PCBs can be mounted in the base (by using distance bolts) and in the lid.



Coloured hinges (tool-operated or hand-operated, as required). Transparent hinges available on request.



PC UL 94 V0 material is suitable for outdoor use (f1 listing acc. to UL 746C and corresponds to requirements set R 22 acc. to DIN EN 45545-2 of hazard level HL3).

## Bocube | Polycarbonate



### Enclosures, polycarbonate UL 94 V0, single-coloured


| Model               | Order no. | A   | B   | C   | a1  | a2    | b1  | b2    | c1    | Colour        |
|---------------------|-----------|-----|-----|-----|-----|-------|-----|-------|-------|---------------|
| B 080805 PC-V0 7024 | 96011114  | 89  | 80  | 47  | 50  | 52.6  | 68  | 73.6  | 40.5  | Graphite grey |
| B 080805 PC-V0 7035 | 96011115  | 89  | 80  | 47  | 50  | 52.6  | 68  | 73.6  | 40.5  | Light grey    |
| B 100804 PC-V0 7024 | 96012144  | 113 | 80  | 40  | 74  | 76.4  | 68  | 73.4  | 32    | Graphite grey |
| B 100804 PC-V0 7035 | 96012145  | 113 | 80  | 40  | 74  | 76.4  | 68  | 73.4  | 32    | Light grey    |
| B 100806 PC-V0 7024 | 96012124  | 113 | 80  | 60  | 74  | 76.4  | 68  | 73.4  | 52    | Graphite grey |
| B 100806 PC-V0 7035 | 96012125  | 113 | 80  | 60  | 74  | 76.4  | 68  | 73.4  | 52    | Light grey    |
| B 100809 PC-V0 7024 | 96012134  | 113 | 80  | 90  | 74  | 75.9  | 68  | 72.9  | 82    | Graphite grey |
| B 100809 PC-V0 7035 | 96012135  | 113 | 80  | 90  | 74  | 75.9  | 68  | 72.9  | 82    | Light grey    |
| B 140804 PC-V0 7024 | 96013144  | 151 | 80  | 40  | 112 | 114.8 | 68  | 73.8  | 32    | Graphite grey |
| B 140804 PC-V0 7035 | 96013145  | 151 | 80  | 40  | 112 | 114.8 | 68  | 73.8  | 32    | Light grey    |
| B 140806 PC-V0 7024 | 96013124  | 151 | 80  | 60  | 112 | 114.4 | 68  | 73.4  | 52    | Graphite grey |
| B 140806 PC-V0 7035 | 96013125  | 151 | 80  | 60  | 112 | 114.4 | 68  | 73.4  | 52    | Light grey    |
| B 140809 PC-V0 7024 | 96013134  | 151 | 80  | 90  | 112 | 113.9 | 68  | 72.9  | 82    | Graphite grey |
| B 140809 PC-V0 7035 | 96013135  | 151 | 80  | 90  | 112 | 113.9 | 68  | 72.9  | 82    | Light grey    |
| B 141306 PC-V0 7024 | 96013224  | 151 | 125 | 60  | 112 | 114.4 | 113 | 118.4 | 52    | Graphite grey |
| B 141306 PC-V0 7035 | 96013225  | 151 | 125 | 60  | 112 | 114.4 | 113 | 118.4 | 52    | Light grey    |
| B 141309 PC-V0 7024 | 96013234  | 151 | 125 | 90  | 112 | 113.9 | 113 | 117.9 | 82    | Graphite grey |
| B 141309 PC-V0 7035 | 96013235  | 151 | 125 | 90  | 112 | 113.9 | 113 | 117.9 | 82    | Light grey    |
| B 180806 PC-V0 7024 | 96014124  | 191 | 80  | 60  | 152 | 154.4 | 68  | 73.4  | 52    | Graphite grey |
| B 180806 PC-V0 7035 | 96014125  | 191 | 80  | 60  | 152 | 154.4 | 68  | 73.4  | 52    | Light grey    |
| B 180809 PC-V0 7024 | 96014134  | 191 | 80  | 90  | 152 | 153.9 | 68  | 72.9  | 82    | Graphite grey |
| B 180809 PC-V0 7035 | 96014135  | 191 | 80  | 90  | 152 | 153.9 | 68  | 72.9  | 82    | Light grey    |
| B 181304 PC-V0 7024 | 96014244  | 191 | 125 | 40  | 152 | 154.6 | 113 | 118.8 | 32    | Graphite grey |
| B 181304 PC-V0 7035 | 96014245  | 191 | 125 | 40  | 152 | 154.6 | 113 | 118.8 | 32    | Light grey    |
| B 181306 PC-V0 7024 | 96014224  | 191 | 125 | 60  | 152 | 154.4 | 113 | 118.4 | 52    | Graphite grey |
| B 181306 PC-V0 7035 | 96014225  | 191 | 125 | 60  | 152 | 154.4 | 113 | 118.4 | 52    | Light grey    |
| B 181309 PC-V0 7024 | 96014234  | 191 | 125 | 90  | 152 | 153.9 | 113 | 117.9 | 82    | Graphite grey |
| B 181309 PC-V0 7035 | 96014235  | 191 | 125 | 90  | 152 | 153.9 | 113 | 117.9 | 82    | Light grey    |
| B 221304 PC-V0 7024 | 96015244  | 231 | 125 | 40  | 192 | 194.6 | 113 | 118.8 | 32    | Graphite grey |
| B 221304 PC-V0 7035 | 96015245  | 231 | 125 | 40  | 192 | 194.6 | 113 | 118.8 | 32    | Light grey    |
| B 221306 PC-V0 7024 | 96015224  | 231 | 125 | 60  | 192 | 194.4 | 113 | 118.4 | 52    | Graphite grey |
| B 221306 PC-V0 7035 | 96015225  | 231 | 125 | 60  | 192 | 194.4 | 113 | 118.4 | 52    | Light grey    |
| B 221309 PC-V0 7024 | 96015234  | 231 | 125 | 90  | 192 | 194.1 | 113 | 117.9 | 82    | Graphite grey |
| B 221309 PC-V0 7035 | 96015235  | 231 | 125 | 90  | 192 | 194.1 | 113 | 117.9 | 82    | Light grey    |
| B 261704 PC-V0 7024 | 96016344  | 271 | 170 | 40  | 232 | 234.8 | 158 | 163.8 | 31.5  | Graphite grey |
| B 261704 PC-V0 7035 | 96016345  | 271 | 170 | 40  | 232 | 234.8 | 158 | 163.8 | 31.5  | Light grey    |
| B 261706 PC-V0 7024 | 96016324  | 271 | 170 | 60  | 232 | 234.4 | 158 | 163.4 | 51.5  | Graphite grey |
| B 261706 PC-V0 7035 | 96016325  | 271 | 170 | 60  | 232 | 234.4 | 158 | 163.4 | 51.5  | Light grey    |
| B 261709 PC-V0 7024 | 96016334  | 271 | 170 | 90  | 232 | 234.1 | 158 | 163.1 | 81.5  | Graphite grey |
| B 261709 PC-V0 7035 | 96016335  | 271 | 170 | 90  | 232 | 234.1 | 158 | 163.1 | 81.5  | Light grey    |
| B 261712 PC-V0 7024 | 96016364  | 271 | 170 | 120 | 232 | 233.4 | 158 | 162.4 | 111.5 | Graphite grey |
| B 261712 PC-V0 7035 | 96016365  | 271 | 170 | 120 | 232 | 233.4 | 158 | 162.4 | 111.5 | Light grey    |
| B 233012 PC-V0 7024 | 96018564  | 239 | 300 | 120 | 186 | 188.1 | 288 | 289.5 | 109   | Graphite grey |
| B 233012 PC-V0 7035 | 96018565  | 239 | 300 | 120 | 186 | 188.1 | 288 | 289.5 | 109   | Light grey    |
| B 273612 PC-V0 7024 | 96017664  | 284 | 364 | 120 | 231 | 233.1 | 352 | 353.5 | 109   | Graphite grey |
| B 273612 PC-V0 7035 | 96017665  | 284 | 364 | 120 | 231 | 233.1 | 352 | 353.5 | 109   | Light grey    |

Scope Of Delivery: Lid and base, hinged quick-release catches



**BOPLA**

A Phoenix Mecano Company

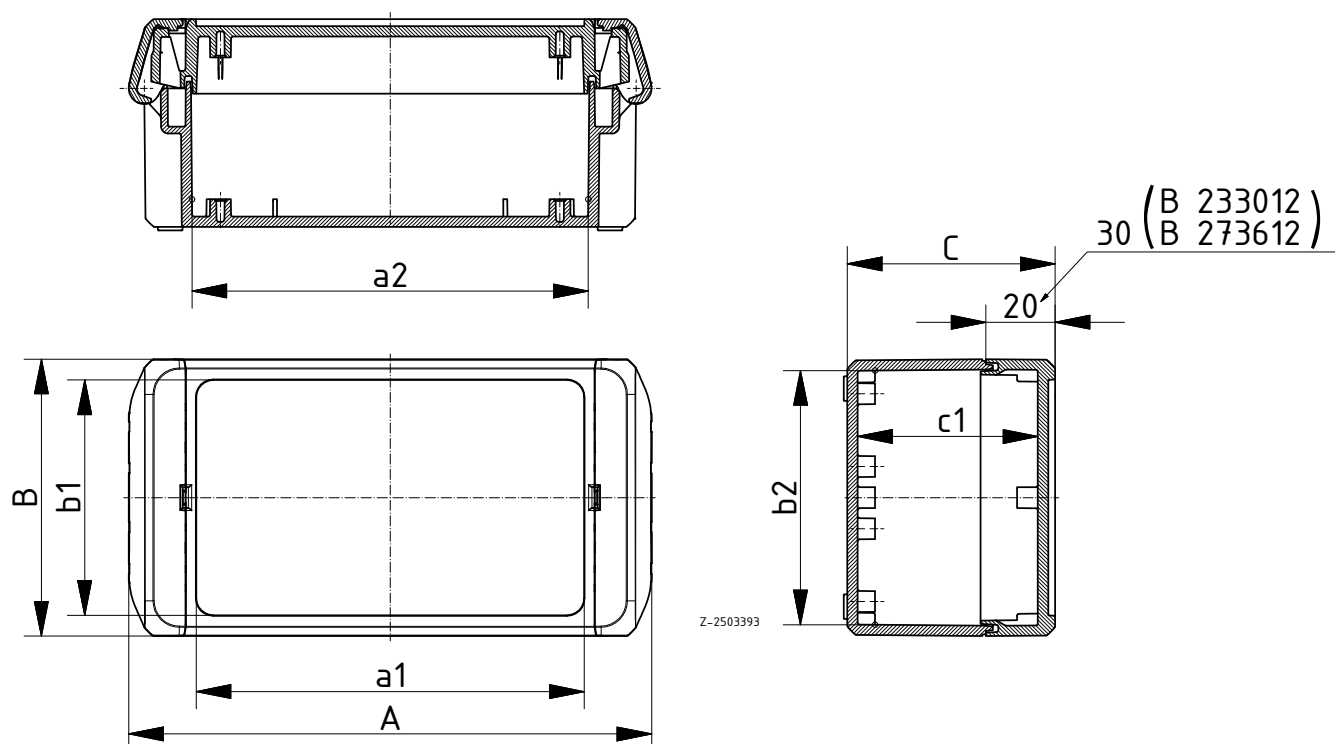

Z-2503393

## Bocube | Polycarbonate



Enclosures, polycarbonate UL 94 V0, crystal-clear lid


| Model                 | Order no. | A   | B   | C   | a1  | a2    | b1  | b2    | c1    | Colour        |
|-----------------------|-----------|-----|-----|-----|-----|-------|-----|-------|-------|---------------|
| B 080805 PC-V0-G 7024 | 96021114  | 89  | 80  | 47  | 50  | 52.6  | 68  | 73.6  | 40.5  | Graphite grey |
| B 080805 PC-V0-G 7035 | 96021115  | 89  | 80  | 47  | 50  | 52.6  | 68  | 73.6  | 40.5  | Light grey    |
| B 100804 PC-V0-G 7024 | 96022144  | 113 | 80  | 40  | 74  | 76.4  | 68  | 73.4  | 32    | Graphite grey |
| B 100804 PC-V0-G 7035 | 96022145  | 113 | 80  | 40  | 74  | 76.4  | 68  | 73.4  | 32    | Light grey    |
| B 100806 PC-V0-G 7024 | 96022124  | 113 | 80  | 60  | 74  | 76.4  | 68  | 73.4  | 52    | Graphite grey |
| B 100806 PC-V0-G 7035 | 96022125  | 113 | 80  | 60  | 74  | 76.4  | 68  | 73.4  | 52    | Light grey    |
| B 100809 PC-V0-G 7024 | 96022134  | 113 | 80  | 90  | 74  | 75.9  | 68  | 72.9  | 82    | Graphite grey |
| B 100809 PC-V0-G 7035 | 96022135  | 113 | 80  | 90  | 74  | 75.9  | 68  | 72.9  | 82    | Light grey    |
| B 140804 PC-V0-G 7024 | 96023144  | 151 | 80  | 40  | 112 | 114.8 | 68  | 73.8  | 32    | Graphite grey |
| B 140804 PC-V0-G 7035 | 96023145  | 151 | 80  | 40  | 112 | 114.8 | 68  | 73.8  | 32    | Light grey    |
| B 140806 PC-V0-G 7024 | 96023124  | 151 | 80  | 60  | 112 | 114.4 | 68  | 73.4  | 52    | Graphite grey |
| B 140806 PC-V0-G 7035 | 96023125  | 151 | 80  | 60  | 112 | 114.4 | 68  | 73.4  | 52    | Light grey    |
| B 140809 PC-V0-G 7024 | 96023134  | 151 | 80  | 90  | 112 | 113.9 | 68  | 72.9  | 82    | Graphite grey |
| B 140809 PC-V0-G 7035 | 96023135  | 151 | 80  | 90  | 112 | 113.9 | 68  | 72.9  | 82    | Light grey    |
| B 141306 PC-V0-G 7024 | 96023224  | 151 | 125 | 60  | 112 | 114.4 | 113 | 118.4 | 52    | Graphite grey |
| B 141306 PC-V0-G 7035 | 96023225  | 151 | 125 | 60  | 112 | 114.4 | 113 | 118.4 | 52    | Light grey    |
| B 141309 PC-V0-G 7024 | 96023234  | 151 | 125 | 90  | 112 | 113.9 | 113 | 117.9 | 82    | Graphite grey |
| B 141309 PC-V0-G 7035 | 96023235  | 151 | 125 | 90  | 112 | 113.9 | 113 | 117.9 | 82    | Light grey    |
| B 180806 PC-V0-G 7024 | 96024124  | 191 | 80  | 60  | 152 | 154.4 | 68  | 73.4  | 52    | Graphite grey |
| B 180806 PC-V0-G 7035 | 96024125  | 191 | 80  | 60  | 152 | 154.4 | 68  | 73.4  | 52    | Light grey    |
| B 180809 PC-V0-G 7024 | 96024134  | 191 | 80  | 90  | 152 | 153.9 | 68  | 72.9  | 82    | Graphite grey |
| B 180809 PC-V0-G 7035 | 96024135  | 191 | 80  | 90  | 152 | 153.9 | 68  | 72.9  | 82    | Light grey    |
| B 181304 PC-V0-G 7024 | 96024244  | 191 | 125 | 40  | 152 | 154.6 | 113 | 118.8 | 32    | Graphite grey |
| B 181304 PC-V0-G 7035 | 96024245  | 191 | 125 | 40  | 152 | 154.6 | 113 | 118.8 | 32    | Light grey    |
| B 181306 PC-V0-G 7024 | 96024224  | 191 | 125 | 60  | 152 | 154.4 | 113 | 118.4 | 52    | Graphite grey |
| B 181306 PC-V0-G 7035 | 96024225  | 191 | 125 | 60  | 152 | 154.4 | 113 | 118.4 | 52    | Light grey    |
| B 181309 PC-V0-G 7024 | 96024234  | 191 | 125 | 90  | 152 | 153.9 | 113 | 117.9 | 82    | Graphite grey |
| B 181309 PC-V0-G 7035 | 96024235  | 191 | 125 | 90  | 152 | 153.9 | 113 | 117.9 | 82    | Light grey    |
| B 221304 PC-V0-G 7024 | 96025244  | 231 | 125 | 40  | 192 | 194.6 | 113 | 118.8 | 32    | Graphite grey |
| B 221304 PC-V0-G 7035 | 96025245  | 231 | 125 | 40  | 192 | 194.6 | 113 | 118.8 | 32    | Light grey    |
| B 221306 PC-V0-G 7024 | 96025224  | 231 | 125 | 60  | 192 | 194.4 | 113 | 118.4 | 52    | Graphite grey |
| B 221306 PC-V0-G 7035 | 96025225  | 231 | 125 | 60  | 192 | 194.4 | 113 | 118.4 | 52    | Light grey    |
| B 221309 PC-V0-G 7024 | 96025234  | 231 | 125 | 90  | 192 | 194.1 | 113 | 117.9 | 82    | Graphite grey |
| B 221309 PC-V0-G 7035 | 96025235  | 231 | 125 | 90  | 192 | 194.1 | 113 | 117.9 | 82    | Light grey    |
| B 261704 PC-V0-G 7024 | 96026344  | 271 | 170 | 40  | 232 | 234.8 | 158 | 163.8 | 31.5  | Graphite grey |
| B 261704 PC-V0-G 7035 | 96026345  | 271 | 170 | 40  | 232 | 234.8 | 158 | 163.8 | 31.5  | Light grey    |
| B 261706 PC-V0-G 7024 | 96026324  | 271 | 170 | 60  | 232 | 234.4 | 158 | 163.4 | 51.5  | Graphite grey |
| B 261706 PC-V0-G 7035 | 96026325  | 271 | 170 | 60  | 232 | 234.4 | 158 | 163.4 | 51.5  | Light grey    |
| B 261709 PC-V0-G 7024 | 96026334  | 271 | 170 | 90  | 232 | 234.1 | 158 | 163.1 | 81.5  | Graphite grey |
| B 261709 PC-V0-G 7035 | 96026335  | 271 | 170 | 90  | 232 | 234.1 | 158 | 163.1 | 81.5  | Light grey    |
| B 261712 PC-V0-G 7024 | 96026364  | 271 | 170 | 120 | 232 | 233.4 | 158 | 162.4 | 111.5 | Graphite grey |
| B 261712 PC-V0-G 7035 | 96026365  | 271 | 170 | 120 | 232 | 233.4 | 158 | 162.4 | 111.5 | Light grey    |
| B 233012 PC-V0-G 7024 | 96028564  | 239 | 300 | 120 | 186 | 188.1 | 288 | 289.5 | 109   | Graphite grey |
| B 233012 PC-V0-G 7035 | 96028565  | 239 | 300 | 120 | 186 | 188.1 | 288 | 289.5 | 109   | Light grey    |
| B 273612 PC-V0-G 7024 | 96027664  | 284 | 364 | 120 | 231 | 233.1 | 352 | 353.5 | 109   | Graphite grey |
| B 273612 PC-V0-G 7035 | 96027665  | 284 | 364 | 120 | 231 | 233.1 | 352 | 353.5 | 109   | Light grey    |

Scope Of Delivery: Lid and base, hinged quick-release catches



**BOPLA**

A Phoenix Mecano Company

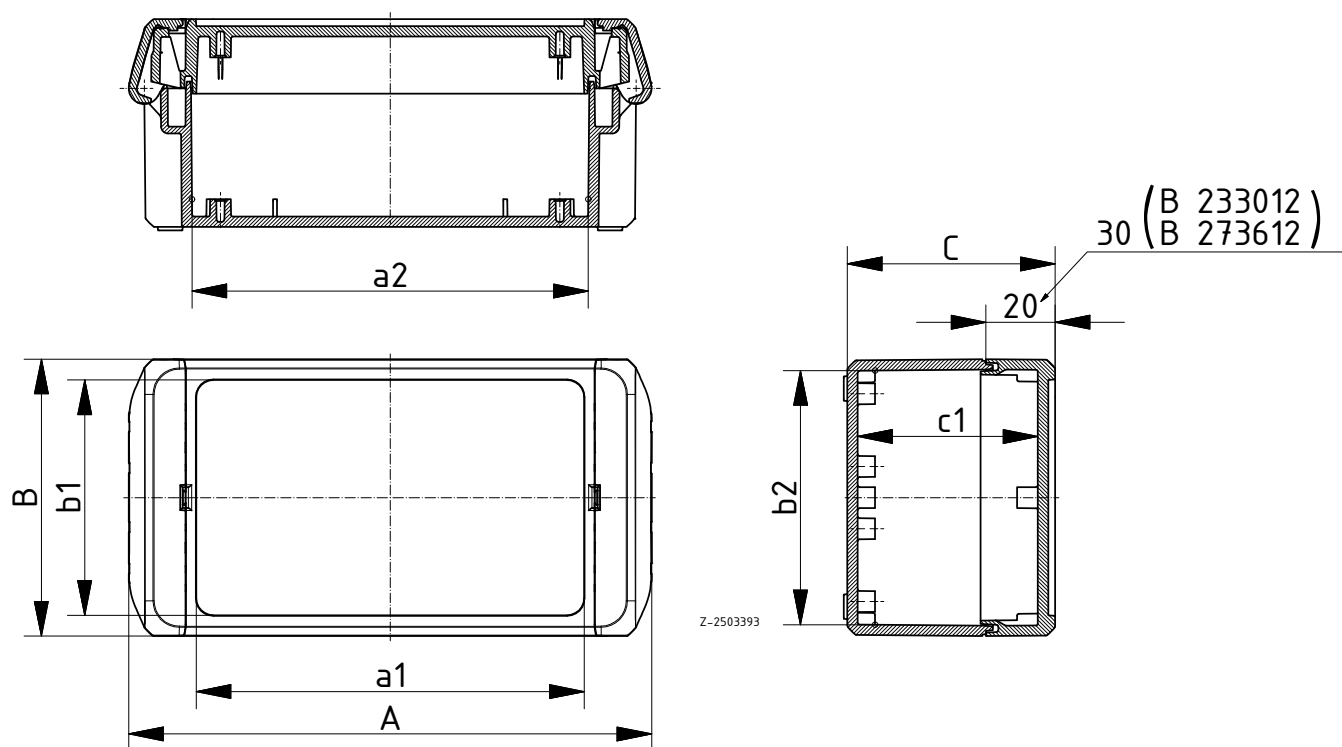

## Bocube | ABS



### Enclosures, ABS, single-coloured

| Model             | Order no. | A   | B   | C   | a1  | a2    | b1  | b2    | c1    | Colour        |
|-------------------|-----------|-----|-----|-----|-----|-------|-----|-------|-------|---------------|
| B 080805 ABS 7024 | 96031114  | 89  | 80  | 47  | 50  | 52.6  | 68  | 73.6  | 40.5  | Graphite grey |
| B 080805 ABS 7035 | 96031115  | 89  | 80  | 47  | 50  | 52.6  | 68  | 73.6  | 40.5  | Light grey    |
| B 100804 ABS 7024 | 96032144  | 113 | 80  | 40  | 74  | 76.4  | 68  | 73.4  | 32    | Graphite grey |
| B 100804 ABS 7035 | 96032145  | 113 | 80  | 40  | 74  | 76.4  | 68  | 73.4  | 32    | Light grey    |
| B 100806 ABS 7024 | 96032124  | 113 | 80  | 60  | 74  | 76.4  | 68  | 73.4  | 52    | Graphite grey |
| B 100806 ABS 7035 | 96032125  | 113 | 80  | 60  | 74  | 76.4  | 68  | 73.4  | 52    | Light grey    |
| B 100809 ABS 7024 | 96032134  | 113 | 80  | 90  | 74  | 75.9  | 68  | 72.9  | 82    | Graphite grey |
| B 100809 ABS 7035 | 96032135  | 113 | 80  | 90  | 74  | 75.9  | 68  | 72.9  | 82    | Light grey    |
| B 140804 ABS 7024 | 96033144  | 151 | 80  | 40  | 112 | 114.8 | 68  | 73.8  | 32    | Graphite grey |
| B 140804 ABS 7035 | 96033145  | 151 | 80  | 40  | 112 | 114.8 | 68  | 73.8  | 32    | Light grey    |
| B 140806 ABS 7024 | 96033124  | 151 | 80  | 60  | 112 | 114.4 | 68  | 73.4  | 52    | Graphite grey |
| B 140806 ABS 7035 | 96033125  | 151 | 80  | 60  | 112 | 114.4 | 68  | 73.4  | 52    | Light grey    |
| B 140809 ABS 7024 | 96033134  | 151 | 80  | 90  | 112 | 113.9 | 68  | 72.9  | 82    | Graphite grey |
| B 140809 ABS 7035 | 96033135  | 151 | 80  | 90  | 112 | 113.9 | 68  | 72.9  | 82    | Light grey    |
| B 141306 ABS 7024 | 96033224  | 151 | 125 | 60  | 112 | 114.4 | 113 | 118.4 | 52    | Graphite grey |
| B 141306 ABS 7035 | 96033225  | 151 | 125 | 60  | 112 | 114.4 | 113 | 118.4 | 52    | Light grey    |
| B 141309 ABS 7024 | 96033234  | 151 | 125 | 90  | 112 | 113.9 | 113 | 117.9 | 82    | Graphite grey |
| B 141309 ABS 7035 | 96033235  | 151 | 125 | 90  | 112 | 113.9 | 113 | 117.9 | 82    | Light grey    |
| B 180806 ABS 7024 | 96034124  | 191 | 80  | 60  | 152 | 154.4 | 68  | 73.4  | 52    | Graphite grey |
| B 180806 ABS 7035 | 96034125  | 191 | 80  | 60  | 152 | 154.4 | 68  | 73.4  | 52    | Light grey    |
| B 180809 ABS 7024 | 96034134  | 191 | 80  | 90  | 152 | 153.9 | 68  | 72.9  | 82    | Graphite grey |
| B 180809 ABS 7035 | 96034135  | 191 | 80  | 90  | 152 | 153.9 | 68  | 72.9  | 82    | Light grey    |
| B 181304 ABS 7024 | 96034244  | 191 | 125 | 40  | 152 | 154.6 | 113 | 118.8 | 32    | Graphite grey |
| B 181304 ABS 7035 | 96034245  | 191 | 125 | 40  | 152 | 154.6 | 113 | 118.8 | 32    | Light grey    |
| B 181306 ABS 7024 | 96034224  | 191 | 125 | 60  | 152 | 154.4 | 113 | 118.4 | 52    | Graphite grey |
| B 181306 ABS 7035 | 96034225  | 191 | 125 | 60  | 152 | 154.4 | 113 | 118.4 | 52    | Light grey    |
| B 181309 ABS 7024 | 96034234  | 191 | 125 | 90  | 152 | 153.9 | 113 | 117.9 | 82    | Graphite grey |
| B 181309 ABS 7035 | 96034235  | 191 | 125 | 90  | 152 | 153.9 | 113 | 117.9 | 82    | Light grey    |
| B 221304 ABS 7024 | 96035244  | 231 | 125 | 40  | 192 | 194.6 | 113 | 118.8 | 32    | Graphite grey |
| B 221304 ABS 7035 | 96035245  | 231 | 125 | 40  | 192 | 194.6 | 113 | 118.8 | 32    | Light grey    |
| B 221306 ABS 7024 | 96035224  | 231 | 125 | 60  | 192 | 194.4 | 113 | 118.4 | 52    | Graphite grey |
| B 221306 ABS 7035 | 96035225  | 231 | 125 | 60  | 192 | 194.4 | 113 | 118.4 | 52    | Light grey    |
| B 221309 ABS 7024 | 96035234  | 231 | 125 | 90  | 192 | 194.1 | 113 | 117.9 | 82    | Graphite grey |
| B 221309 ABS 7035 | 96035235  | 231 | 125 | 90  | 192 | 194.1 | 113 | 117.9 | 82    | Light grey    |
| B 261704 ABS 7024 | 96036344  | 271 | 170 | 40  | 232 | 234.8 | 158 | 163.8 | 31.5  | Graphite grey |
| B 261704 ABS 7035 | 96036345  | 271 | 170 | 40  | 232 | 234.8 | 158 | 163.8 | 31.5  | Light grey    |
| B 261706 ABS 7024 | 96036324  | 271 | 170 | 60  | 232 | 234.4 | 158 | 163.4 | 51.5  | Graphite grey |
| B 261706 ABS 7035 | 96036325  | 271 | 170 | 60  | 232 | 234.4 | 158 | 163.4 | 51.5  | Light grey    |
| B 261709 ABS 7024 | 96036334  | 271 | 170 | 90  | 232 | 234.1 | 158 | 163.1 | 81.5  | Graphite grey |
| B 261709 ABS 7035 | 96036335  | 271 | 170 | 90  | 232 | 234.1 | 158 | 163.1 | 81.5  | Light grey    |
| B 261712 ABS 7024 | 96036364  | 271 | 170 | 120 | 232 | 233.4 | 158 | 162.4 | 111.5 | Graphite grey |
| B 261712 ABS 7035 | 96036365  | 271 | 170 | 120 | 232 | 233.4 | 158 | 162.4 | 111.5 | Light grey    |
| B 233012 ABS 7024 | 96038564  | 239 | 300 | 120 | 186 | 188.1 | 288 | 289.5 | 109   | Graphite grey |
| B 233012 ABS 7035 | 96038565  | 239 | 300 | 120 | 186 | 188.1 | 288 | 289.5 | 109   | Light grey    |
| B 273612 ABS 7024 | 96037664  | 284 | 364 | 120 | 231 | 233.1 | 352 | 353.5 | 109   | Graphite grey |
| B 273612 ABS 7035 | 96037665  | 284 | 364 | 120 | 231 | 233.1 | 352 | 353.5 | 109   | Light grey    |


Scope Of Delivery: Lid and base, hinged quick-release catches

Notes: Material shrinkage may result in ABS enclosures being approx. 0.1 – 0.25 % larger.



**BOPLA**

A Phoenix Mecano Company

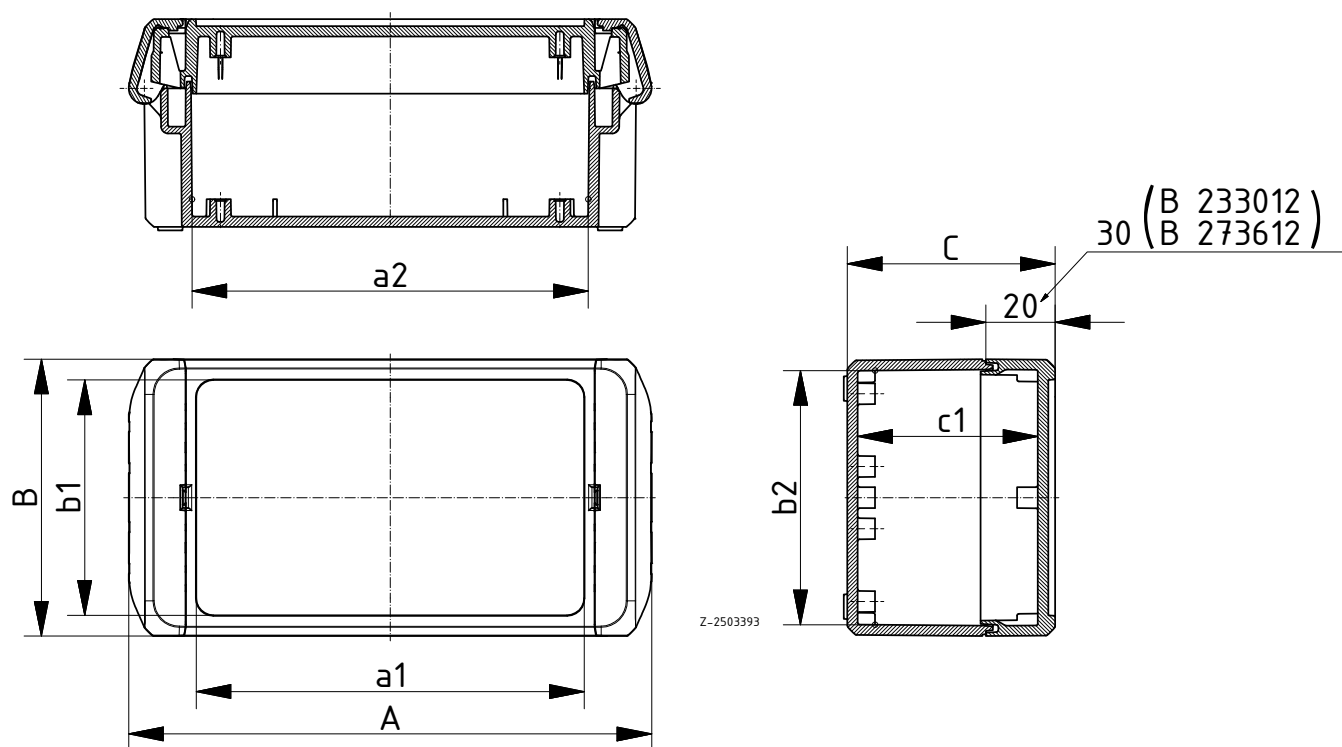

## Bocube | Accessories

### Hinged quick-release catches (Set), polycarbonate UL 94 V0 or ABS



| Model              | Order no. | Colour           | Note                                       |
|--------------------|-----------|------------------|--------------------------------------------|
| B SC 08 PC-V0 1023 | 96310103  | Traffic yellow   | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC 08 ABS 1023   | 96330103  | Traffic yellow   | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC 08 PC-V0 7035 | 96310105  | Light grey       | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC 08 ABS 7035   | 96330105  | Light grey       | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC 08 PC-V0 7024 | 96310104  | Graphite grey    | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC 08 ABS 7024   | 96330104  | Graphite grey    | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC 08 PC-V0 6029 | 96310109  | Mint green       | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC 08 ABS 6029   | 96330109  | Mint green       | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC 08 PC-V0 5002 | 96310102  | Ultramarine blue | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC 08 ABS 5002   | 96330102  | Ultramarine blue | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC 08 PC-V0 3000 | 96310100  | Flame red        | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC 08 ABS 3000   | 96330100  | Flame red        | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC 13 PC-V0 1023 | 96310203  | Traffic yellow   | For B 1413.., B 1813.., B 2213..           |
| B SC 13 ABS 1023   | 96330203  | Traffic yellow   | For B 1413.., B 1813.., B 2213..           |
| B SC 13 PC-V0 7035 | 96310205  | Light grey       | For B 1413.., B 1813.., B 2213..           |
| B SC 13 ABS 7035   | 96330205  | Light grey       | For B 1413.., B 1813.., B 2213..           |
| B SC 13 PC-V0 7024 | 96310204  | Graphite grey    | For B 1413.., B 1813.., B 2213..           |
| B SC 13 ABS 7024   | 96330204  | Graphite grey    | For B 1413.., B 1813.., B 2213..           |
| B SC 13 PC-V0 6029 | 96310209  | Mint green       | For B 1413.., B 1813.., B 2213..           |
| B SC 13 ABS 6029   | 96330209  | Mint green       | For B 1413.., B 1813.., B 2213..           |
| B SC 13 PC-V0 5002 | 96310202  | Ultramarine blue | For B 1413.., B 1813.., B 2213..           |
| B SC 13 ABS 5002   | 96330202  | Ultramarine blue | For B 1413.., B 1813.., B 2213..           |
| B SC 13 PC-V0 3000 | 96310200  | Flame red        | For B 1413.., B 1813.., B 2213..           |
| B SC 13 ABS 3000   | 96330200  | Flame red        | For B 1413.., B 1813.., B 2213..           |
| B SC 17 PC-V0 1023 | 96310303  | Traffic yellow   | For B 2617..                               |
| B SC 17 ABS 1023   | 96330303  | Traffic yellow   | For B 2617..                               |
| B SC 17 PC-V0 7035 | 96310305  | Light grey       | For B 2617..                               |
| B SC 17 ABS 7035   | 96330305  | Light grey       | For B 2617..                               |
| B SC 17 PC-V0 7024 | 96310304  | Graphite grey    | For B 2617..                               |
| B SC 17 ABS 7024   | 96330304  | Graphite grey    | For B 2617..                               |
| B SC 17 PC-V0 6029 | 96310309  | Mint green       | For B 2617..                               |
| B SC 17 ABS 6029   | 96330309  | Mint green       | For B 2617..                               |
| B SC 17 PC-V0 5002 | 96310302  | Ultramarine blue | For B 2617..                               |
| B SC 17 ABS 5002   | 96330302  | Ultramarine blue | For B 2617..                               |
| B SC 17 PC-V0 3000 | 96310300  | Flame red        | For B 2617..                               |
| B SC 17 ABS 3000   | 96330300  | Flame red        | For B 2617..                               |
| B SC PC-V0 1023    | 96310003  | Traffic yellow   | For B 233012, B 273612                     |
| B SC ABS 1023      | 96330003  | Traffic yellow   | For B 233012, B 273612                     |
| B SC PC-V0 3000    | 96310000  | Flame red        | For B 233012, B 273612                     |
| B SC ABS 3000      | 96330000  | Flame red        | For B 233012, B 273612                     |
| B SC PC-V0 5002    | 96310002  | Ultramarine blue | For B 233012, B 273612                     |
| B SC ABS 5002      | 96330002  | Ultramarine blue | For B 233012, B 273612                     |
| B SC PC-V0 6029    | 96310009  | Mint green       | For B 233012, B 273612                     |
| B SC ABS 6029      | 96330009  | Mint green       | For B 233012, B 273612                     |
| B SC PC-V0 7024    | 96310004  | Graphite grey    | For B 233012, B 273612                     |
| B SC ABS 7024      | 96330004  | Graphite grey    | For B 233012, B 273612                     |
| B SC PC-V0 7035    | 96310005  | Light grey       | For B 233012, B 273612                     |
| B SC ABS 7035      | 96330005  | Light grey       | For B 233012, B 273612                     |

Scope Of Delivery: B SC 08 - B SC 17 = 2 pcs. tool-operated; B SC = 4 pcs. tool-operated

# Bocube | Accessories

## Hand-operated hinged catch (set), polycarbonate UL 94 V0 or ABS

| Model                 | Order no.  | Colour           | Note                                       |
|-----------------------|------------|------------------|--------------------------------------------|
| B SC HB 08 PC-V0 1023 | 96910103   | Traffic yellow   | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC HB 08 ABS 1023   | 96930103   | Traffic yellow   | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC HB 08 PC-V0 7035 | 96910105** | Light grey       | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC HB 08 ABS 7035   | 96930105** | Light grey       | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC HB 08 PC-V0 7024 | 96910104** | Graphite grey    | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC HB 08 ABS 7024   | 96930104** | Graphite grey    | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC HB 08 PC-V0 6029 | 96910109   | Mint green       | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC HB 08 ABS 6029   | 96930109   | Mint green       | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC HB 08 PC-V0 5002 | 96910102   | Ultramarine blue | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC HB 08 ABS 5002   | 96930102   | Ultramarine blue | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC HB 08 ABS 3000   | 96930100   | Flame red        | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC HB 08 PC-V0 3000 | 96910100   | Flame red        | For B 0808.., B 1008.., B 1408.., B 1808.. |
| B SC HB 13 PC-V0 1023 | 96910203   | Traffic yellow   | For B 1413.., B 1813.., B 2213..           |
| B SC HB 13 ABS 1023   | 96930203   | Traffic yellow   | For B 1413.., B 1813.., B 2213..           |
| B SC HB 13 PC-V0 7035 | 96910205** | Light grey       | For B 1413.., B 1813.., B 2213..           |
| B SC HB 13 ABS 7035   | 96930205** | Light grey       | For B 1413.., B 1813.., B 2213..           |
| B SC HB 13 PC-V0 7024 | 96910204** | Graphite grey    | For B 1413.., B 1813.., B 2213..           |
| B SC HB 13 ABS 7024   | 96930204** | Graphite grey    | For B 1413.., B 1813.., B 2213..           |
| B SC HB 13 PC-V0 6029 | 96910209   | Mint green       | For B 1413.., B 1813.., B 2213..           |
| B SC HB 13 ABS 6029   | 96930209   | Mint green       | For B 1413.., B 1813.., B 2213..           |
| B SC HB 13 PC-V0 5002 | 96910202   | Ultramarine blue | For B 1413.., B 1813.., B 2213..           |
| B SC HB 13 ABS 5002   | 96930202   | Ultramarine blue | For B 1413.., B 1813.., B 2213..           |
| B SC HB 13 PC-V0 3000 | 96910200   | Flame red        | For B 1413.., B 1813.., B 2213..           |
| B SC HB 13 ABS 3000   | 96930200   | Flame red        | For B 1413.., B 1813.., B 2213..           |
| B SC HB 17 PC-V0 1023 | 96910303   | Traffic yellow   | For B 2617..                               |
| B SC HB 17 ABS 1023   | 96930303   | Traffic yellow   | For B 2617..                               |
| B SC HB 17 PC-V0 7035 | 96910305** | Light grey       | For B 2617..                               |
| B SC HB 17 ABS 7035   | 96930305** | Light grey       | For B 2617..                               |
| B SC HB 17 PC-V0 7024 | 96910304** | Graphite grey    | For B 2617..                               |
| B SC HB 17 ABS 7024   | 96930304** | Graphite grey    | For B 2617..                               |
| B SC HB 17 PC-V0 6029 | 96910309   | Mint green       | For B 2617..                               |
| B SC HB 17 ABS 6029   | 96930309   | Mint green       | For B 2617..                               |
| B SC HB 17 PC-V0 5002 | 96910302   | Ultramarine blue | For B 2617..                               |
| B SC HB 17 ABS 5002   | 96930302   | Ultramarine blue | For B 2617..                               |
| B SC HB 17 PC-V0 3000 | 96910300   | Flame red        | For B 2617..                               |
| B SC HB 17 ABS 3000   | 96930300   | Flame red        | For B 2617..                               |
| B SC HB PC-V0 1023    | 96910003   | Traffic yellow   | For B 233012, B 273612                     |
| B SC HB ABS 1023      | 96930003   | Traffic yellow   | For B 233012, B 273612                     |
| B SC HB PC-V0 7035    | 96910005** | Light grey       | For B 233012, B 273612                     |
| B SC HB ABS 7035      | 96930005** | Light grey       | For B 233012, B 273612                     |
| B SC HB PC-V0 7024    | 96910004** | Graphite grey    | For B 233012, B 273612                     |
| B SC HB ABS 7024      | 96930004** | Graphite grey    | For B 233012, B 273612                     |
| B SC HB PC-V0 6029    | 96910009   | Mint green       | For B 233012, B 273612                     |
| B SC HB ABS 6029      | 96930009   | Mint green       | For B 233012, B 273612                     |
| B SC HB PC-V0 5002    | 96910002   | Ultramarine blue | For B 233012, B 273612                     |
| B SC HB ABS 5002      | 96930002   | Ultramarine blue | For B 233012, B 273612                     |
| B SC HB PC-V0 3000    | 96910000   | Flame red        | For B 233012, B 273612                     |
| B SC HB ABS 3000      | 96930000   | Flame red        | For B 233012, B 273612                     |

Scope Of Delivery: B SC 08 - B SC 17 = 1 pc. tool-operated and 1 pc. manually-operated; B SC = 2 pcs. tool-operated and 2 pcs. manually-operated

Notes: IP protection class only guaranteed with closed hinged catch. \*\* To order ONLY the hand-operated hinge, please order the a.m. article number plus ".E" (e.g. 96930105.E)




## Bocube | Accessories



### Wall brackets

| Model       | Order no. | Colour        | Note                   |
|-------------|-----------|---------------|------------------------|
| B WL 7024   | 96510004  | Graphite grey | For B 08... - B 26...  |
| B WL 7035   | 96510005  | Light grey    | For B 08... - B 26...  |
| B WL-2 7024 | 96510604  | Graphite grey | For B 2330.., B 2736.. |
| B WL-2 7035 | 96510605  | Light grey    | For B 2330.., B 2736.. |

Scope Of Delivery: 4 wall brackets (polycarbonate UL 94 V0), 4 screws

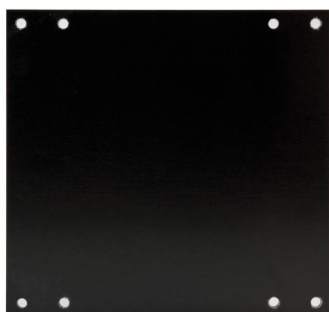


### Mounting panels, laminated paper, 2 mm

| Model    | Order no. | Note         |
|----------|-----------|--------------|
| B M 0808 | 96601100  | For B 0808.. |
| B M 1008 | 96602100  | For B 1008.. |
| B M 1408 | 96603100  | For B 1408.. |
| B M 1413 | 96603200  | For B 1413.. |
| B M 1808 | 96604100  | For B 1808.. |
| B M 1813 | 96604200  | For B 1813.. |
| B M 2213 | 96605200  | For B 2213.. |
| B M 2330 | 96608500  | For B 2330.. |
| B M 2617 | 96606300  | For B 2617.. |
| B M 2736 | 96607600  | For B 2736.. |

Scope Of Delivery: 1 mounting panel

Notes: Please order fixing screws order no. [96600000](#) (for B 08...) and order no. [96600010](#) (for B 10..., B 14..., B 18..., B 22..., B 26..., B 23... and B 27...) separately.

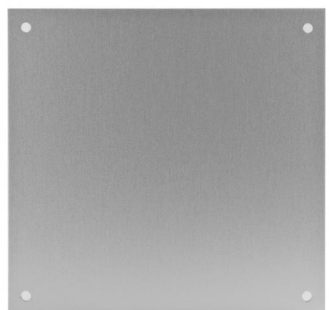

### Front panels, 2 mm, natural-coloured anodised aluminium

| Model     | Order no. | Note                                       |
|-----------|-----------|--------------------------------------------|
| B FP 1008 | 96702100  | For B 1008.., front panel thickness 1.5 mm |
| B FP 1408 | 96703100  | For B 1408.., front panel thickness 1.5 mm |
| B FP 1413 | 96703200  | For B 1413.., front panel thickness 1.5 mm |
| B FP 1808 | 96704100  | For B 1808.., front panel thickness 2.0 mm |
| B FP 1813 | 96704200  | For B 1813.., front panel thickness 2.0 mm |
| B FP 2213 | 96705200  | For B 2213.., front panel thickness 2.0 mm |
| B FP 2330 | 96708500  | For B 2330.., front panel thickness 2.5 mm |
| B FP 2617 | 96706300  | For B 2617.., front panel thickness 2.5 mm |
| B FP 2736 | 96707600  | For B 2736.., front panel thickness 2.5 mm |

Scope Of Delivery: 1 front panel

Notes: Please order fixing screws order no. [96700000](#) and distance bolts separately.



### Sets of screws

| Model        | Order no. | Note                                                   |
|--------------|-----------|--------------------------------------------------------|
| B FP-SHR     | 96700000  | A (for fixing front panels)                            |
| B M-SHR 0808 | 96600000  | B (for fixing mounting panels B M 0808)                |
| B M-SHR      | 96600010  | C (for fixing mounting panels B M 1008-2736)           |
| B SHR        | 96300000  | D (for optional screwing of enclosures B 0808 - 2617)  |
| B SHR-2      | 96300002  | E (for optional screwing of enclosures B 2330, B 2736) |

Scope Of Delivery: PU = 4 pcs. (exception: B M-SHR 0808, PU = 2 pcs)

## Bocube | Accessories

### Distance bolts

| Model                | Order no. | Note                                                               |
|----------------------|-----------|--------------------------------------------------------------------|
| DIBLZ AK 30x5/IM3/8  | 96708000  | ND = 2,4 - 2,6, for B....04                                        |
| DIBLZ AK 30x5/IM3/28 | 96728000  | ND = 2,4 - 2,6, for B....06                                        |
| DIBLZ AK 30x7/IM3/26 | 96726000  | ND = 2,4 - 2,6, for B....06 if a mounting plate is used            |
| DIBLZ AK 30x5/IM3/58 | 96758000  | ND = 2,4 - 2,6, for B....09                                        |
| DIBLZ AK 30x7/IM3/56 | 96756000  | ND = 2,4-2,6, for B....09 if a mounting plate is used              |
| DIBLZ AK 30x5/IM3/88 | 96788000  | ND = 2,4 - 2,6, for B....12                                        |
| DIBLZ AK 30x7/IM3/86 | 96786000  | ND = 2,4 - 2,6, for B....12 if a mounting plate is used            |
| DIBLZ AK 30x5/IM3/76 | 96776000  | ND = 2,4 - 2,6, for B 233012, B 273612                             |
| DIBLZ AK 30x7/IM3/74 | 96774000  | ND = 2,4 - 2,6, for B 233012, B 273612 if a mounting plate is used |

Scope Of Delivery: 4 distance bolts


Notes: ND = boss internal diameter



### Blanking plugs to determine the hinge side

| Model     | Order no. | Colour        |
|-----------|-----------|---------------|
| B VS 7024 | 96410004  | Graphite grey |
| B VS 7035 | 96410005  | Light grey    |
| B VS 3000 | 96410000  | Flame red     |

Scope Of Delivery: Blanking plugs (PC UL 94 V0), PU = 10 pieces

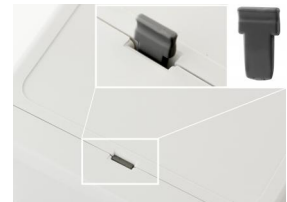

### DIN rails DIN EN 60715 TH 15, galvanised steel

| Model | Order no. | Note                                                                        |
|-------|-----------|-----------------------------------------------------------------------------|
| TS 15 | 22151851  | For BCD 160 terminal compartment up, B 2330.. (crosswise)                   |
| TS 15 | 22150701  | For EM/ET 207-210, EM/ET 225, B 1008..                                      |
| TS 15 | 22151101  | For EM/ET 213, EM/ET 215-217, EM/ET 227, B 1408.., B 1413..                 |
| TS 15 | 22151501  | For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..                 |
| TS 15 | 22151901  | For EM/ET 214, EM/ET 221-223, EM/ET 232, EM/ET 237, BCD 200, B 2213..       |
| TS 15 | 22152301  | For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise) |
| TS 15 | 22152851  | For B 2330..                                                                |
| TS 15 | 22153451  | For B 2736..                                                                |

Scope Of Delivery: 1 DIN rail



### DIN rails DIN EN 60715 G 32, galvanised steel

| Model | Order no. | Note                                                                        |
|-------|-----------|-----------------------------------------------------------------------------|
| TS 32 | 22320701  | For EM/ET 208-210, EM/ET 225, B 1008..                                      |
| TS 32 | 22321101  | For EM/ET 213, EM/ET 215-217, EM/ET 227, B 1408.., B 1413..                 |
| TS 32 | 22321501  | For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..                 |
| TS 32 | 22321851  | For B 2330.. (crosswise)                                                    |
| TS 32 | 22321901  | For EM/ET 214, EM/ET 221-223, EM/ET 232, EM/ET 237, B 22130.                |
| TS 32 | 22322301  | For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise) |
| TS 32 | 22322851  | For B 2330..                                                                |
| TS 32 | 22323451  | For B 2736..                                                                |

Scope Of Delivery: 1 DIN rail



# Bocube | Accessories



## DIN rails DIN EN 60715 TH 35, galvanised steel

| Model | Order no. | Note                                                                        |
|-------|-----------|-----------------------------------------------------------------------------|
| TS 35 | 22350701  | For EM/ET 208-210, EM/ET 225, B 1008..                                      |
| TS 35 | 22351101  | For EM/ET 213, EM/ET 215-217, EM/ET 227, B 1408.., B 1413..                 |
| TS 35 | 22351501  | For EM/ET 220, EM/ET 229-231, EM/ET 238, B 1808.., B 1813..                 |
| TS 35 | 22351851  | For B 2330.. (crosswise)                                                    |
| TS 35 | 22351901  | For EM/ET 214, EM/ET 221-223, EM/ET 232, EM/ET 237, BCD 200, B 2213..       |
| TS 35 | 22352851  | For B 2330..                                                                |
| TS 35 | 22352301  | For EM/ET 224, EM/ET 233-236, EM/ET 239-242, B 2617.., B 2736.. (crosswise) |
| TS 35 | 22353451  | For B 2736..                                                                |

Scope Of Delivery: 1 DIN rail



**BOPLA**

A Phoenix Mecano Company

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Phoenix Mecano:](#)

[96310109](#) [96410004](#) [96310103](#) [96510005](#) [96601100](#) [96606300](#) [96705200](#) [96300000](#) [96600010](#) [96700000](#)