





Auer Signal

# PC7 ASI-Interface

 IP66/IP67 UL Type 4/4X/13

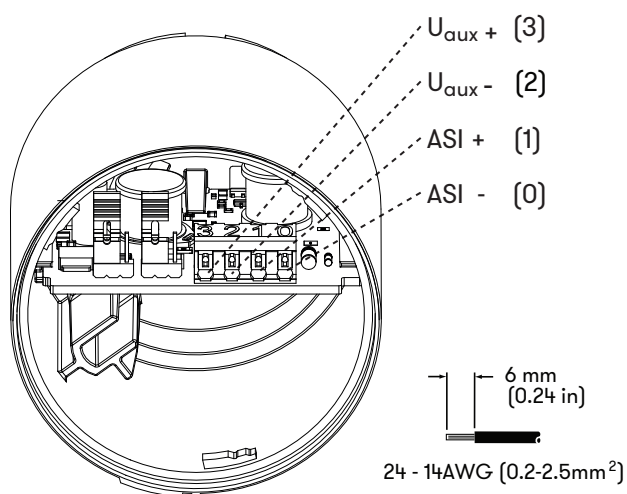


-30°C to +60°C (-22°F to +140°F)




26,5 V<sub>DC</sub> - 31,5 V<sub>DC</sub>

≤ 300 mA

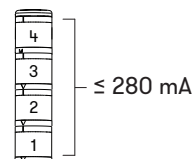


-30°C to +70°C (-22°F to +158°F)

 


26,5 V<sub>DC</sub> - 31,5 V<sub>DC</sub>

≤ 20 mA

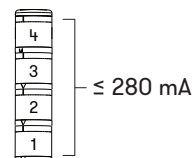

U<sub>aux</sub> = ≤ 280 mA  
PELV 24 V<sub>DC</sub> +/-10%

PUSH TO LOCK  
POUSSER POUR VERROUILLER  
DRÜCKEN ZU SPERREN  
PREMERE PER BLOCCARE  
EMPURRE PARA TRAVAR  
EMPUJAR PARA BLOQUEAR

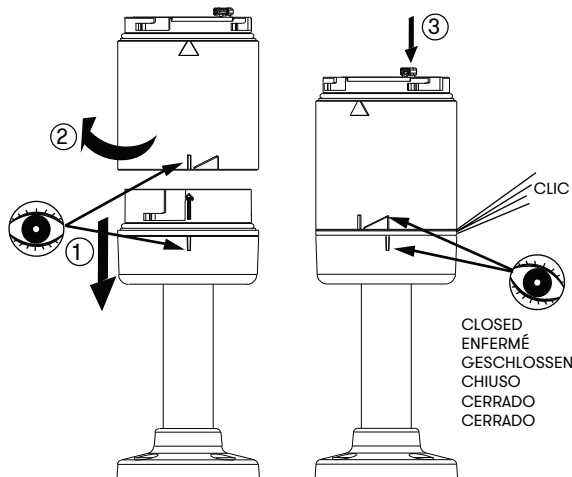


|    |   |
|----|---|
| D3 | 4 |
| D2 | 3 |
| D1 | 2 |
| D0 | 1 |



IO / ID / ID1 / ID2

|          |   |    |                                                                   |
|----------|---|----|-------------------------------------------------------------------|
| PC7ASI20 | 4 | 31 | 8 <sub>h</sub> / F <sub>h</sub> / F <sub>h</sub> / F <sub>h</sub> |
| PC7ASI21 | 3 | 62 | 8 <sub>h</sub> / A <sub>h</sub> / 7 <sub>h</sub> / E <sub>h</sub> |
| PC7ASI30 | 4 | 62 | 7 <sub>h</sub> / A <sub>h</sub> / 7 <sub>h</sub> / 7 <sub>h</sub> |

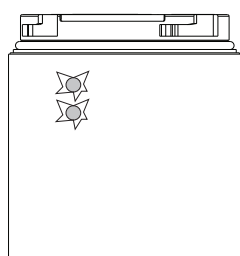

| grün<br>green | rot<br>red | Status                                                                                                                       |
|---------------|------------|------------------------------------------------------------------------------------------------------------------------------|
| ●             | ○          | Normaler Betrieb / Normal operation                                                                                          |
| ●             | ●          | Keine Datenübertragung / No data exchange                                                                                    |
| ★             | ●          | Keine Datenübertragung, Slave-Adresse = 0<br>No data exchange, Slave-address = 0                                             |
| ★             | ★          | Peripheriefehler, Überstrom oder Unterspannung am<br>Ausgang / Peripheral fault, overcurrent or low<br>voltage on the output |

Wechselblinken  
Alternate flashing

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Auer Signal:](#)

[910775200](#) [910775300](#)