

09238RA (D-Type)

DC Axial Fan


92[□]X38^L



General Specifications

Motor Protection	Auto Restart / Polarity Protection
Insulation Resistance	10MΩ or over with a DC500V Megger
Dielectric Withstand Voltage	AC700V 1s
Allowable Ambient Temperature Range	- 10°C ~ + 70°C (Operating) - 40°C ~ + 70°C (Storage) non-condensing environment

Outline

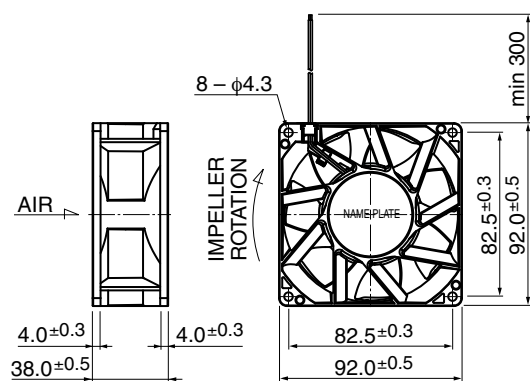


* Outline is E (Flange) type.

Expected Life


※ Failure Rate: 10% (L10 Life)

25°C 100,000 (Hours)

Panel Out-cuts

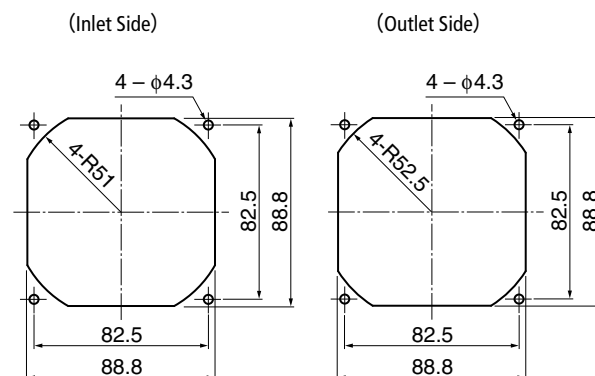

Characteristic Curves

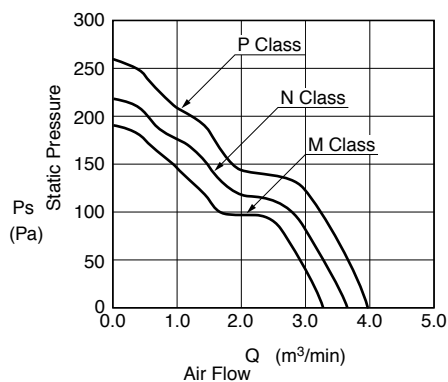

Material

Casing	: Plastic (Black) UL94V-0
Impeller	: Plastic (Black) UL94V-0
Bearing	: Ball Bearing
Lead Wire	: UL3385 AWG26 + : Red, - : Black

Customize service for IP compatible type and Oil-proof type is available for this item. Please contact to our sales representative for more detail.

Specifications

Model**	Product Number	Rating Voltage	Operating Voltage	Current	Input Power	Speed	Max Air Flow		Max Static Pressure		Noise	Mass
		(V)	(V)	(A)*1	(W)*1	(min-1)*1	(m³/min)*1	(CFM)*1	(Pa)	(In H2O)*1	(dB)*1	(g)
09238RA-24L-AAD-	0	24	10.0 ~ 27.6	0.42	10.10	5000	2.94	103.8	142.0	0.57	53.0	230
09238RA-24M-AAD-	0	24	14.0 ~ 27.6	0.56	13.44	5700	3.36	118.6	187.0	0.75	57.0	
09238RA-24N-AAD-	0	24	14.0 ~ 27.6	0.71	17.04	6200	3.68	129.9	222.0	0.89	59.0	
09238RA-24P-AAD-	0	24	14.0 ~ 27.6	0.92	22.08	6700	4.00	141.2	260.0	1.04	61.0	

Rotation: Clockwise as seen from the label side
Airflow Outlet: Label side

**Flange casing also available

*1: Average Values in Free Air

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[MinebeaMitsumi:](#)

[09238RA-12L-EAD-0](#) [09238RA-12M-EAD-0](#) [09238RA-12N-EAD-0](#) [09238RA-12N-ELD-0](#) [09238RA-24N-ETD-0](#)
[09238RA-12M-ETD-0](#) [09238RA-12N-ETD-0](#) [09238RA-12L-ETD-0](#) [09238RA-24N-ELD-0](#) [09238RA-24M-ELD-0](#)
[09238RA-24L-ELD-0](#) [09238RA-24Q-ELD-0](#) [09238RA-24Q-EAD-0](#) [09238RA-12L-ELD-0](#) [09238RA-48Q-EAD-0](#)
[09238RA-24M-ETD-0](#) [09238RA-24Q-ETD-0](#) [09238RA-12M-ELD-0](#) [09238RA-24L-ETD-0](#)