


SG18J, K, M


Metal Brush

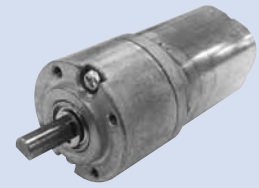

Applications

Robot, Door Lock, Shade, Blind

External Dimensions

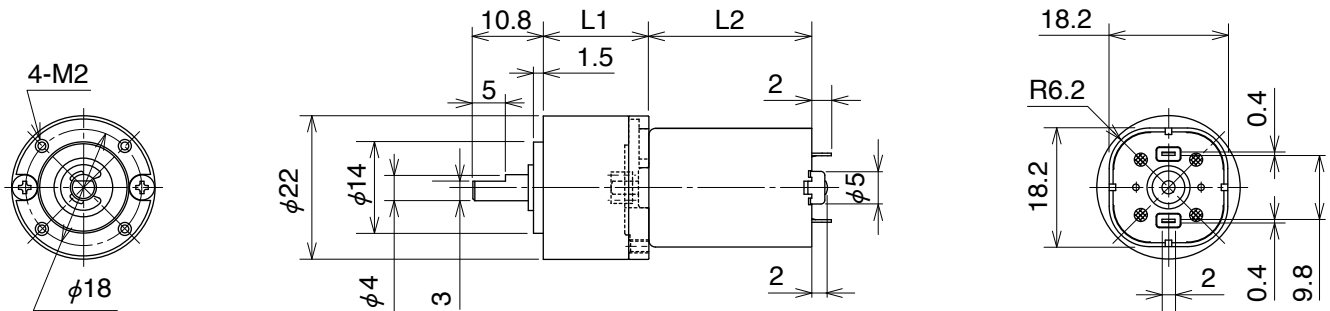


Unit: mm

Reference Characteristics

Model	Voltage	No Load		Rated Load		Rated Load		Max Rated Load Torque		Starting Torque		Gear Box		Motor	
	Rated	Speed	Current			Speed	Current								
	(V)	(min ⁻¹)	(mA)	(gf·cm)	(mN·m)	(min ⁻¹)	(mA)	(gf·cm)	(mN·m)	(gf·cm)	(mN·m)	Gear Ratio	Step	L1	L2
SG18J1L	6	321	180	306	30	271	427	918	90	1969	193	1 : 16	2	16.2	20
SG18J1L	6	214	190	612	60	170	517	1429	140	2949	289	1 : 24	2	16.2	20
SG18K1M	6	207	109	612	60	165	392	1531	150	3051	299	1 : 16	2	16.2	25
SG18M1L	12	291	130	1224	120	222	586	2551	250	5194	509	1 : 16	2	16.2	30

Characteristics

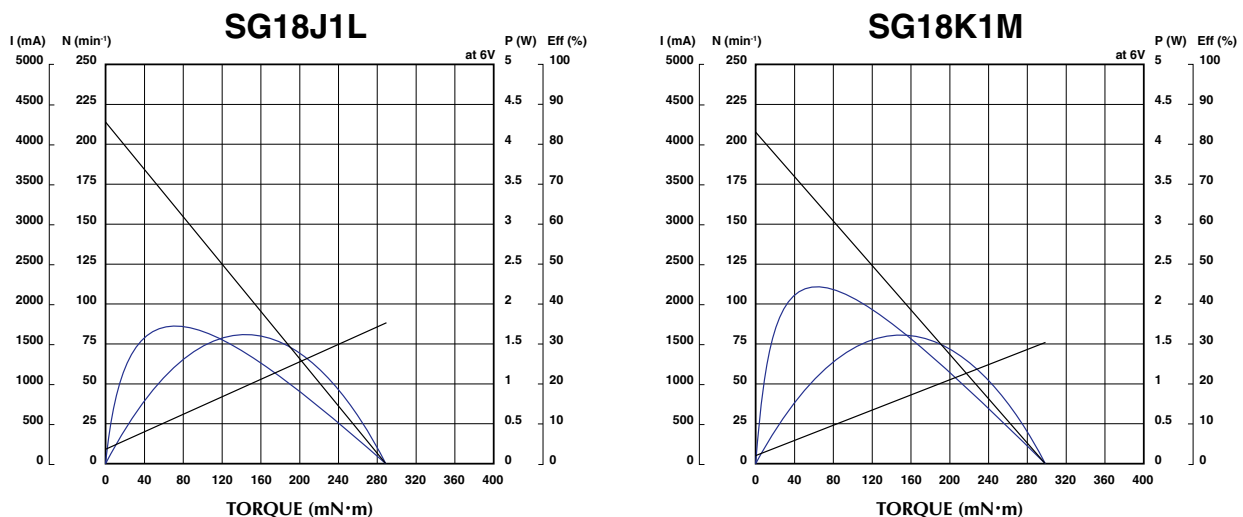

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[MinebeaMitsumi:](#)

[SG18](#) [SG18K1BTTR-S](#)