


FEATURES

- Actuator on the center of the spring prevents deterioration of operating feel due to misalignment between switch and knob
- Sharp click feel and long operating life
- IP68 dust / water resistance

APPLICATIONS

- Smartphones
- Digital cameras
- Gaming devices
- Wearables
- Outdoor equipment (dusty environment)

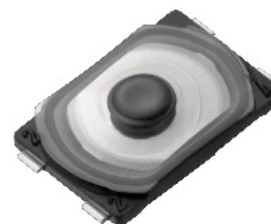

PART NUMBER CODE

Series	Height	Actuator Type	Operating Force	Ablation Terminal	
□ □ □	□ □ □	□	□ □	□	X
STU	057 (0.57mm) 060 (0.60mm)	A	23 (2.25N) 30 (3.0N)	A (IP68)	

SPECIFICATIONS


Switch Type	SPST	Tactile
Electrical Characteristics	Rating (Resistive Load)	DC15V, 20mA (maximum)
		DC2V, 10μA (minimum)
	Contact Resistance	500Ω or less
Life	STU-057A23AC	500,000 times
	STU-060A30AX	300,000 times
Dust / Water Resistance	Protective Resistance	IP68 (1.5m depth x 30 min.)

TYPE

Model Name	Model No.	Operating Force	Travel	Click Ratio	Pcs/Reel
STU-057A23AC	R 668127	2.25N	0.15mm	≥ 40%	20,000
STU-060A30AX	R 668098	3.0N	0.15mm	≥ 35%	20,000


DIMENSIONS

STU-057A23AC

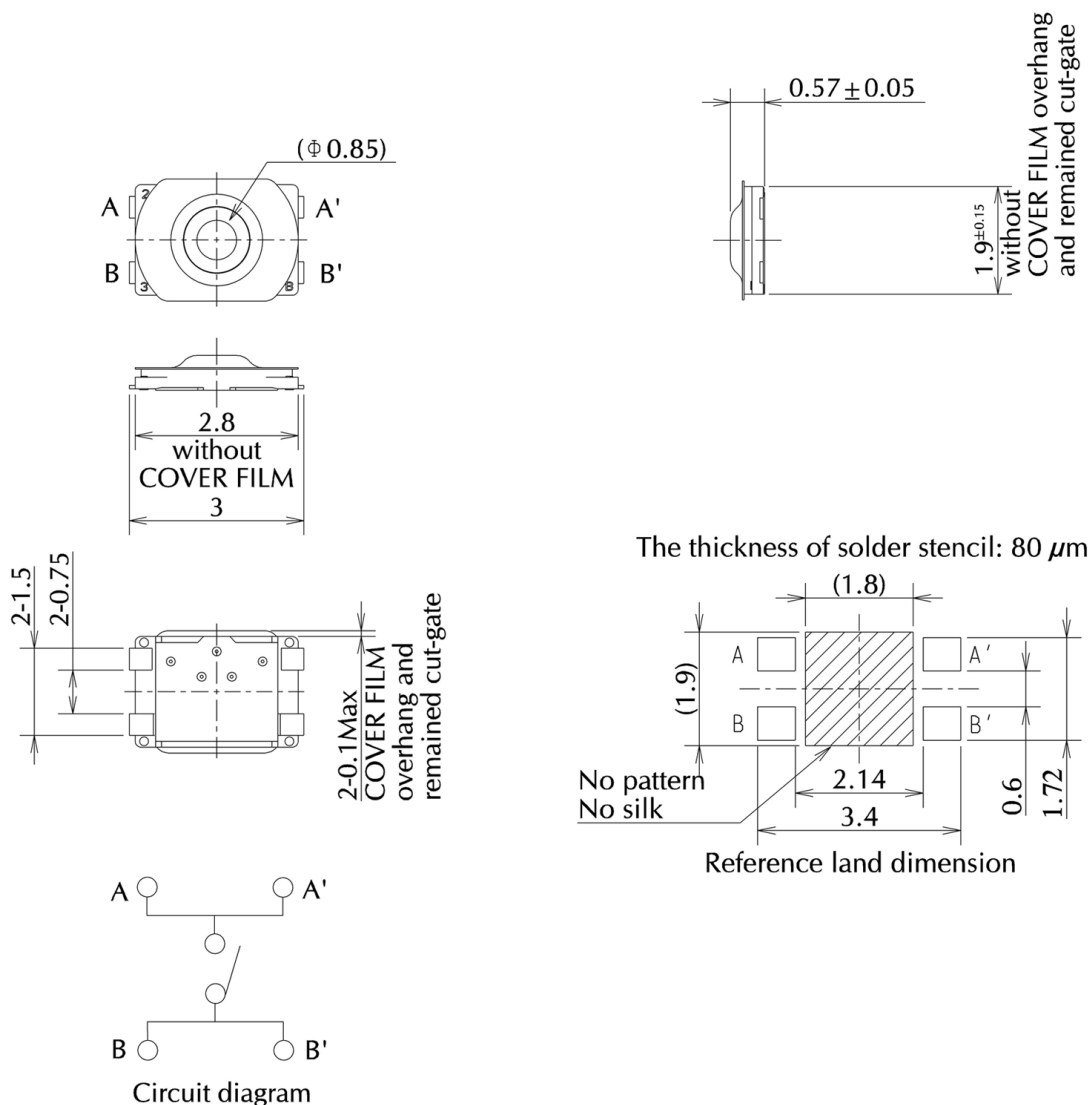

DIMENSIONS

STU-060A30AX

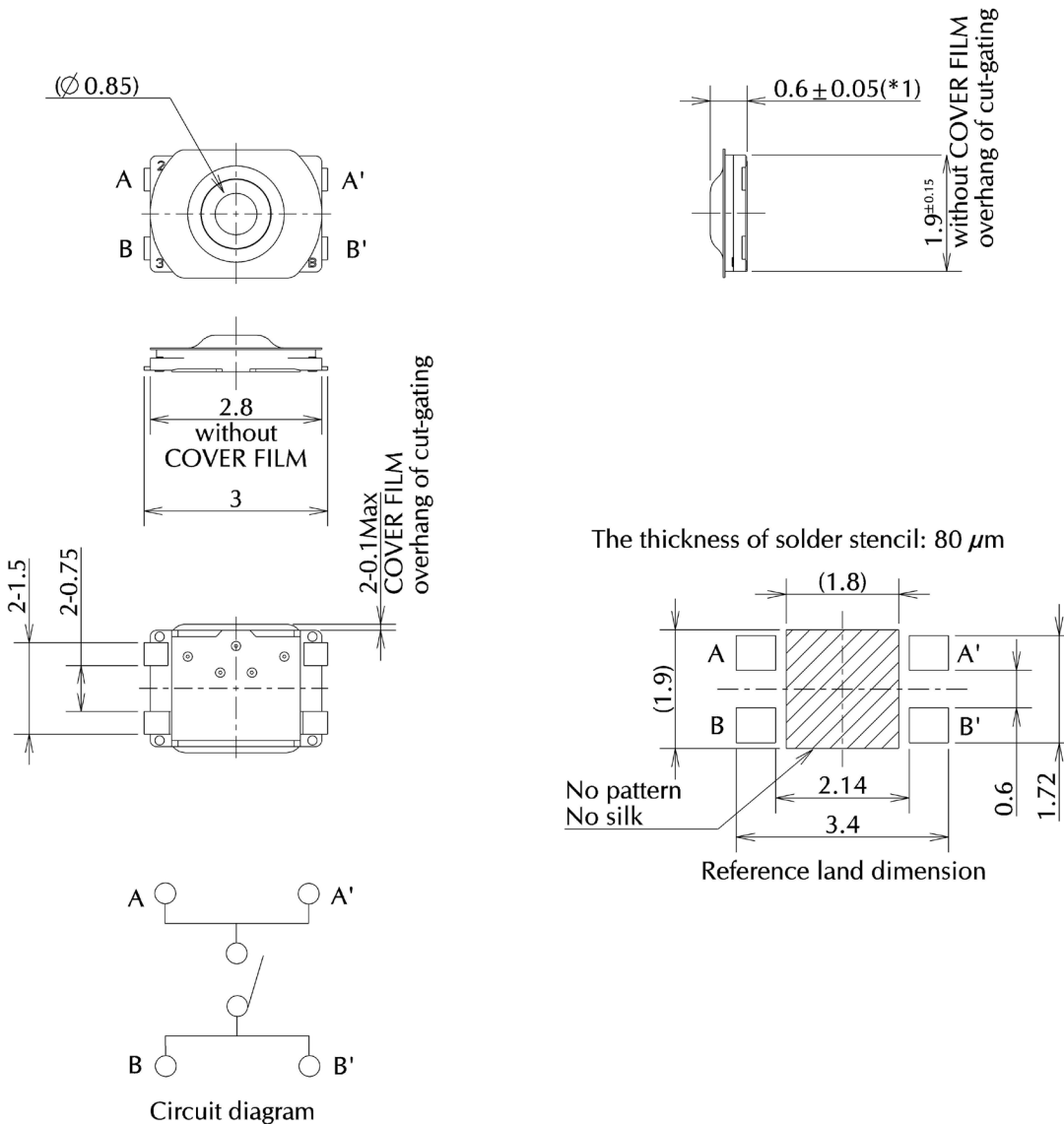

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[MinebeaMitsumi:](#)

[STU-057A23AC](#) [STU-060A30AX](#)