


OA172AP Series



AC Fans - 115, 230V
172mm x 51mm (6.7" x 2.0")

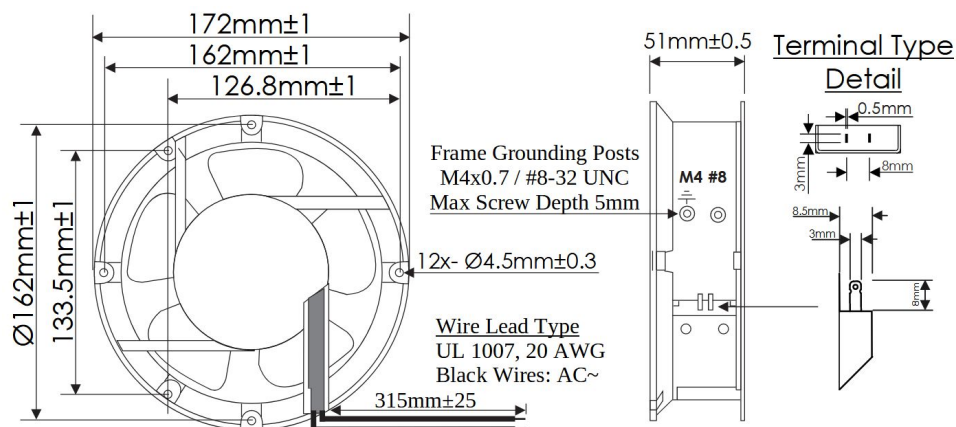

Frame	Die Cast Aluminum, Black Finish	<u>Operating Temperature</u> -20°C ~ +70°C <u>Storage Temperature</u> -40°C ~ +80°C <u>Life Expectancy</u> 60,000 Hours (L10 at 40°C) <u>Available Options</u> Tachometer Output Alarm Output Weight: 2.53 lbs.
Impeller	PBT, UL94 V-0 Plastic	
Connection	2x Lead Wires, UL 1007 20 AWG, or Terminals	
Motor	Capacitor Induction, Impedance Protected	
Bearing System	Ball Bearings	
Dielectric Strength	1500VAC/min, <1mA	
Insulation Resistance	≥10MΩ @ 500 VDC	

Part Number	Rated Voltage (Volts AC)	Voltage Range (Volts AC)	Input Power (Watts)	Rated Speed (RPM)	Max Airflow (CFM)	Noise Level (dBA)	Max Static Pressure ("H ₂ O)
OA172AP-11-1*B	115	80 ~ 130	26 / 35	2700 / 3200	195 / 235	53	0.57 / 0.70
OA172AP-11-2*B	115	80 ~ 130	22 / 20	2400 / 2300	175 / 170	42	0.49 / 0.47
OA172AP-11-3*B	115	80 ~ 130	18 / 16	1500 / 1800	105 / 130	33	0.35 / 0.43
OA172AP-22-1*B	230	200 ~ 260	26 / 35	2700 / 3200	195 / 235	53	0.57 / 0.70
OA172AP-22-2*B	230	200 ~ 260	22 / 20	2400 / 2300	175 / 170	42	0.49 / 0.47
OA172AP-22-3*B	230	200 ~ 260	18 / 16	1500 / 1800	105 / 130	33	0.35 / 0.43

* Insert "T" for Terminal type power connection, or "W" for Wire lead type power connection.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Orion Fans:](#)

[OA172AP-11-3TB](#) [OA172AP-22-3TB](#) [OA172AP-11-2TB](#) [OA172AP-11-3WB](#) [OA172AP-22-2TB](#) [OA172AP-22-2WB](#)
[OA172AP-22-3WB](#) [OA172AP-22-1WB](#) [OA172AP-11-1WB](#) [OA172AP-11-1TB](#) [OA172AP-22-1TB](#) [OA172AP-11-2WB](#)