


OA200AP IP Rated Series



AC Fans - 115, 230V
220mm x 70mm (8.7" x 2.8")

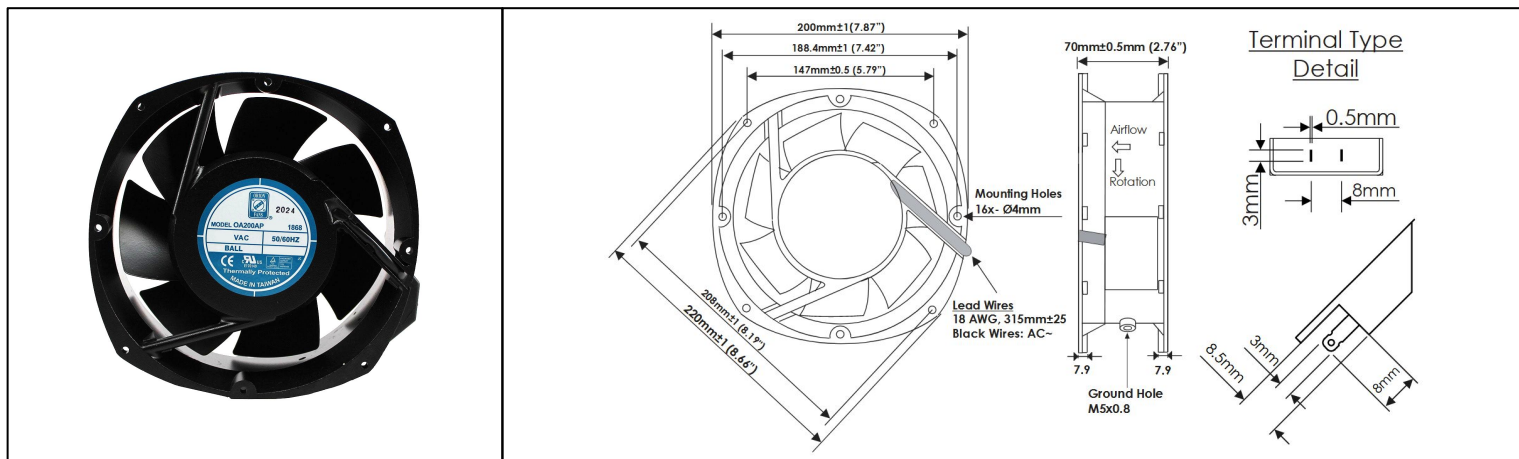

Frame	Die Cast Aluminum, Black Finish	Operating Temperature -30°C ~ +80°C Storage Temperature -40°C ~ +100°C Life Expectancy 50,000 Hours (L10 at 55°C) Weight: 4.63 lbs	
Impeller	Steel, All Metal, 7 Blades		
Connection	Lead Wires, 315mm 18 AWG, or Terminals		
Motor	AC, Capacitor Induction, Single Phase, Thermally Protected, IP68 or IP69K		
Bearing System	Ball Bearings		
Dielectric Strength	1500VAC/min, <1mA		
Insulation Resistance	≥10MΩ @ 500V DC		

Part Number	Rated Voltage (Volts AC)	Voltage Range (Volts AC)	Input Power (Watts)	Frequency (Hertz)	Rated Speed (RPM)	Max Airflow (CFM)	Noise Level (dBA)	Max Static Pressure ("H ₂ O)
OA200AP-11-1*B18xxx	115	100 ~ 130	95 / 105	50 / 60	2775 / 3300	430 / 485	68.2	0.82 / 0.93
OA200AP-22-1*B18xxx	230	200 ~ 255	95 / 105	50 / 60	2775 / 3300	430 / 485	68.2	0.82 / 0.93

*Insert "T" for Terminal type power connection, or "W" for Wire Lead type power connection.
xxx Insert "68" for IP68 Rating, or "69K" for IP69K Rating

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OA200AP-11-1TB1869K](#) [OA200AP-11-1WB1869K](#) [OA200AP-22-1TB1869K](#) [OA200AP-22-1WB1869K](#)