


OA225AP All Metal IP Rated Series



AC Fans - 115, 230V
225mm x 80mm (8.9" x 3.2")

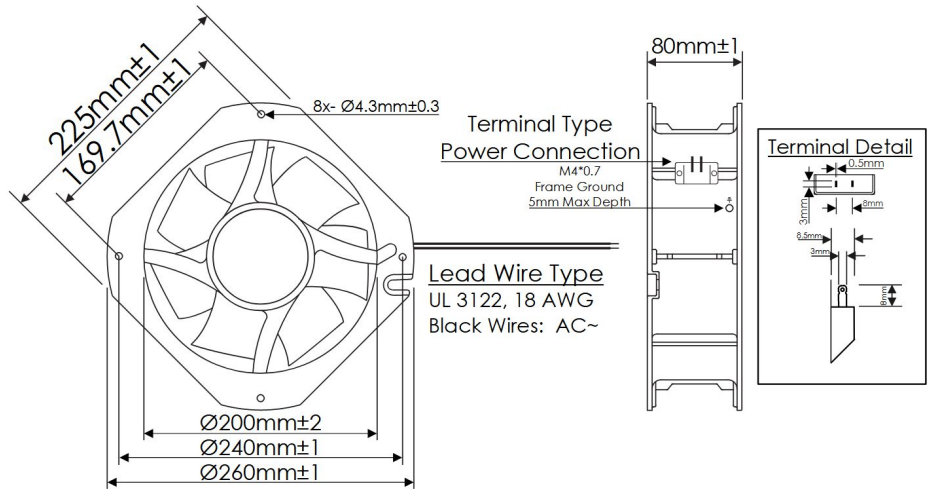

Frame	Die Cast Aluminum, Black Finish	<u>Operating Temperature</u> -30°C ~ +80°C	Static Pressure ("H₂O") vs Air Flow (CFM) --- 50Hz — 60Hz
Impeller	Steel Alloy, Black Finish	<u>Storage Temperature</u> -40°C ~ +100°C	
Connection	Lead Wires, UL 3122 18 AWG, or Terminals	<u>Life Expectancy</u> 45,000 Hours (L10 at 55°C)	
Motor	AC, Capacitor Induction, Single Phase, Thermally Protected	<u>Installed Options</u> IP Rating	
Bearing System	Ball Bearings	<u>Available Options</u> Tachometer Output Alarm Output Other Speeds Available	
Dielectric Strength	1500VAC/min, <5mA	Weight: 4.81 lbs.	
Insulation Resistance	≥100MΩ @ 500VAC		

Part Number	Rated Voltage (Volts AC)	Voltage Range (Volts AC)	Frequency (Hertz)	Input Power (Watts)	Rated Speed (RPM)	Max Airflow (CFM)	Noise Level (dBA)	Max Static Pressure ("H ₂ O")
OA225AP-11-1*B18IPxx	115	100 ~ 130	50 / 60	60 / 80	2600 / 3000	540 / 620	66.2	0.80 / 0.74
OA225AP-22-1*B18IPxx	230	200 ~ 255	50 / 60	60 / 80	2600 / 3000	540 / 620	66.2	0.80 / 0.74

*Insert "T" for Terminal or "W" for Lead Wire
xx = Insert "68" for IP68 Rated or "69K" for IP69K rating

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Orion Fans:](#)

[OA225AP-11-1TB1869K](#) [OA225AP-11-1WB1869K](#) [OA225AP-22-1TB1869K](#) [OA225AP-22-1WB1869K](#) [OA225AP-11-1TB1868](#) [OA225AP-11-1WB1868](#) [OA225AP-22-1TB1868](#) [OA225AP-22-1WB1868](#)