



OA2547AP IP Rated Series



AC Fans - 115, 230V
254mm x 89mm (10" x 3.5")

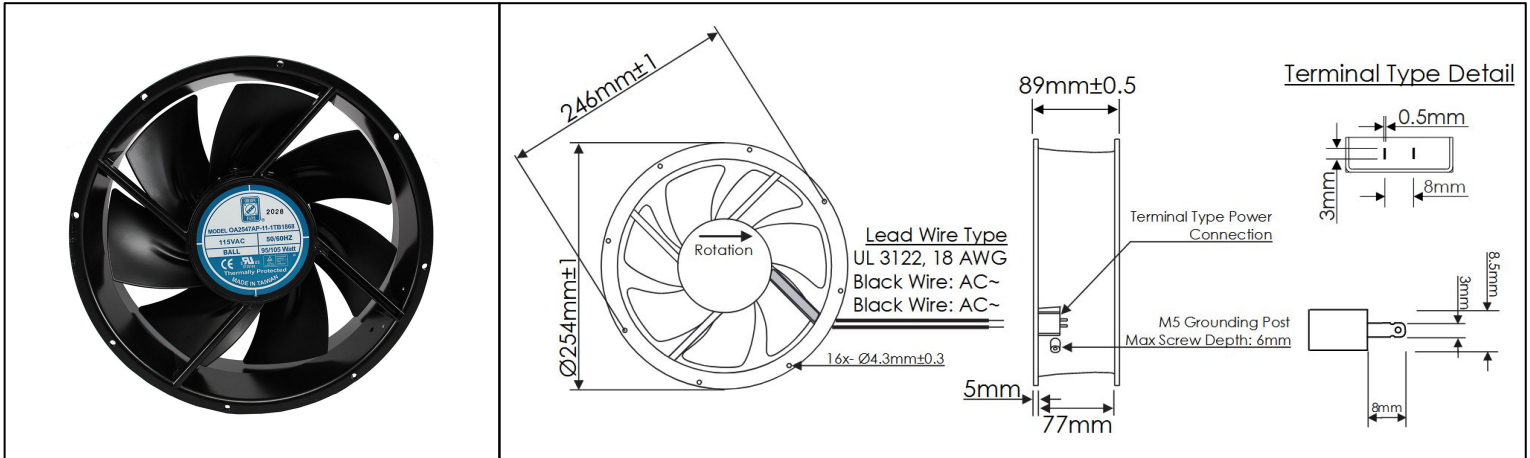

Frame	Die Cast Aluminum, Black Finish	<u>Operating Temperature</u> -30°C ~ +80°C <u>Storage Temperature</u> -40°C ~ +100°C <u>Life Expectancy</u> 50,000 Hours (L10 at 55°C) <u>Available Options</u> Tachometer Output Alarm Output Other Speeds Weight: 5.6 lbs.
Impeller	Steel Alloy, Black Finish	
Connection	Lead Wires, UL 3122 18 AWG, or Terminals	
Motor	AC, Capacitor Induction, Single Phase, Thermally Protected, IP Rated	
Bearing System	Ball Bearings	
Dielectric Strength	1500VAC/min, <5mA	
Insulation Resistance	≥10MΩ @ 500 VDC	

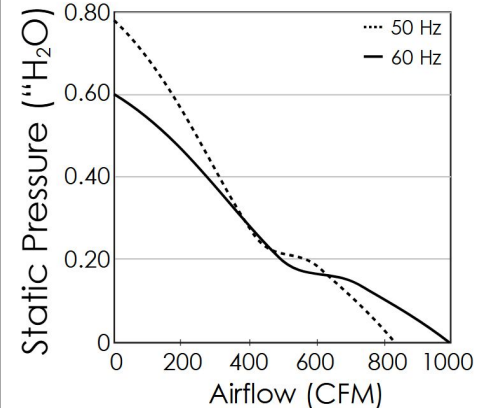

Part Number	Rated Voltage (Volts AC)	Voltage Range (Volts AC)	Input Power (Watts)	Frequency (Hertz)	Rated Speed (RPM)	Max Airflow (CFM)	Noise Level (dBA)	Max Static Pressure ("H ₂ O)
OA2547AP-11-1*B18xxx	115	100 ~ 130	95 / 105	50 / 60	2775 / 3250	830 / 1000	70	0.78 / 0.60
OA2547AP-22-1*B18xxx	230	200 ~ 255	95 / 105	50 / 60	2775 / 3250	830 / 1000	70	0.78 / 0.60

*Insert "T" for Terminals type power connection, or "W" for Lead Wire type power connection
xxx Append "68" for IP68 Rating, or "69K" for IP69K Rating

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Orion Fans:](#)

[OA2547AP-11-1TB1869K](#) [OA2547AP-11-1WB1869K](#) [OA2547AP-22-1TB1869K](#) [OA2547AP-22-1WB1869K](#)