


OA254AP Series



AC Fans - 115, 230V
254mm x 89mm (10" x 3.5")

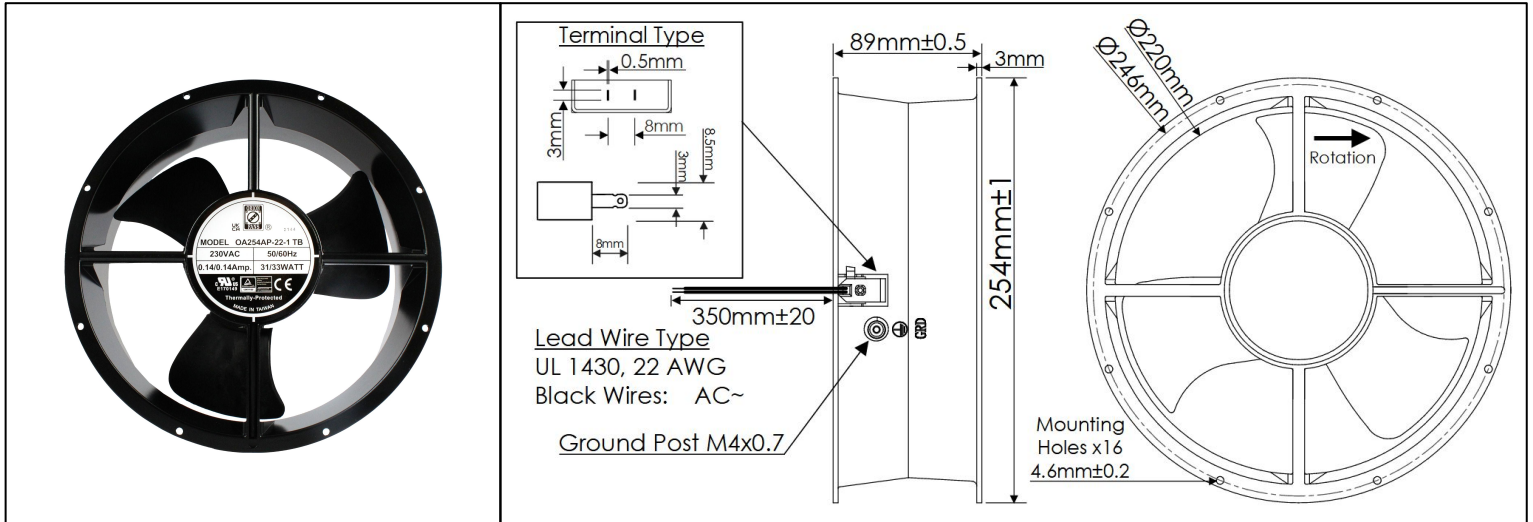

Frame	Die Cast Aluminum, Black Finish	Operating Temperature -20°C ~ +80°C Storage Temperature -40°C ~ +80°C Life Expectancy 60,000 Hours (L10 at 40°C) Available Options Tachometer Output IP Ratings Weight: 4.2 lbs.	
Impeller	PBT, UL94 V-0 Plastic		
Connection	2x Wire Leads, 22 AWG, or Terminals		
Motor	AC Capacitor Induction, Thermally Protected		
Bearing System	Ball Bearings		
Dielectric Strength	1500VAC/min, <1mA		
Insulation Resistance	≥10MΩ @ 500 VDC		

Part Number	Rated Voltage (Volts AC)	Frequency Range (Hertz)	Voltage Range (Volts AC)	Rated Current (Amps)	Locked Current (Amps)	Input Power (Watts)	Rated Speed (RPM)	Max Airflow (CFM)	Noise Level (dBA)	Max Static Pressure ("H ₂ O)
OA254AP-11-1*B	115	50 / 60	80 ~ 130	0.30 / 0.29	0.53 / 0.51	31 / 33	1400 / 1650	460 / 547	52 / 55	0.32 / 0.39
OA254AP-22-1*B	230	50 / 60	160 ~ 260	0.14 / 0.14	0.26 / 0.26	31 / 33	1400 / 1650	460 / 547	52 / 55	0.32 / 0.39

*Substitute "W" for Wire Lead type power connection, or "T" for Terminal type power connection.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Orion Fans:](#)

[OA254AP-11-1WB](#) [OA254AP-11-1TB](#) [OA254AP-22-1WB](#) [OA254AP-22-1TB](#)