


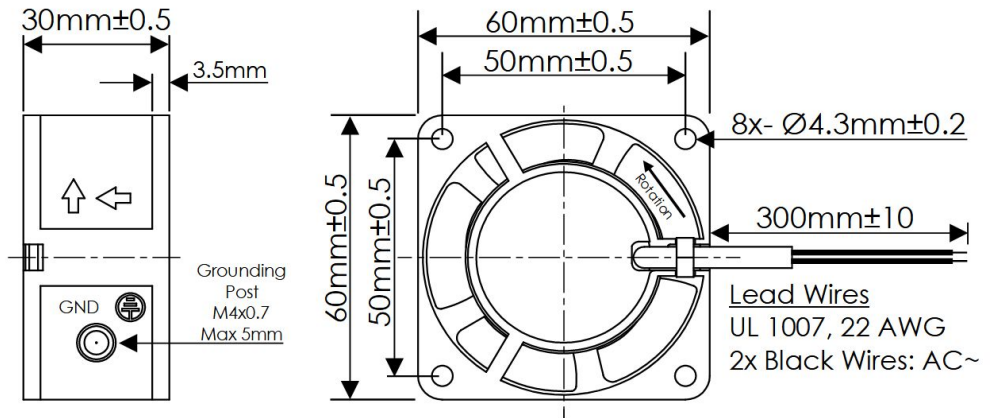

Frame	Die Cast Aluminum, Black Finish	<u>Operating Temperature</u> -40°C ~ +70°C <u>Storage Temperature</u> -40°C ~ +80°C <u>Life Expectancy</u> 40,000 Hours (L10 at 40°C) Weight: 0.31 lbs
Impeller	PBT, UL 94 V-0 Plastic	
Connection	2x Wire Leads, 22 AWG	
Motor	AC Shaded Pole, Impedance Protected	
Bearing System	Ball Bearings	
Dielectric Strength	1500VAC/min, <1mA	
Insulation Resistance	≥10MΩ @ 500 VDC	

Airflow (CFM)	Static Pressure (inches H ₂ O) at 50 Hz	Static Pressure (inches H ₂ O) at 60 Hz
0	0.06	0.105
2	0.03	0.06
4	0.015	0.03
6	0.01	0.025
8	0.005	0.015
10	0	0

Part Number	Rated Voltage (Volts AC)	Voltage Range (Volts AC)	Frequency (Hertz)	Input Power (Watts)	Rated Current (Max Amps)	Rated Speed (RPM)	Max Airflow (CFM)	Noise Level (dBA)	Max Static Pressure ("H ₂ O)
OA60AP-11-1WB	115	105 ~ 130	50 / 60	5 / 4	0.064 / 0.056	2400 / 3000	7.8 / 9.9	28.3	0.06 / 0.10
OA60AP-22-1WB	230	210 ~ 255	50 / 60	5 / 4	0.035 / 0.030	2400 / 3000	7.8 / 9.9	28.3	0.06 / 0.10

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OA60AP-11-1WB](#) [OA60AP-22-1WB](#) [OA60AP-11-1TB](#) [OA60AP-22-1TB](#)