


OA92EC XC Series



EC Fan Universal Voltage
92mm x 25mm (3.62" x 0.98")

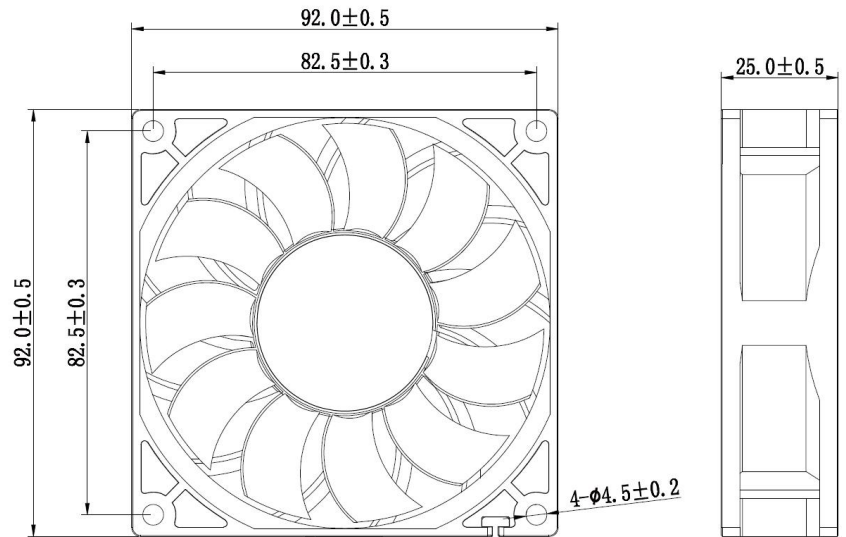

Frame	PBT, UL94 V-0 Plastic	<u>Operating Temperature</u> -10°C ~ +70°C <u>Storage Temperature</u> -40°C ~ +75°C <u>Life Expectancy</u> 70,000 Hours (L10 at 40°C) Weight: 0.22 lbs.	
Impeller	PBT, UL94 V-0 Plastic		
Connection	2x Wire Leads		
Motor	Electronically Commutated, Auto Cutoff, Auto Restart, Electronically Protected		
Bearing System	Ball Bearings		
Dielectric Strength	500VAC/min, <1mA		
Insulation Resistance	≥10MΩ @ 500 VDC		

Part Number	OA92EC-UR-1WBXC
Rated Voltage (Volts AC)	115 / 230
Voltage Range (Volts AC)	85 ~ 265
Frequency (Hertz)	50 / 60
Rated Input (Watts)	8 ~ 6 Max (4.0 Typical)
Rated Speed (RPM)	2600
Max Airflow (CFM)	56
Noise Level (dBA)	35
Max Static Pressure (" H ₂ O)	0.16

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Orion Fans:

[OA92EC-UR-1WBXC](#)