


OA938EC XC Series



EC Fans - Universal Voltage
92mm x 38mm (3.62" x 1.50")

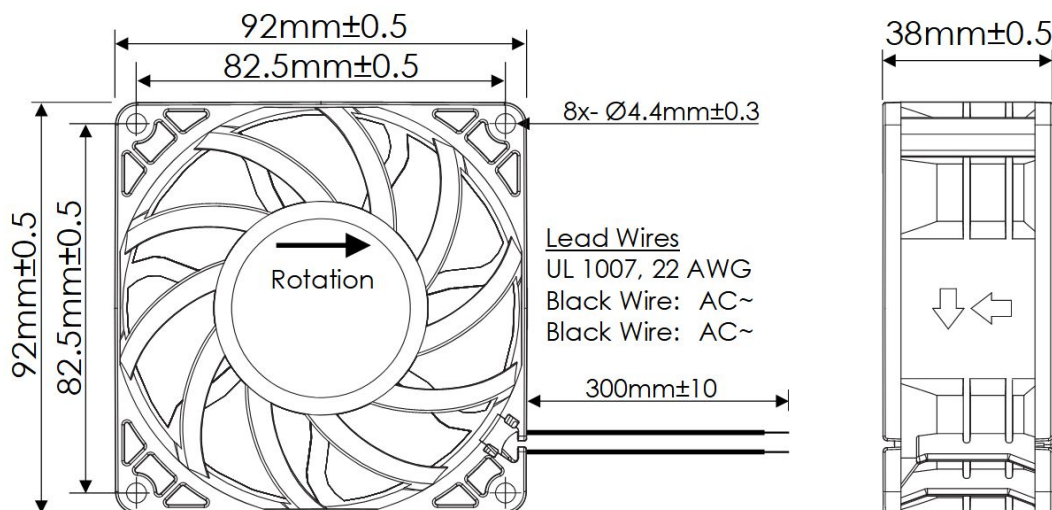

Frame	PBT, UL 94 V-0 Plastic	<u>Operating Temperature</u> -20°C ~ +65°C <u>Storage Temperature</u> -20°C ~ +75°C <u>Life Expectancy</u> 70,000 Hours (L10 at 40°C) Weight: 0.44 lbs.	Static Pressure ("H₂O") vs. CFM graph showing a curve from 0.50 at 0 CFM to 0 at 90 CFM.
Impeller	PBT, UL 94 V-0 Plastic		
Connection	2x Wire Leads, UL 1007 22 AWG, 300mm±10		
Motor	AC-DC Energy Saving, Electronically Protected		
Bearing System	Ball Bearings		
Dielectric Strength	1500VAC/min, <1mA		
Insulation Resistance	≥10MΩ @ 500 VDC		

Part Number	OA938EC-UR-1WBXC
Rated Voltage (Volts AC)	115 / 230
Frequency (Hertz)	50 / 60
Voltage Range (Volts AC)	85 ~ 265
Input Power (Watts)	11 ~ 9
Rated Speed (RPM)	4200
Max Airflow (CFM)	85.4
Noise Level (dBA)	52
Max Static Pressure ("H ₂ O)	0.5

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Orion Fans:](#)

[OA938EC-UR-1WBXC](#)